


926894-1 Soft Shell Connectors
Soft Shell - Contacts

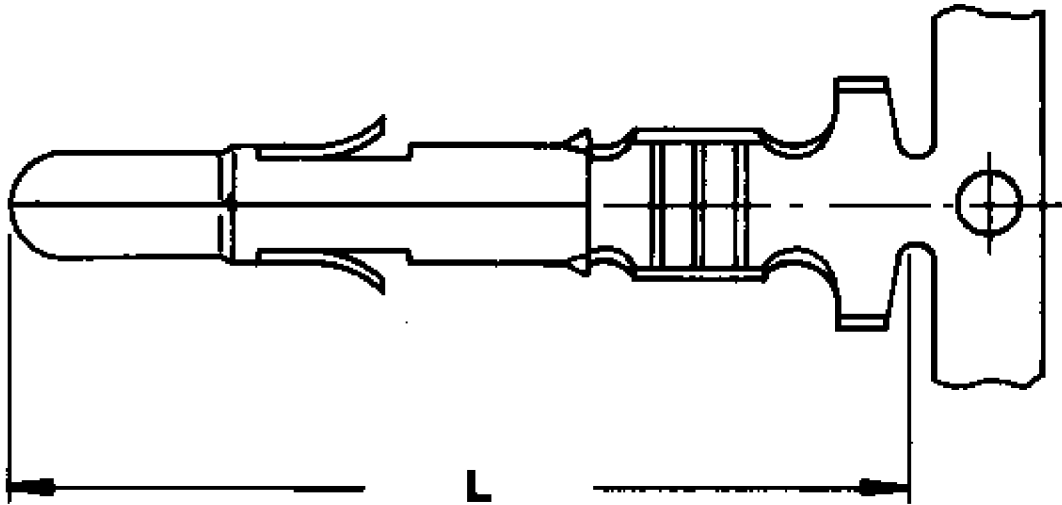

Line art represents typical product only.

| <i>Searchable Features:</i> | |
|------------------------------------|--|
| Connector Line | Universal MATE-N-LOK |
| Contact Diameter | .084 [2.13] in. [mm] |
| Contact Type | Pin |
| High Current | No |
| Mount | Wire Crimp |
| Wire Range | 20-14 [0.50-2.00 ²] AWG [mm] |
| Insulation Diameter | .130 [3.30] Max. in. [mm] |
| Material | Brass |
| Finish | Pre Tin |
| Packaging Method | Loose Piece |
| <i>Other Properties:</i> | |
| Dim. L | .791 [20.10] in. [mm] |