



7 320394 415710



7 320394 415727










7 320394 415734



7 320394 415741

Art no	441571 / H=10mm
Art no	441572 / H=12mm
Art no	441573 / H=15mm
Art no	441574 / H=20mm
Material	Rfr. SIS 2333 / S.S. ASTM 304
Ytbehandling / Treatment	Elektropolerat / Electro polished
Vikt / Weight	52-65g/st / 52-65g/pcs

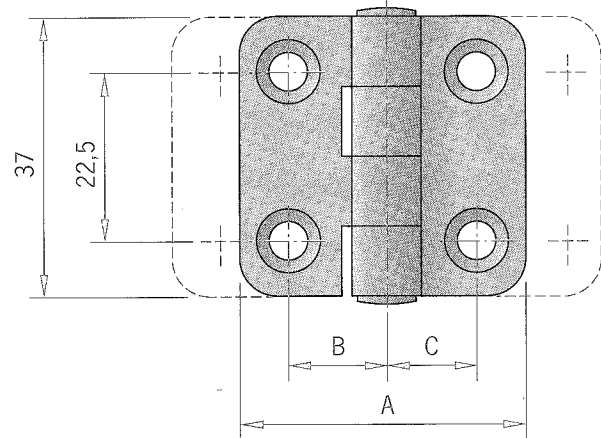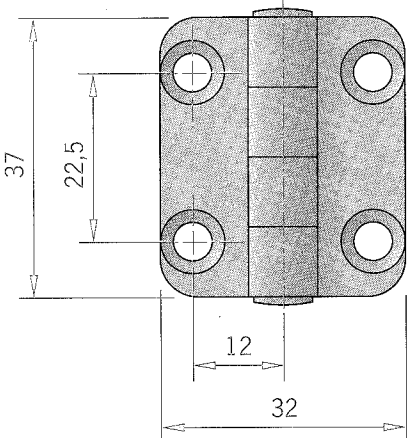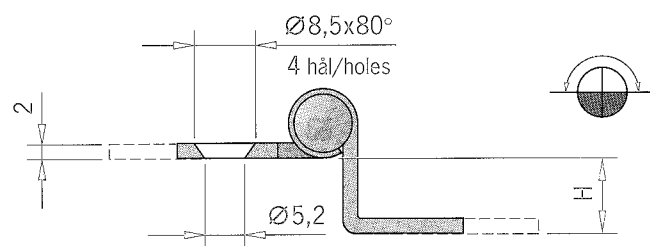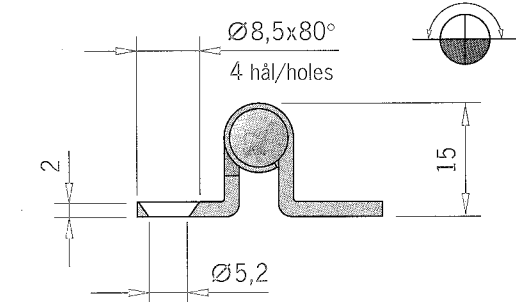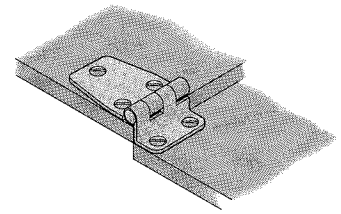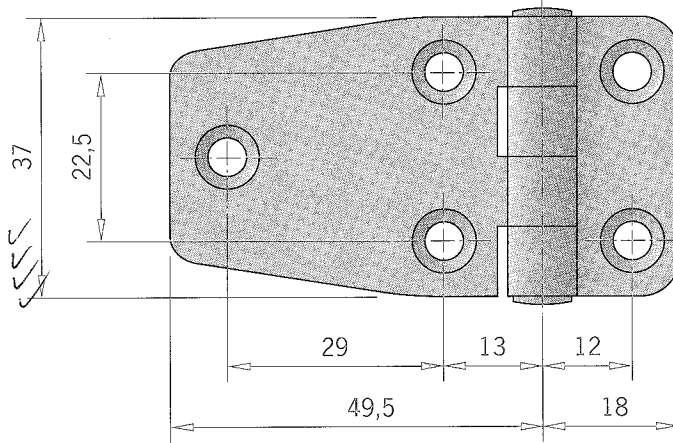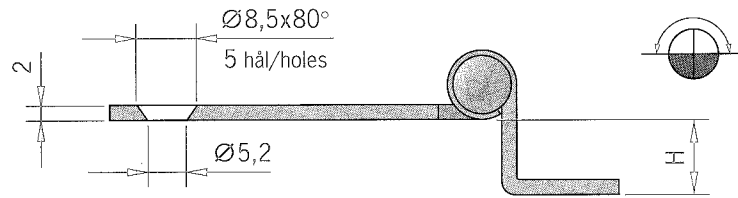

Art no	441630
Material	Rfr. SIS 2333 / S.S. ASTM 304
Ytbehandling / Treatment	Elektropolerat / Electro polished
Vikt / Weight	45g/st / 45g/pcs

	H	A	B	C	
Art no	444030	10	57	22	24
Art no	444031	15	57	22	24
Art no	441591	10	38	13	12
Art no	441592	12	38	13	12
Art no	441593	15	38	13	12
Art no	441594	20	38	13	12
Material	Rfr. SIS 2333 / S.S. ASTM 304				
Ytbehandling / Treatment	Elektropolerat / Electro polished				
Vikt / Weight	36-49g/st / 36-49g/pcs				



7 320394 415918



7 320394 415925



7 320394 415932



7 320394 416304



7 320394 440309



7 320394 440316



7 320394 415949

