

FEATURES AND SPECIFICATIONS

Features and Benefits

- Cable assembly with two 90327 connectors
- Sizes 4 to 20 and 26 (see 90327)
- UL 2651, 28 AWG (7 strand) ribbon cable
- Lengths from 7 to 120cm

Reference Information

Packaging: Bag
 Mates With: 90325, 90800, 90814, 90715 and 90779
 Designed In: Millimeters

Electrical

Voltage: 250V
 Current: 1.2A

Mechanical


Mating Force: 1.7N
 Unmating Force: 0.25N
 Durability: 30 cycles max.

Physical


Housing: 6/6 nylon, UL 94V-0
 Contact: Phosphor Bronze Alloy
 Plating: 3–6µ" Tin/Lead
 Temperature: -20 to +105°C
 Insulation: Cable—Gray PVC
 Wire Range: 28 AWG

**molex® 1.27mm (.050") Pitch
 Picoflex™ PF-50
 Custom Cable Harness**

92315

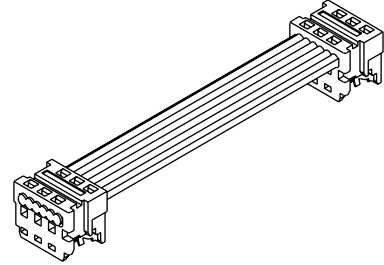

See 90327 and 6800 cable pages for more specifications

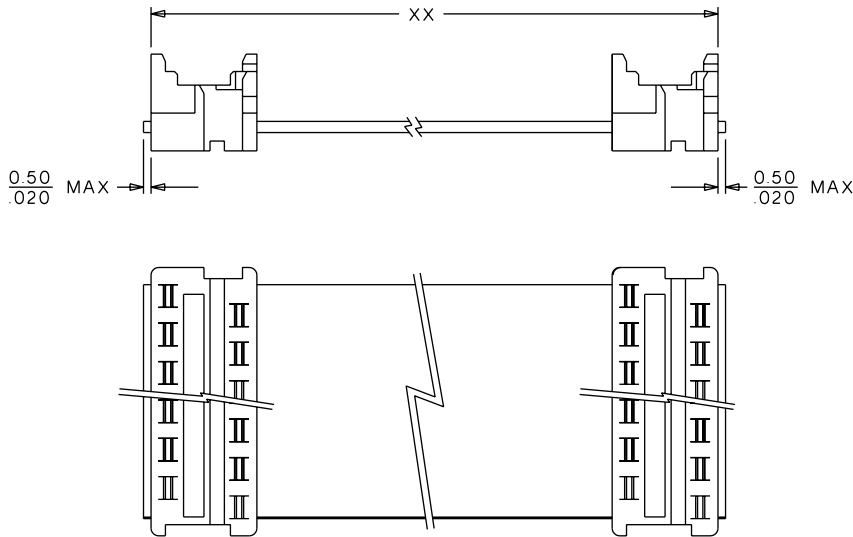

ORDERING INFORMATION AND DIMENSIONS

Circuits	Order No.
4	92315-04XX
6	92315-06XX
8	92315-08XX
10	92315-10XX
12	92315-12XX
14	92315-14XX
16	92315-16XX
18	92315-18XX
20	92315-20XX
26	92315-26XX

Length	XX
7–99cm	07–99
100cm	01
105cm	02
110cm	03
115cm	04
120cm	05

Replace XX with length in cm (min. 7cm, max. 120cm), see table
 Example: 92315-0832 is a cable with two 90327-0308, 32cm long