

# Product Selector

## Ap800 Direct Power Adaptor



Direct power adaptor for AC Utility supply voltage.

Suitable for; UK, European and North American supplies, just select the relevant lead.

### Description

### ASL Stock Number

Universal Power Adaptor ( 110 to 230 VAC )

07-Ap800-PSA

Power Cord ( USA & Canada )

07-Ap800-PSA-CA-A

Mains Lead ( UK & Ireland )

07-Ap800-PSA-CA-B

Power Cord ( Europe )

07-Ap800PSA-CA-E


---

## Data Cables

We offer a range of data cables designed to offer connectivity to popular data sources. Each cable is terminated with the special locking connector required at the printer side. An open-ended cable is supplied for OEM integration or special cables can be manufactured by request.

<b>Connector cables available</b>	<b>Length</b>	<b>ASL Stock Number</b>
9 way D-Type RS232	1.7 metres (to be phased out)	07-Ap800-9-BD17
9 way D-Type RS232	1.2 metres (new version)	07-Ap800-B9C
25 way D-Type RS232	2 metres	07-Ap800-BDC
No connector	2 metres	07-Ap800-BOC

## Consumables

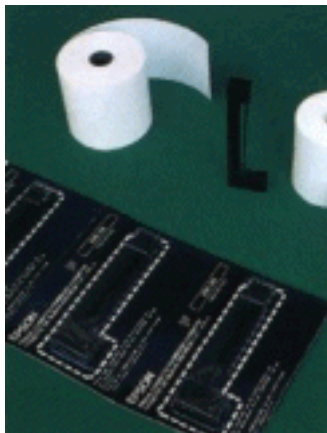

### **Ap890 / Ap892 Impact Versions**

### **ASL Stock Number**

Ink Ribbon Cassette -  
Purple

05-A160IRCP

Ink Ribbon Cassette -  
Black

05-A160IRCB

Paper Roll, 50mm  
OD (approx.19m  
length)

04-A160PR

### **Ap863 Thermal Versions**

### **ASL Stock Number**

Thermal paper roll  
46mm OD (approx.  
24m length)

04-A05846TPR1

Thermal paper roll  
60mm OD (approx. 44m length) 04-A05860TPR1

---

## Mounting Brackets

The Ap800 range of printers can be fixed onto a vertical, horizontal or inclined surface using a specially designed mounting bracket. To use this option it is necessary to specify a modified version of the printer (incorporating specially fitted brass inserts) when ordering. The bracket itself is available as a separate item.



<b>Description</b>	<b>ASL Stock Number</b>
Metal bracket kit including screws & washers but excluding case inserts	07-Ap800-MPL
24 Column Impact Printer with bracket mounting modification	07-Ap890-BI
40 Column Impact Printer with bracket mounting modification	07-Ap892-BI
Fixed Head Thermal Printer with bracket mounting modification	07-Ap863-BI

---

## Special Colours



The Ap800 series printers are light grey (also referred to as 'bone' coloured).

Dark grey is also available to special order.

Other colours can be painted or moulded (subject to minimum order quantities)

---

## Carry Cases



Shoulder strap and / or belt fixing versions can be supplied. Please contact us for further details.

