



Series POS & POO
- open body with and without centre bars -
If you need all Insulator Dimension pls. ask for customer drawing!

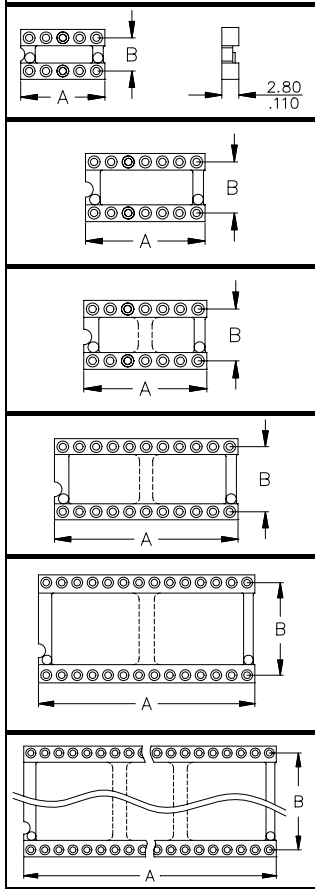

POS sockets in 7,62mm/.300" DIP spacing are either supplied with or without bars in the centre depending on plastic wafer availability. If you need sockets without centre bars, then please always order with POO instead of POS.

Pin	Dimension		Available Pinouts of Series		
	"A"	"B"	POS	POO	PCL
10	12,60	5,08 .200"	-210-	-210-	-210-
6	7,60	7,62 .300"	-306-	-	-
8	10,10		-308-	-	-308-
10	12,60		-310-	-	-
14	17,70		-314-	-314-	-314-
16	20,30	7,62 .300"	-316-	-316-	-316-
18	22,80		-318-	-318-	-318-
20	25,30		-320-	-320-	-320-
22	27,80		-322-	-322-	-
24	30,40		-324-	-324-	-
28	35,50		-328-	-328-	-
16	20,32	10,16 .400"	-416-	-416-	-416-
22	27,80		-422-	-422-	-422-
24	30,60		-424-	-424-	-424-
24	30,50	15,24 .600"	-624-	-624-	-624-
28	35,50		-628-	-628-	-628-
32	40,60		-632-	-632-	-632-
36	45,70		-636-	-636-	-
40	50,80		-640-	-640-	-640-
48	60,96		-648-	-648-	-648-
64	81,26	22,86 .900"	-964-	-964-	-

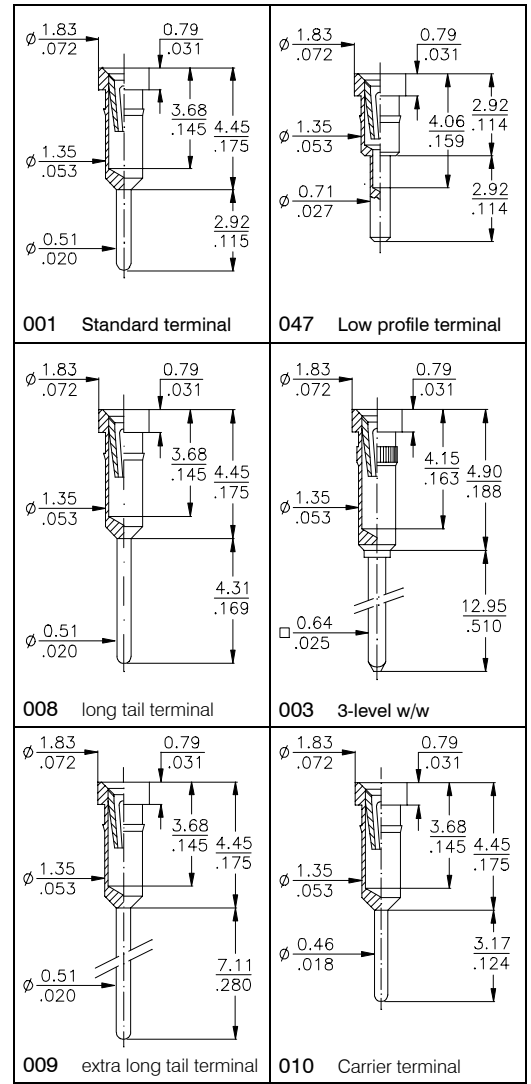

Specifications
see page 71 of this catalogue.

Insulator body
POS series = open insulator - see drawings above
POO series = open insulator w/o centre bars
PCL series = closed insulator body

Terminals
The POS, POO and PCL series are available with many different terminal styles. The most common terminal styles are shown on the right hand side of this page. Many other additional terminals can be found at the end of this catalogue. Custom design terminals are available on request.

How to order

XXX - x xx - S xxx - xx

Series
POS
POO
PCL

DIP spacing (inch)
see above table, dimension "B"
Example: **3** for .300"
Nbr of contacts
see above table
Example: **06** for 6 Pin
insert the corresponding data of the POS, POO or PCL column

Terminal style
see drawings above or refer to last pages of this catalogue for other types.

Plating
- **95** = tin/gold
- **55** = gold/gold
- **99** = tin/tin
(tin leadfree)