



## Strip headers, right angle 2.54 mm L.C.

# INTERKON

### FEATURES

Breakable strip pitch 2.54 mm.

### TECHNICAL DATA

#### Material

Insulator material: black polyester P.B.T. UL94V-0

Contact: copper alloy

#### Electrical

Current rating: 3A maxi


Dielectric withstanding: 100 V AC for one minute

Insulation resistance:  $5 \times 10^3$  M $\Omega$  mini

Contact resistance: 10 m $\Omega$  max

#### Mechanical

Temperature rating: -40°C to 105°C

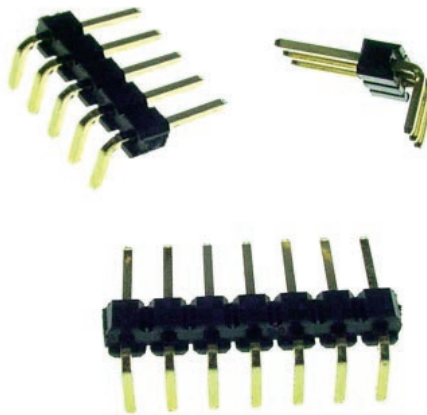


Call K-C for eventual tape and reel packaging availability (depending on quantity and number of contacts).  
High temperature PA UL94V0 insulator available on demand.

a	b	c	d	e
472	9716	1	xx	4x0


**d** Number of contacts from 02 to 40.

**e** Plating  
 0 Gold 0.25  $\mu$ m  
 1 Gold flash  
 4 Tin

(N= Number of contacts)

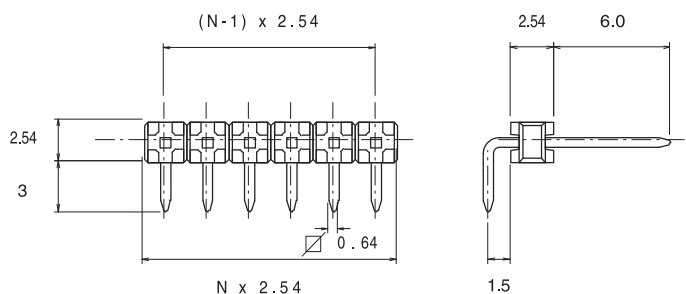

### Recommended P.C.Board Hole Layout

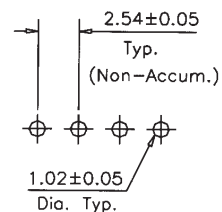

For alternative products see also page 69 and 88.