


## Fixing Accessories for Wirewound Resistors Equipped with AN Collars Suitable for RW - RA - RSSD - RSO

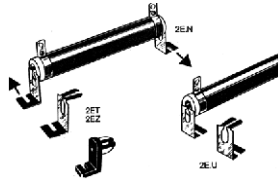

These 2E double right-angle brackets are designed to fix resistors without providing electrical contact. As they are fitted to resistors with fixing insulated connections, they can be mounted on uninsulated panels.

### FEATURES


- They are available in three versions:
  - Bracket 2E N Shape
  - Bracket 2E U Shape (restricted space)
  - Brackets 2E T or 2E Z shape designed for models of Ø 40 mm and 50 mm
- The brackets are metal, and are corrosion-resistant
- Material categorization: For definitions of compliance please see [www.vishay.com/doc?99912](http://www.vishay.com/doc?99912)




RoHS  
COMPLIANT

### DIMENSIONS in millimeters

#### DOUBLE RIGHT-ANGLE BRACKET 2E N

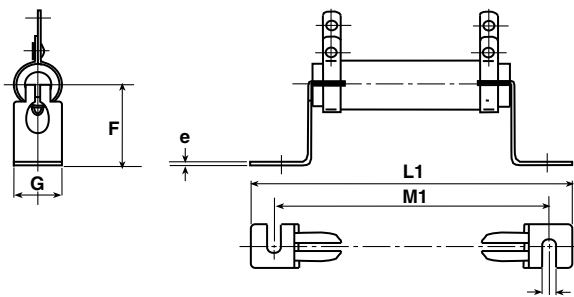

#### DOUBLE RIGHT-ANGLE BRACKET 2E U

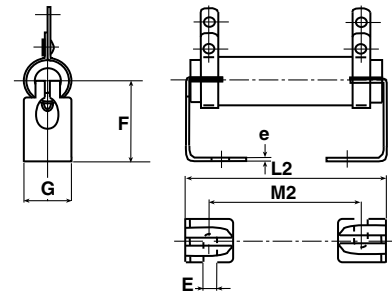

| DIMENSIONS in millimeters |          |                |            |          |            |                  |                  |                  |                  |     |                                |
|---------------------------|----------|----------------|------------|----------|------------|------------------|------------------|------------------|------------------|-----|--------------------------------|
| SERIES                    |          | BRACKET        | E<br>± 0.1 | F<br>± 1 | G<br>± 0.5 | L1<br>- 0<br>- 4 | M1<br>- 1<br>- 4 | L2<br>- 0<br>- 4 | M2<br>- 0<br>- 4 | E   | AVERAGE<br>UNIT WEIGHT<br>IN g |
| RW<br>RSO<br>RA           | RSSD     |                |            |          |            |                  |                  |                  |                  |     |                                |
| 8 x 34                    | 8 x 34   | 2E BN or 2E BU | 3.2        | 21.5     | 8          | 58               | 48               | 38               | 26               | 1   | 1.8                            |
| 10 x 50                   | 10 x 50  | 2E DN or 2E DU | 3.2        | 21.5     | 10         | 74               | 64               | 54               | 42               | 1   | 2.2                            |
| 13 x 70                   |          | 2E DN or 2E DU | 3.2        | 21.5     | 10         | 94               | 84               | 74               | 62               | 1   | 2.2                            |
|                           | 13 x 70  | 2E FN or 2E FU | 4          | 26.5     | 14         | 102.5            | 88.5             | 74.5             | 58               | 1.2 | 4.5                            |
| 16 x 94                   | 16 x 94  | 2E HN or 2E HU | 5          | 29.5     | 20         | 132.5            | 115.5            | 98.5             | 79               | 1.2 | 8                              |
| 20 x 117                  |          | 2E HN or 2E HU | 5          | 29.5     | 20         | 155.5            | 138.5            | 121.5            | 102              | 1.2 | 8                              |
|                           | 20 x 117 | 2E KN or 2E KU | 5.5        | 37.5     | 22         | 161.5            | 141.5            | 121.5            | 99               | 1.2 | 13                             |
| 25 x 138                  |          | 2E KN or 2E KU | 5.5        | 37.5     | 22         | 182.5            | 162.5            | 142.5            | 120              | 1.2 | 13                             |
| 25 x 168                  |          | 2E KN or 2E KU | 5.5        | 37.5     | 22         | 212.5            | 192.5            | 172.5            | 150              | 1.2 | 13                             |
|                           | 25 x 138 | 2E MN or 2E MU | 5.5        | 37.5     | 22         | 182.5            | 162.5            | 142.5            | 120              | 1.2 | 13                             |
|                           | 25 x 168 | 2E MN or 2E MU | 5.5        | 37.5     | 22         | 212.5            | 192.5            | 172.5            | 150              | 1.2 | 13                             |
| 30 x 250                  |          | 2E PN or 2E PU | 8          | 44.2     | 30         | 311              | 283              | 255              | 224              | 1.5 | 28                             |
|                           | 30 x 250 | 2E SN or 2E SU | 8          | 44.2     | 30         | 311              | 283              | 255              | 224              | 1.5 | 28                             |
| 40 x 370                  | 40 x 370 | 2E T           | 9          | 40       | 40         | 448              | 418              | -                | -                | 6   | 65                             |
| 50 x 373                  | 50 x 373 | 2E Z           | 9          | 40       | 40         | 451              | 421              | -                | -                | 6   | 65                             |



| ORDERING INFORMATION                         |      |      |                |  |
|--|------|------|----------------|--|
| MODEL  | TYPE | PAIR | LEAD (PB)-FREE |  |
| 2E   | BN   | ...  | e              |  |
| Fixing accessories for RW 8 x 34 AN resistor |      |      |                |  |

**Note**

- Brackets are sold in pairs

| SAP PART NUMBERING GUIDELINES |       |      |  |
|-------------------------------|-------|------|--|
| ACCRF                         | 2E    | BN   |  |
| MODEL                         | STYLE | TYPE |  |