




Product Specification Sheet

Auteau Knee Operated Valve

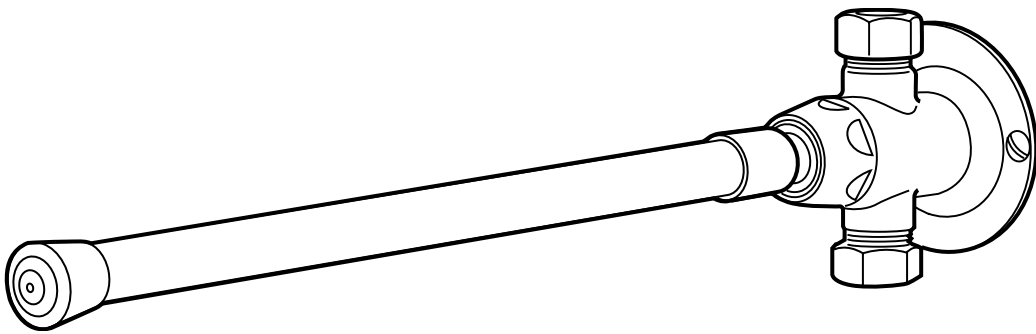

A high quality, chrome plated, timed flow knee operated tap, for industrial, commercial and healthcare applications.

Product Features and Benefits

- **Hands free activation** of timed flow control to prevent cross contamination.
- Incorporates the patented **self cleaning** Auteau cartridge.
- Removable cartridge for **easy maintenance or replacement**.
- **Solid brass** body for **long life**.
- Standard 15mm compression connection.
- Conforms to BS EN 816.
- **Saves up to 60% of water usage** when compared to conventional taps.
- **Saves energy** as well as water when fitted on hot water systems.
- 15 sec timed flow rate.

Auteau Knee Operated Valve

Description

The Auteau knee operated tap is solid brass construction, chrome plated to a high standard, the internal timeflow mechanism incorporates the unique self cleaning cartridge which is designed to provide a flow of water for 15 sec as per BS EN 816, a strainer is also incorporated into the cartridge to protect against system or mains debris entering and damaging the internal working components of the cartridge.

The Auteau knee operated tap is suitable for use in industrial, commercial, and healthcare applications where it is desirable to avoid touching the tap with hands to turn on the flow of water. It can be used in conjunction with Reliance's range of thermostatic mixing valves, such as the Heatguard TMV3-8 (HEAT 160 series) for single outlet applications or the Planar 430 (HEAT 430 series) and 530 (HEAT 530 series) for use in multiple outlet applications.

Product Range

PUSH 100 030: 15mm compression, knee operated timed flow bib tap
SKIT 100 001: Spare time flow cartridge


Materials

Body: Standard brass
Cartridge: Polyacetal
Seals: Nitrile


Standards

Conforms to BS EN 816

Flow Rate

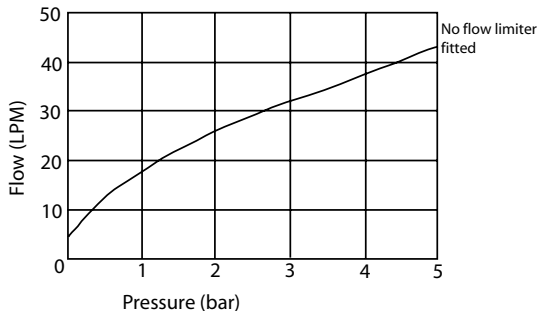

Dimensions

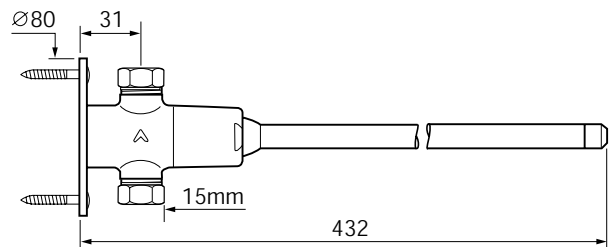

All dimensions in mm unless stated

Specifications

Maximum working pressure:	6 bar
Minimum working pressure:	0.2 bar
Maximum static pressure:	10 bar
Timed flow rate:	15 sec (± 5 sec.)
Maximum temperature:	90°C
Minimum temperature:	5°C
Connection:	15mm Compression

How to Specify

A 15mm knee operated valve, conforming to BS EN 816. The tap shall be constructed from solid brass and incorporate a self cleaning cartridge (include correct product range code).

Guarantee

All Reliance products undergo strict performance tests prior to despatch, and are guaranteed against faulty materials and workmanship for one year from the date of purchase. This is in addition to any statutory rights.

Contacts:	Sales Enquiries	Technical Support
Telephone:	+44 (0)1386 712400	+44 (0)1386 47148
Fax:	+44 (0)1386 47028	+44 (0)1386 422217
E-Mail:	sales@rwc.co.uk	technical@rwc.co.uk



Reliance Water Controls
Worcester Road, Evesham, Worcestershire, WR11 4RA, UK
Tel: +44 (0)1386 47148 Fax: +44 (0)1386 47028 www.rwc.co.uk

