


FLOJET

a xylem brand

R4300242A

*Self-Priming Quad
Diaphragm Pump 230v ac*

- ◆ Built-in pressure switch automatically starts and stops pump instantaneously when discharge valve is opened and closed.
- ◆ Compact design and plug-in port fittings make installation easy.
- ◆ Can run dry without damage and handle liquids up to 130°F (54C).
- ◆ Quad Diaphragm design eliminates troublesome shaft seal.
- ◆ No metal contact with liquid being pumped.
- ◆ Self-priming capability up to 1.5m. Pump may be located above the liquid level.
- ◆ Powerful, permanent magnet motor with low current draw and long life brushes

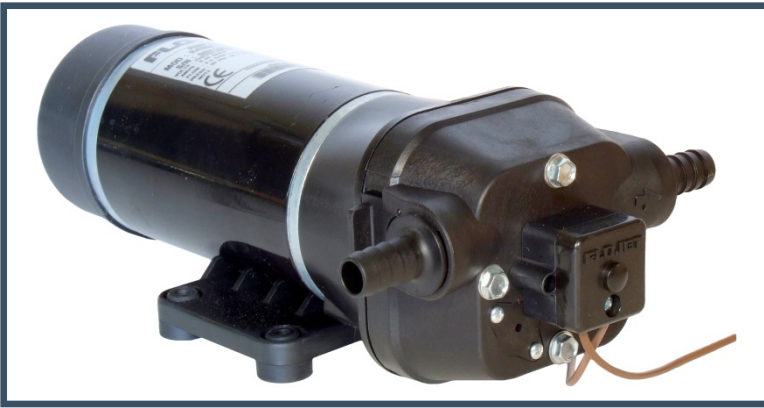

CONNECTIONS: 15mm (1/2") hose barb.

PRESSURE SWITCH SETTINGS:


Cuts in at 1 bar (15 psi)
Cuts out at 2 bar (30psi)

MATERIALS OF CONSTRUCTION:

Pump head: Glass-filled Polypropylene
Diaphragm: Santoprene®
Valves: EPDM

OUTPUT:

Up to 12 litres/minute (2.7 gallons/minute).

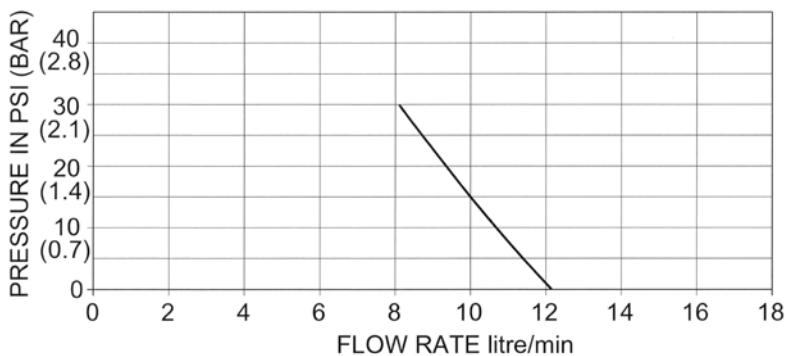

FUSE SIZE: 3 amp

WEIGHT: 2.9 Kg

