

Blizzard 50 L 20W 100-240V

DIN rail mount PTC heating element

(natural convection)

- Features:
- Dynamic natural convection heating
 - Compact and powerful design
 - Self regulating, highest power at low ambient
 - Finger-guard with integrated terminal block
 - Stainless steel 35mm DIN rail clip
 - Approved Heater Component KSOT2/8, E319928





Specifications:	
Marking (adhesive label)	ΩDBK Blizzard 50 L 20W 100-240VAC
Maximum Wattage (25°C/77°F)	20W
Voltage (VAC)	100 - 240 VAC
Ir	≤1.2A
Dimensions L mm [in]	97.5mm [3.84"]
Protection Type	IP20
Terminal Block	UL94V-0 12-24AWG



Application Notes:

Optimised for Low Inrush Current
Dual Voltage 100-240VAC
UL94V-0 heater guard, does not exceed 74°C (165°F)
For optimum performance mount vertically

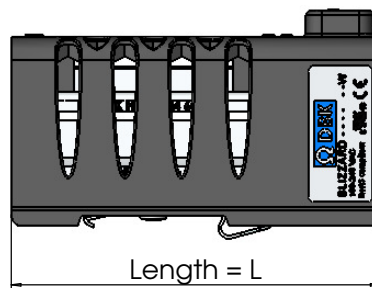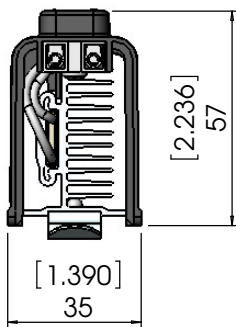


Blizzard 200 L 30W 100-240V

DIN rail mount PTC heating element

(natural convection)



- Features:
- Dynamic natural convection heating
 - Compact and powerful design
 - Self regulating, highest power at low ambient
 - Finger-guard with integrated terminal block
 - Stainless steel 35mm DIN rail clip
 - Approved Heater Component KSOT2/8, E319928

Specifications:	
Marking (adhesive label)	ΩDBK Blizzard 200 L 30W 100-240VAC
Maximum Wattage (25°C/77°F)	30W
Voltage (VAC)	100 - 240 VAC
Ir	≤2.2A
Dimensions L mm [in]	157.5mm [6.21"]
Protection Type	IP20
Terminal Block	UL94V-0 12-24AWG

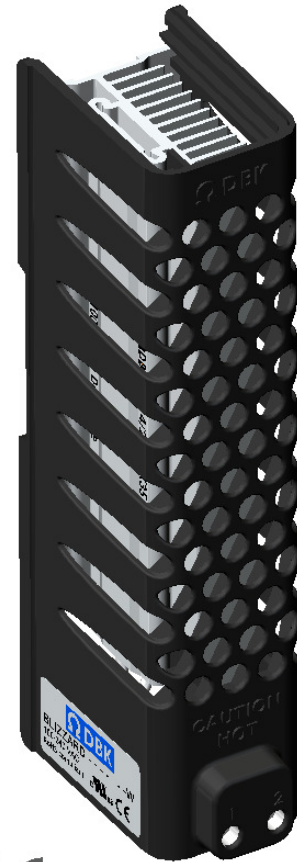

Application Notes:

- Optimised for Low Inrush Current
- Dual Voltage 100-240VAC
- UL94V-0 heater guard, does not exceed 74°C (165°F)
- For optimum performance mount vertically

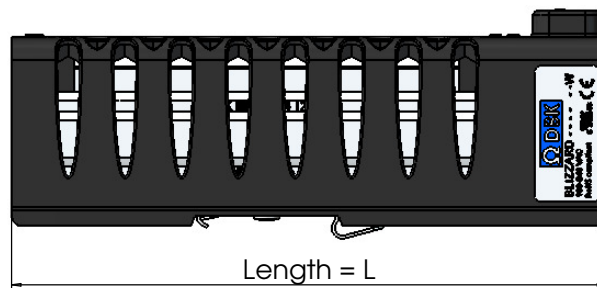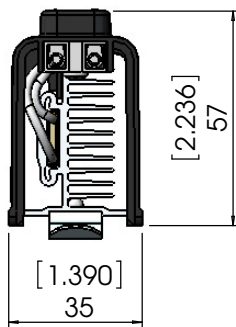

Blizzard 50 H 40W 100-240V

DIN rail mount PTC heating element

(natural convection)

- Features:
- Dynamic natural convection heating
 - Compact and powerful design
 - Self regulating, highest power at low ambient
 - Finger-guard with integrated terminal block
 - Stainless steel 35mm DIN rail clip
 - Approved Heater Component KSOT2/8, E319928





Specifications:	
Marking (adhesive label)	ΩDBK Blizzard 50 H 40W 100-240VAC
Maximum Wattage (25°C/77°F)	40W
Voltage (VAC)	100 - 240 VAC
Ir	≤2.0A
Dimensions L mm [in]	97.5mm [3.84"]
Protection Type	IP20
Terminal Block	UL94V-0 12-24AWG



Application Notes:

Optimised for Low Inrush Current
Dual Voltage 100-240VAC
UL94V-0 heater guard, does not exceed 105°C (221°F)
For optimum performance mount vertically

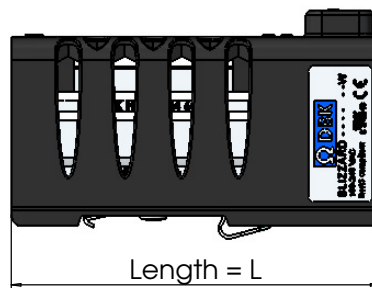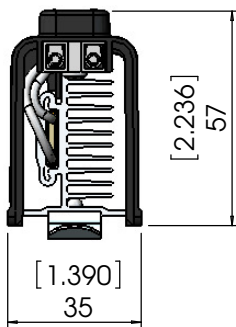


Blizzard 200 H 65W 100-240V

DIN rail mount PTC heating element

(natural convection)

- Features:
- Dynamic natural convection heating
 - Compact and powerful design
 - Self regulating, highest power at low ambient
 - Finger-guard with integrated terminal block
 - Stainless steel 35mm DIN rail clip
 - Approved Heater Component KSOT2/8, E319928

Specifications:	
Marking (adhesive label)	ΩDBK Blizzard 200 H 65W 100-240VAC
Maximum Wattage (25°C/77°F)	65W
Voltage (VAC)	100 - 240 VAC
Ir	≤6.0A
Dimensions L mm [in]	157.5mm [6.21"]
Protection Type	IP20
Terminal Block	UL94V-0 12-24AWG

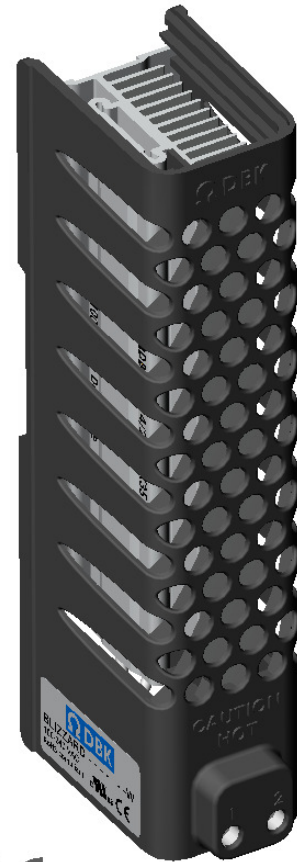

Application Notes:

- Optimised for Low Inrush Current
- Dual Voltage 100-240VAC
- UL94V-0 heater guard, does not exceed 105°C (221°F)
- For optimum performance mount vertically

