


Drive: 1/2"  
 Finish: forged, phosphated  
 Material: CHROMO-EXTRA  
 Torque according to DIN and ANSI  
 T=depth of female hexagon  
 With Dynamic-Drive-Profile

Sockets Inch, Deep  
 K7806Z

					L mm	D1 mm	D2 mm	T mm		
K7806Z-3/8	7314150137725	10	3/8	78	17	25	12	K560F-4	160	
K7806Z-7/16	7314150137732	10	7/16	78	18.5	25	13	K560F-4	160	
K7806Z-1/2	7314150137749	10	1/2	78	20.5	25	14	K560F-4	180	
K7806Z-9/16	7314150137756	10	9/16	78	23	25	14	K560F-4	180	
K7806Z-5/8	7314150137763	5	5/8	78	24.5	30	16	K560F-5	180	
K7806Z-11/16	7314150137770	5	11/16	78	27	30	17	K560F-5	220	
K7806Z-3/4	7314150137787	5	3/4	78	28	30	20	K560F-5	225	
K7806Z-13/16	7314150137794	5	13/16	78	30	30	22	K560F-5	290	
K7806Z-7/8	7314150137800	5	7/8	78	31.8	30	22	K560F-5	320	
K7806Z-15/16	7314150137718	5	15/16	78	33.8	30	24	K560F-5	320	
K7806Z-1	7314150137817	5	1	78	35.8	30	27	K560F-5	340	
K7806Z-1.1/16	7314150137824	5	1 1/16	78	37.8	30	27	K560F-5	410	
K7806Z-1.1/8	7314150137831	5	1 1/8	78	39.8	30	27	K560F-5	410	
K7806Z-1.1/4	7314150137848	5	1 1/4	78	43.8	30	32	K560F-5	430	
K7806Z-1.5/16	7314150137855	5	1 5/16	78	44.8	30	32	K560F-5	430	
K7806Z-1.3/8	7314150137862	5	1 3/8	78	47.8	30	32	K560F-5	480	
K7806Z-1.7/16	7314150137879	5	1 7/16	78	49.8	30	32	K560F-5	570	
K7806Z-1.1/2	7314150137886	5	1 1/2	78	49.8	30	32	K560F-5	570	

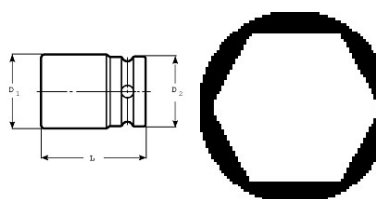

Double sided tooth system for ratchet-like use.  
 Self locking function in both directions.  
 Strong chain made of tempered special steel.  
 Material; Jaws in forged hardened steel, black  
 Handles in forged hardened steel, gray epoxy lacquered  
 Standards; US Norm GGG-W-651, Type I Class B  
 UNE 16555

Chain pipe wrench  
 HD 372

				L mm	A mm	B mm	S	
372-1.1/2	7314150133239	1	350	8	38	1.1/2	1400	
372-2.1/2	7314150133246	1	685	9	49	2.1/2	3500	
372-4	7314150133253	1	940	13	60	4	6700	
372-6	7314150133260	1	1122	20	75	6	12600	
372-8	7314150133277	1	1278	20	79	8	17000	
372-12	7314150133284	1	1625	20	82	8	24200	

