



# 16 Cable sheath strippers

## ▶ Pivoting blade sheath strippers

### Pivoting blade sheath stripper



- Extended hook for easy cable placing.
- Ergonomic "low effort" push-button.
- Easy, handy thumbwheel adjustment.
- Rounded handle for a perfect grip.



### Sheath strippers


- Ergonomic "low-effort" push-button.
- Spare blade included in the body.
- Easily accessible thumbwheel adjustment.
- Self-pivoting blade.
- 985955 straight blade.
- 985956 hooked blade.

Capacity	∆∆	
∅ mm	g	
985951	16	65
985952	28	65
985953	35	65
985954	50	65
985955	28 LD	75
985956	28 LC	75



985951 - 985952 - 985953 - 985954 - 985955 - 985956

985951	①	①
985956	986061	

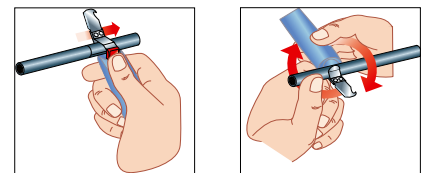

## ▶ Straight/helical sheath strippers

### Rotary sheath and insulation stripping tool

#### 985957

- Perfect for stripping long lengths.
- 2 stripping options :
  - Straight-line stripping.
  - Helical stripping by simply rotating the head.
- Capacity : 4.5 to 29 mm - L : 137 mm.

Capacity	L	∆∆	
∅ mm	mm	g	
985957	4,5 à 29	137	97

985957 - 985958

985957	①	①
	985959	

