

Bench Area Products, Flap Brushes, cont'd

### Scotch-Brite™ CPFB-R


Flaps of strong, durable cut and polish web, Roloc™ mounting system. Great for inside diameters and to create a uniform surface finish or blend surface imperfections.



UPC Number	ID	Grade	Size	Color	Desc	Case Qty	UOM
00-048011-14588-4	PF-ZR	AMED	3"x1-3/8"	Tan	MOS: 8,000 RPM	10	BH

### Scotch-Brite™ CPFB-S

Flaps of strong, durable cut and polish web on a 1/4" shank for portable tools. Excellent for inside diameters, to create a uniform surface finish or blend surface imperfections.

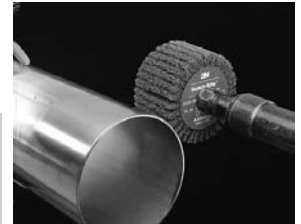

UPC Number	ID	Grade	Size	Color	Desc	Case Qty	UOM
00-048011-16622-3	PF-ZS	AMED	2"x1"x1/4"	Tan	MOS: 12,000 RPM	25	BH
00-048011-05974-7	PF-ZS	AMED	3"x1 3/4"x1/4"	Tan	MOS: 8,500 RPM	10	BH

### Scotch-Brite™ Finishing Flap Brush

Light duty for cleaning and finishing applications. Individual sheets adhered at a 90° angle to a steel core.



UPC Number	ID	Grade	Size	Color	Desc	Case Qty	UOM
00-048011-01179-0	CF-FB	5AFIN	8"x2"x3"	Maroon	MOS: 3,200 RPM	2	BH
00-048011-04325-8	CF-FB	3AFIN	12"x2"x5"	Maroon	MOS: 2,500 RPM	1	BH

Discs, Bristle Discs

### 3M™ Radial Bristle Disc

Durable radial plastic disc for thin coating removal. Leaves a fine satin finish. Gang multiple discs to form a brush. Fits portable hand tool or small bench motor.



UPC Number	ID	Grade	Size	Color	Desc	Case Qty	UOM
00-048011-27614-4	RB-ZB	120	9/16"x1/16"	White	MOS: 35,000 RPM	192	DC
00-048011-25755-6	RB-ZB	80	3/4"x1/16"	Yellow	MOS: 35,000 RPM	192	DC
00-048011-25757-0	RB-ZB	220	3/4"x1/16"	Red	MOS: 30,000 RPM	192	DC
00-048011-25758-7	RB-ZB	400	3/4"x1/16"	Blue	MOS: 35,000 RPM	192	DC
00-048011-25759-4	RB-ZB	Pumice	3/4"x1/16"	Pink	MOS: 35,000 RPM	192	DC
00-048011-27612-0	RB-ZB	80	1"x1/8"	Yellow	MOS: 35,000 RPM	96	DC
00-048011-24279-8	RB-ZB	50	3"x3/8"	Green	MOS: 25,000 RPM	40	DC