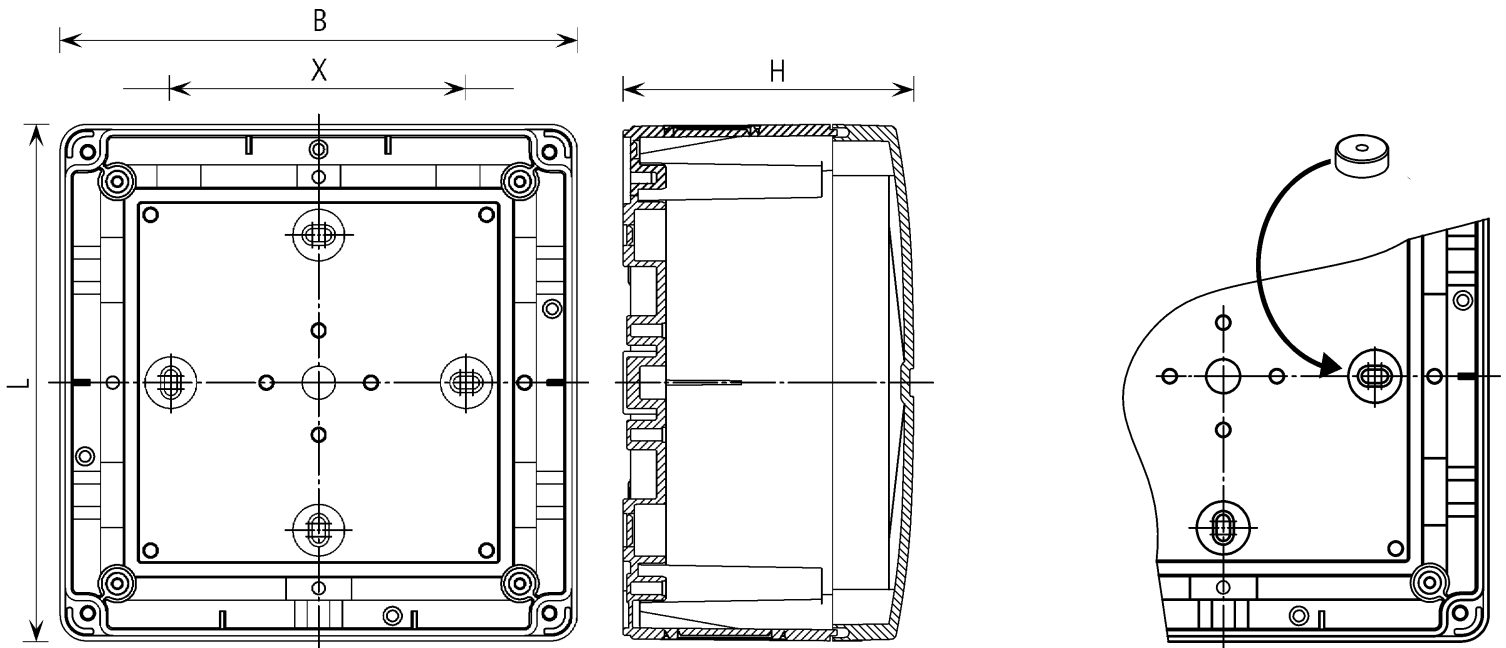
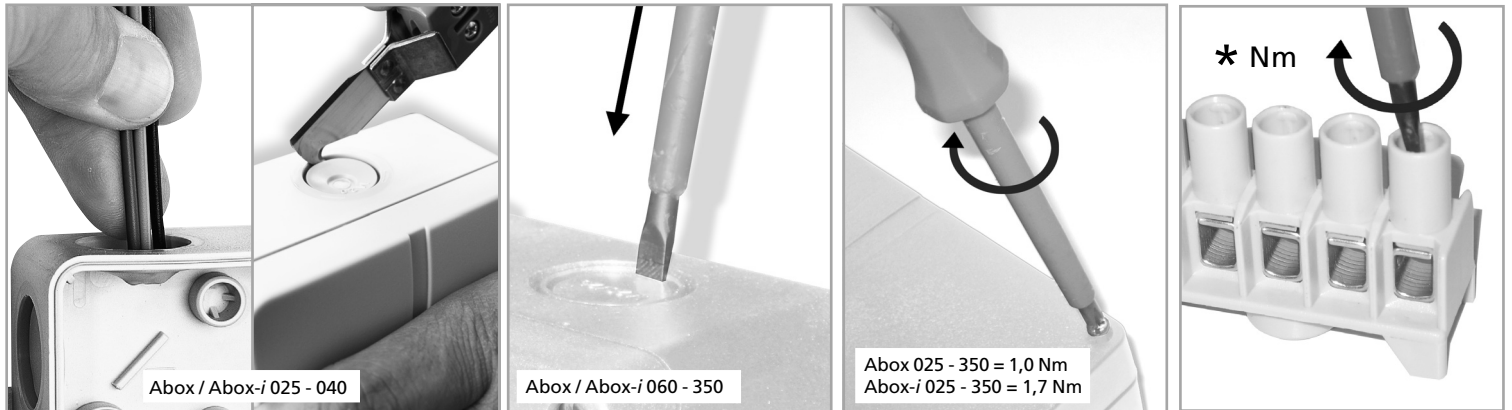

 


### Abox / Abox-i IP 54/65 - 690 V



Type Type Type Tipos	L	B	H	X			[mm <sup>2</sup> ]		
Abox 025-2,5 <sup>2</sup>	80	80	52	46	2,5/4 mm <sup>2</sup>	*1,2 Nm	4x1,5	4x2,5	4x4,0
Abox 040-4 <sup>2</sup>	93	93	55	59	4 mm <sup>2</sup>	*1,2 Nm	4x1,5	4x2,5	3x4
Abox 060-6 <sup>2</sup>	110	110	67	□50	6 mm <sup>2</sup>	*2,0 Nm	4x2,5	4x4	3x6
Abox 100-10 <sup>2</sup>	140	140	79	□80	10 mm <sup>2</sup>	*2,0 Nm	4x4	4x6	4x10
Abox 160-16 <sup>2</sup>	180	180	91	□120	16 mm <sup>2</sup>	*2,5 Nm	4x6	4x25	4x35
Abox 250-25 <sup>2</sup>	200	200	115	□184	25 mm <sup>2</sup>	*4,0 Nm	4x10	4x16	4x25
Abox 350-35 <sup>2</sup>	250	250	115	□184	35 mm <sup>2</sup>	*4,0 Nm	4x16	4x25	4x35