


## Terminals

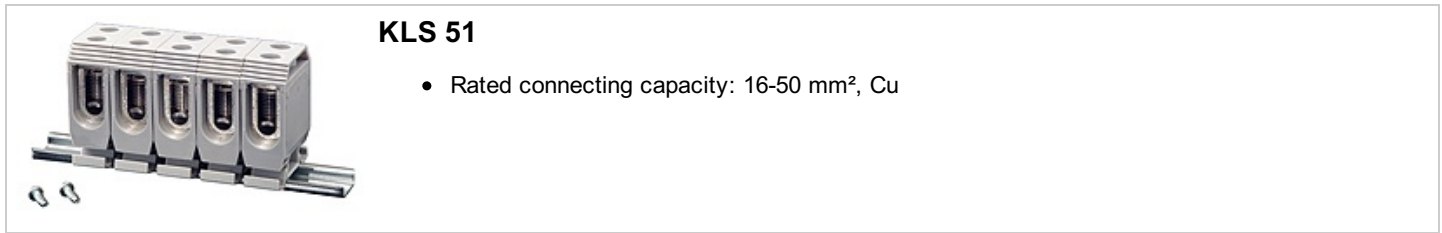

### KLS 51

- Rated connecting capacity: 16-50 mm<sup>2</sup>, Cu

- for insertion in cable junction boxes
- current carrying capacity: 150 A
- 5-pole per pole 6 x 16 mm<sup>2</sup> s, 4 x 25 mm<sup>2</sup> s, 4 x 35 mm<sup>2</sup> s, 4 x 50 mm<sup>2</sup> s
- for cable junction boxes K 9350, K 9500, K 8350, K 8500, KF 9350, KF 9500, KF 8350, KF 8500, KF 5350, KF 5500, KF 4350, KF 4500, KD 5350, KD 4350
- complete with fixing elements

rated insulation voltage	Ui = 690 V a.c./d.c.
Dismantling length	20 mm
tightening torque for terminal	12,0 Nm
Weight	1,141 kg

## Drawings

Dimension drawing

