

# TouchNTuff® 92-500 92-600 92-605

CHEMICAL & LIQUID PROTECTION



STYLE #	COATING MATERIAL	LINER MATERIAL	GRIP DESIGN	CUFF STYLE	COLOUR	AQL	POWDER-FREE	EN SIZE	LENGTH MM	THICKNESS MM	PACKAGING
92-500	Nitrile	N/A	Textured fingertips	Rolled beaded	Green	1.5	No	6½-7, 7½-8, 8½-9, 9½-10	240	0.12	100 gloves in a box, 10 boxes in a carton
92-600 ★	Nitrile	N/A	Smooth	Rolled beaded	Green	1.5	Yes	6½-7, 7½-8, 8½-9, 9½-10	240	0.12	100 gloves in a box, 10 boxes in a carton
92-605 ★	Nitrile	N/A	Textured fingertips	Rolled beaded	Green	1.5	Yes	6½-7, 7½-8, 8½-9, 9½-10	300	0.12	100 gloves in a box, 10 boxes in a carton



## Proven splash resistance against hazardous chemicals

### PRIMARY INDUSTRIES



### IDEAL APPLICATIONS


- Chemical handling
- Laboratory analysis
- Pharmaceuticals
- Paint and spray shops
- Printing industry
- Electronics
- Light assembly tasks
- Light assembly of oil-coated pieces
- Glass manufacturing
- Handling of cytostatics
- Intricate parts handling

### DESCRIPTION

- Further testing of the TouchNTuff® by a certified body on an even wider range of chemicals confirms that it resists a greater variety of industrial chemicals for longer periods than any other nitrile disposable gloves.
- Manufactured from nitrile, TouchNTuff® offers up to four times the puncture resistance of comparable natural-latex gloves, and three times the resistance of similar neoprene gloves.
- It contains no natural rubber proteins, which means no risk of Type I allergies for the wearer. Primary skin irritation studies and Insult Patch tests have also shown no evidence of risk from irritation or allergic contact dermatitis.
- With a unique "Thin Nitrile Technology" formulation, this glove offers easy donning and strong grip in wet or dry conditions.
- The glove is highly versatile and suitable for many different uses.

### REMARKS

- 92-600: Fit for special purpose
- TouchNTuff® is anti-staticity tested (EN 1149-1 & 1149-3) and meets the requirements defined in EN 1149-5

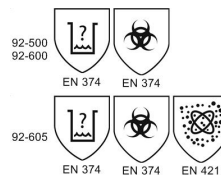

CATEGORY III

Print date: 18-09-2014

### Ansell Healthcare Europe N.V. (European Head Office)

Riverside Business Park, Block J  
 Boulevard International 55, 1070 Brussels, Belgium  
 Tel. +32 (0) 2 528 74 00 • Fax +32 (0) 2 528 74 01 • Fax Customer Service +32 (0) 2 528 74 03  
<http://www.ansell.eu> • E-mail [info@ansell.eu](mailto:info@ansell.eu)

