


F10-24-IP65 Series is a range of High Power IP65 Rated LED Flexible Strips suitable for domestic, commercial and retail internal lighting applications.

- Energy Saving
- Compact strip with SMD LED Technology
- Non yellowing, scratch resistant UV stable resin
- Water Resistant to IP65 level*
- 50k hours working life
- High Reliability & Efficiency
- 60 LEDs per metre
- Cuttable every 100mm
- 120° beam angle

Applications


- Accent Lighting
- Cabinet Lighting
- Mood Lighting
- Cove Lighting
- Under Cabinet Lighting
- Bookshelf Lighting
- Display Cabinet Lighting

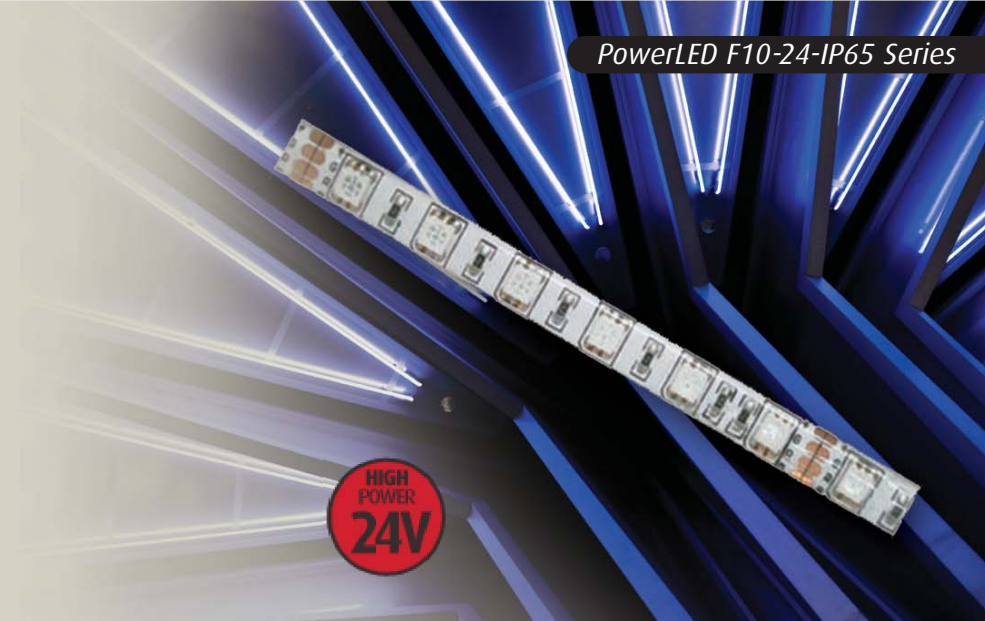

High Power IP65 Rated Energy Saving LED Flexi Strips

★ Flexi Strip Specification

Power	14.4W per metre
Input	24V
LEDs Per Meter	60
Cuttable Length	every 100mm
IP Rating	IP65
Cable Length	300mm

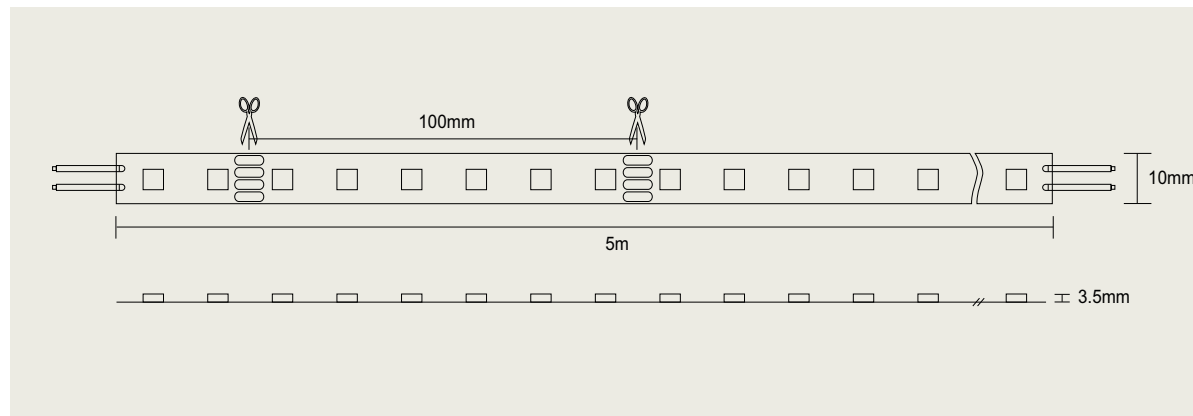


IP65



Part number	Strip Length	Lumens	Colour Temperature
F10-C5050-24-60-IP65	5 metres	1200LM	6000K (cool white)
F10-W5050-24-60-IP65	5 metres	1100LM	3000K (warm white)

*Product not fully IP65 Rated unless IP65 Rated connections & power supply used
Representative colours may change; purchase from the same batch code for colour consistency

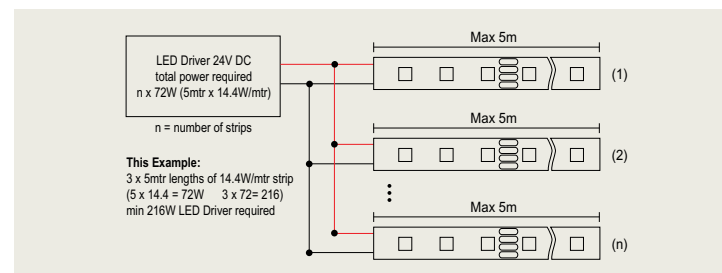

We recommend a maximum of 15mtrs strip per driver due to possible voltage drop