
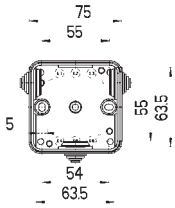


### HP 70

75 x 75 x 42 mm,  
internal dimension: 68 x 68 x 38 mm

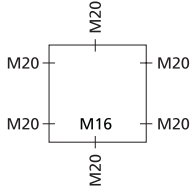

Description

Order No.

Packing Qty

Junction box acc. DIN EN 60670 (VDE 0606),  $U_i=400V$ ,  
3 recessed stepped nipples and two loose ones enclosed, seal range 5 - 16 mm,  
for terminals up to 2.5 mm<sup>2</sup>

IP55

2,5<sup>2</sup>

IK07



400V  
AC





**HP 70-L**  
grey, without terminals

320 970 01

60/1

### HP 80

85 x 85 x 42 mm  
internal dimension: 78 x 78 x 38 mm

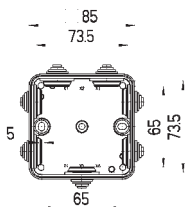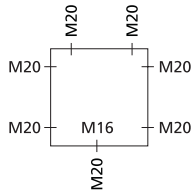

Junction box acc. DIN EN 60670 (VDE 0606),  $U_i=400V$ ,  
7 recessed stepped nipples, seal range 5 - 16 mm, for terminals up to 2.5 mm<sup>2</sup>

IP55

2,5<sup>2</sup>

IK07



400V  
AC



**HP 80-L**  
grey, without terminals

322 980 01

50/1