

Manual Tackers

STANLEY
FatMax

Easy squeeze:

For effortless
actuation

Anti jam:

For less downtime



Soft grip handle:
For grip and comfort

**Adjustable
power:** For selection
of staple depth

6 in 1: LD staples.
Crown staples. Brads
(with and without
heads)

4 IN 1 MANUAL TACKER

Features:

Stanley FatMax heavy-duty 6 in 1 stapler

Tacker is bottom loading

Low angle handle for easier use

Built in wire guide/staple window

An internal handle lock prevents accidental stapling

Fastener mode switch to change between different types of brad/pin/staple

Supplied with a variety of brads, pins and staples

Suitable for the following Staples , Nails and Pins

Type A 0-TRA200 series staples: 6mm - 14mm

Type G 1-TRR130 series staples: 6mm -14mm

Type H 1-TRA700 series staples: 6mm - 14mm

Type 7 1-CT100 series staples: 12mm - 14mm

Type J 0-SWKBN series brads: 15mm

Type 9 Pin Nails: 15mm

**Features:**

Heavy-duty stapler/nailer

Robust steel construction for a longer working life

Easy squeeze for easy actuation and an anti Jam feature

Fires Heavy duty Type G staples

Fires 1-SWKBN 18 GAUGE BRADS

STANLEY

Staplers / Staples

HD Steel Construction:
For a long working life

Easy squeeze:
For effortless actuation



HD Staples:
6 – 14mm Takes
staple range 6 to
14mm (1/4 to 9/16 in)



1-CT106T

10MM/3/8" CABLE STAPLES X1000 7CT100

1-CT107T

11MM/7/16" CABLE STAPLES X1000 7CT100

1-CT108T

12MM/1/2" CABLE STAPLES X1000 7CT100

1-CT109T

14MM/9/16" CABLE STAPLES X1000 7CT100



1-TRA704-5T
1-TRA705-5T
1-TRA706-5T
1-TRA708-5T
1-TRA709-5T
1-TRA704T
1-TRA705T
1-TRA706T
1-TRA708T
1-TRA709T

6MM/1/4" H/D STAPLES (X5000) G TYPE
8MM/5/16"H/D STAPLES (X5000) G TYPE
10MM/3/8" H/D STAPLES (X5000) G TYPE
12MM/1/2" H/D STAPLES (X5000) G TYPE
14MM/9/16"H/D STAPLES(5000) G TYP EU
6MM/1/4" H/D STAPLES(1,000) G TYPE
8MM/5/16" H/D STAPLES(1,000) G TYPE
10MM/3/8" H/D STAPLES(1000) G TYPE
12MM/1/2" H/D STAPLES(1,000) G TYPE
14MM/9/16"H/D STAPLES(1,000) G TYPE



FMHT0-70411

Light duty 4 in 1 stapler fire cable tacks, light duty staples,
both headless and standard brads

Easy squeeze

Fires 1-TRA200 series light duty staples 4-14mm

Fires 1-CT100 series round staples

Fires 1-SWKBN 18 gauge brads 12-15mm

With anti jam


STANLEY



STHT0-70410

Robust steel construction
Easy squeeze
Fires 1-TRA200 series light duty staples 4-14mm
Fires 1-SWKBN 18 gauge brads 12-15mm
With anti jam

STANLEY

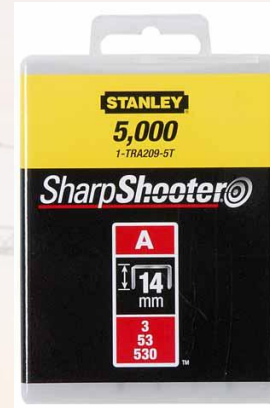

1-TRA209T
1-TRA209-5T
1-TRA208-5T
1-TRA206T
1-TRA206-5T
1-TRA205T
1-TRA205-5T
1-TRA204T
1-TRA204-5T

14MM/9/16"L/D STAPLE(1000) A TYPE
14MM/9/16"L/DUTY STAPL(5000)A TYP EU
12MM/1/2"L/DUTY STAPL(5000) A TYP EU
10MM/3/8"L/D STAPLES(1,000) A TYPE
10MM/3/8"L/DUTY STAPL(5000) A TYP EU
8MM/5/16" L/D STAPLES(1,000) A TYPE
8MM/5/16"L/DUTY STAPL(5000) A TYP EU
6MM/1/4" L/D STAPLES(1,000) A TYPE
6MM/1/4"L/DUTY STAPLE(5000) A TYP EU

STANLEY



1-CT305T
1-CT306T
1-CT308T

FLAT NARROW CROWN STAPLES 8 MM
FLAT NARROW CROWN STAPLES 10 MM
FLAT NARROW CROWN STAPLES 12 MM