


DYMO

LabelWriter™

4XL

High-Speed, Wide-Format Label Printer for Heavy-Duty Use

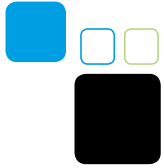

High-volume, low total-cost-of-ownership label printing – at speeds up to 2 labels per second!

The DYMO® LabelWriter™ 4XL is the only label printer that uses new DYMO® High Capacity Labels – labels mounted sideways to fit up to 3 times the labels per roll, for fewer roll changes, our fastest print speeds, and our lowest per-label printing costs.

LabelWriter™ 4XL with High Capacity Labels:


- 1. Up to 1050 labels per roll***
Work longer between roll changes for fewer interruptions, maximum productivity
- 2. Print up to 129 labels per minute!****
Save time on every job, every day with DYMO's fastest print speeds – as fast as 2 labels per second!
- 3. Small footprint label printer**
Compact (17.18 cm W x 18.5 cm D x 13.4 cm H) printer size and sleek design fits any office or work environment.

* When compared to standard 99010 LabelWriter™ Address Labels and 99014 LabelWriter™ Shipping Labels

** 4-line address on high capacity labels




Only the DYMO LabelWriter™ 4XL label printer uses new DYMO® High Capacity Labels

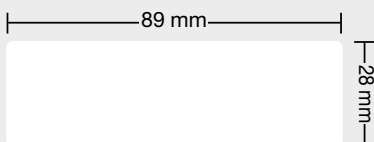

High Capacity 89 mm x 28 mm Labels

Permanent adhesive, white paper, 1050/Roll, 2 rolls/box

| Item No. | Description |
|----------|------------------------------|
| S0947410 | High Capacity Address Labels |

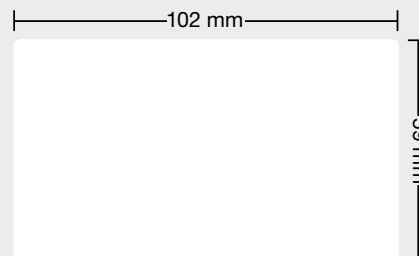

High Capacity 102 mm x 59 mm Labels

Permanent adhesive, white paper, 575/Roll, 2 rolls/box

| Item No. | Description |
|----------|-------------------------------------|
| S0947420 | High Capacity Large Shipping Labels |

LabelWriter™ 4XL Printer Features:

- 1 Prints labels up to 106 mm wide
- 2 Prints all DYMO® LabelWriter™ labels – 21+ sizes and styles in all
- 3 Print speeds up to 129 labels per minute* or 81 mm per second
- 4 300 dpi resolution for precise barcodes and clear, legible text and graphics
- 5 Uses thermal printing technology – never needs ink or toner
- 6 Connects via USB (cable included)
- 7 Share easily using Windows or Mac® printer sharing, or with the optional DYMO® LabelWriter™ Print Server
- 8 Includes drivers for Windows, Windows Vista®, Windows® 7 and Mac OS® v10.3.9 or later

* 4-line address on high capacity labels


 





DYMO Software Development Kit (SDK) Resources that simplify integration of DYMO® technology

Whether you're developing for Windows, Mac®, Linux® or a custom embedded system, you'll find the SDK you need to integrate LabelWriter™ label printing technology into your product. Visit www.dymo.com/var.



Designed for use with original DYMO® Labels

| Name | Code | Description | Material | Size (W x H) | Rolls per Box | Labels on Roll | Glue Type |
|--|--------------------------------------|---|---|--|---------------|------------------|-------------------------------|
| Shipping Labels  | S0722430 (99014) | Shipping/ Name badge labels | White paper | 54 mm x 101 mm | 1 | 220 | Permanent |
| | S0904980 S0947420 NEW | Extra large shipping labels High capacity large shipping labels | White paper White paper | 104 mm x 159 mm 102 mm x 59 mm | 1 2 | 220 575 | Permanent Permanent |
| Address Labels  | S0722370 (99010) | Address labels | White paper | 28 mm x 89 mm | 2 | 130 | Permanent |
| | S0722400 (99012) | Large address labels | White paper | 36 mm x 89 mm | 2 | 260 | Permanent |
| | S0722410 (99013) | Large address labels | Transparent plastic | 37 mm x 89 mm | 1 | 260 | Permanent |
| | S0722520 (11352) S0722380 (99011) | Large return address labels Assorted colour labels | White paper Yellow, blue, pink and green paper | 25 mm x 54 mm 28 mm x 89 mm | 1 4 x 1 | 500 130 | Permanent Permanent |
| S0947410 NEW | High capacity address labels | White paper | 89 mm x 28 mm | 2 | 1050 | Permanent | |
| Filing and Media Storage Labels  | S0722460 (99017) | Suspension file labels | White paper | 12 mm x 50 mm | 1 | 220 | Permanent |
| | S0722470 | Lever arch labels, small | White paper | 38 mm x 190 mm | 1 | 110 | Permanent |
| | S0722480 | Lever arch labels, large | White paper | 59 mm x 190 mm | 1 | 110 | Permanent |
| | S0719250 (14681) | CD/DVD labels (white) | White paper | Ø 57 mm | 1 | 160 | Permanent |
| Multipurpose Labels  | S0722440 (99015) | Large multipurpose labels | White paper | 54 mm x 70 mm | 1 | 320 | Permanent |
| | S0722530 (11353) | Multipurpose labels | White paper | 13 mm x 25 mm | 1 | 1000 | Removable |
| | S0929120 | Square multipurpose labels | White paper | 25 mm x 25 mm | 1 | 750 | Removable |
| | S0722540 (11354) | Multipurpose labels | White paper | 32 mm x 57 mm | 1 | 1000 | Removable |
| | S0722550 (11355) | Multipurpose labels | White paper | 19 mm x 51 mm | 1 | 500 | Removable |
| Name Badge Labels  | S0722560 (11356) | Small name badge labels | White paper | 41 mm x 89 mm | 1 | 300 | Removable |
| | S0929100 | Appointment/Name badge cards | White card | 51 mm x 89 mm | 1 | 300 | Non-Adhesive |
| | S0929110 | Large name badge cards | White card | 62 mm x 106 mm | 1 | 250 | Non-Adhesive |

DYMO

NewellRubbermaid
Brands That Matter