

---

## 64193

OSRAM ORIGINAL LINE | Halogen headlight lamps for cars



---

### Areas of application

- Headlight

---

### Product benefits

- OEM Quality
- Wide product range
- Reliable quality

---

### Product features

- Original spare parts

# Product datasheet

## Technical data

### Electrical data


Power input	75 / 68 W <sup>1)</sup>
Nominal wattage	60.0 W
Nominal voltage	12.0 V
Test voltage	13.2 V

<sup>1)</sup> Maximum

### Photometrical data

Luminous flux	1650/1000 lm
Luminous flux tolerance	±12 / ±15 %

### Dimensions & weight

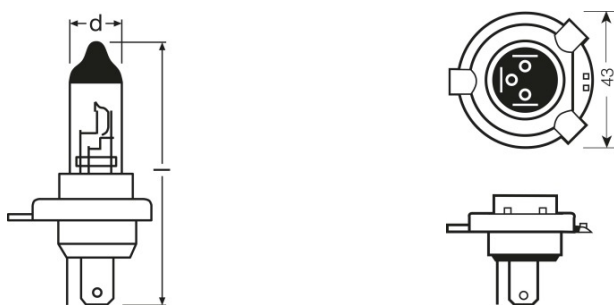

Length	82.0 mm
Diameter	17.0 mm

### Lifespan

Lifespan B3	250 / 400 h <sup>1)</sup>
Lifespan Tc	500 / 900 h <sup>1)</sup>

<sup>1)</sup> Filament 1 / Filament 2

### Additional product data

Base (standard designation)	P43t
-----------------------------	------

### Certificates & standards

ECE category	H4
--------------	----

### Country specific categorizations

## Product datasheet

<b>Order reference</b>	64193 60/55W 12
------------------------	-----------------

---

### Country specific information

<b>Product code</b>	<b>METEL code</b>	<b>SEG number</b>	<b>STK number</b>	<b>UK Org</b>
4050300001470	OSRA64193	8328048	8328048	-
4050300925127	OSRA64193BL1	8328396	8328396	-

## Product datasheet

### Logistical Data

Product code	Product description	Packaging unit (Pieces/Unit)	Dimensions (length x width x height)	Volume	Gross weight
4050300001470	64193	Folding carton box 1	71 mm x 47 mm x 47 mm	0.16 dm <sup>3</sup>	33.80 g
4050300212067	64193	Bundle 10	98 mm x 71 mm x 240 mm	1.67 dm <sup>3</sup>	338.00 g
4050300212074	64193	Shipping carton box 100	485 mm x 160 mm x 250 mm	19.40 dm <sup>3</sup>	5240.17 g
4050300925127	64193	Blister 1	135 mm x 66 mm x 81 mm	0.72 dm <sup>3</sup>	36.80 g
4008321142191	64193	Shipping carton box 10	335 mm x 147 mm x 117 mm	5.76 dm <sup>3</sup>	468.00 g
4052899056770	64193	Folding carton box 1	47 mm x 47 mm x 70 mm	0.15 dm <sup>3</sup>	30.60 g
4052899056787	64193	Bundle 10	- x - x -		
4052899056794	64193	Shipping carton box 100	485 mm x 245 mm x 156 mm	18.54 dm <sup>3</sup>	3530.00 g

The mentioned product code describes the smallest quantity unit which can be ordered. One shipping unit can contain one or more single products. When placing an order, for the quantity please enter single or multiples of a shipping unit.

### Disclaimer

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.