

RATCHETING SCREWDRIVERS

RATCHETING SCREWDRIVER

- Ratcheting bit holder screwdriver 1/4"
- Handle: 3-component handle with textured finish for maximum torque and minimum effort
- Interchangeable bit storage compartment with release button for quick access
- Slide tray that stores 6 different bits in a handy and secure way: PH 1, PH 2, PZ 1, PZ 2, slotted 4,5 and 5,5
- Magnetic blade secures the bit in the screwdriver and makes bit changing easy

• 808050



PISTOL HANDLE SCREWDRIVER

- Handle swivels and locks at 30° position for application of higher torque when necessary. This is especially important in work areas where there is little room to twist the screwdriver and the user's hand
- Locks at 180° for normal operation

• 808050P



LED LIGHT RATCHETING SCREWDRIVER

- Long-lasting LED lights mounted in front casing provide illumination in dark conditions

 
• 808050L



Model	Barcode	Qty	Bit Size	Length (mm)	Weight (g)
808050	3017642	1	1/4"	125	230
808050P	0128105	1	1/4"	135	270
808050L	0128075	1	1/4"	135	215
808050L-SP1	0129218	1	spare led panel + 3 batteries AG-3, 4.5V		

STUBBY RATCHETING SCREWDRIVER

- Stubby ratcheting 1/4" bit holder, bits and sockets set
- Lightweight case with rounded corners
- Detachable square driver blade
- Available in a 18 pieces and 22 pieces set



Model	Barcode	Qty	Dimensions (mm)	Weight (g)
808050S-18	0128921	1	195x130x46	530
808050S-22	0128938	1	195x130x46	530



www.bahco.com



SNA Europe MRO-1100-INT
Bahco is a registered trademark of SNA Europe Group

WE ARE INNOVATORS

BAHCO INNOVATES - INSULATED, RATCHETING AND INTERCHANGEABLE IN ONE TOOL!

BAHCO
INSULATED
RATCHETING
SCREWDRIVER



www.bahco.com

INSULATED, RATCHETING AND INTERCHANGEABLE IN ONE TOOL!




INSULATED

The 808060 is certified according IEC 6090 and is suited for working on live equipment



RATCHETING

The 808060 has a 48 tooth non-conductive ratcheting mechanism

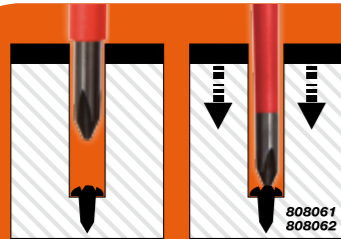

SLIM BLADES

The blades are 30% slimmer than regular insulated blades for better accessibility (e.g. sunken screws and spring elements)



INTERCHANGEABLE BLADES

Patented **blade release system** to easily and safely change blades without the blade falling out

SPARE BLADES & LOOSE HANDLE

- Single handle and blades are available as spare parts




DESCRIPTION	EAN	UNITS	LENGTH (mm)
808060 Handle	7314150243822	1	180
8610SL-2P PH1	7314150243891	2	100
8620SL-2P PZ1	7314150243907	2	100
8810SL-2P PH2	7314150243914	2	100
8820SL-2P PZ2	7314150243921	2	100
8010SL-2P 0,4 x 2,5	7314150243853	2	100
8220SL-2P 0,5 x 3,0	7314150243860	2	100
8040SL-2P 0,8 x 4,0	7314150243877	2	100
8050SL-2P 1 x 5,5	7314150243884	2	100
8910SL-2P T10	7314150243938	2	100
8915SL-2P T15	7314150243945	2	100
8920SL-2P T20	7314150243952	2	100
8925SL-2P T25	7314150243969	2	100
8930SL-2P T30	7314150243976	2	100
8510SL-2P combi-tip PH1/5.0x100	7314150245758	2	100
8520SL-2P combi-tip PH2/6.0x100	7314150245765	2	100
8710SL-2P combi-tip PZ1/5.0x100	7314150245772	2	100
8720SL-2P combi-tip PZ2/6.0x100	7314150245789	2	100

NOT JUST A RATCHETING SCREWDRIVER!

The 808060 is an insulated ratcheting screwdriver combined with interchangeable slim blades, a revolutionary new innovation by Bahco. With this innovation Bahco combines all advantages in one ultimate tool, made in one of Bahco's own factories in Europe.

The **blade release system** built in the comfortable handle makes it easy and safe to change the slim blades without the blades falling out. The blades are 30% slimmer than the blade of a regular insulated screwdriver for better accessibility and more applications (e.g. sunken screws and spring elements). **A must have tool for electricians.**

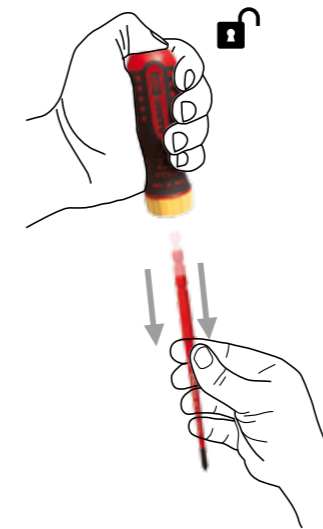

SCREWDRIVER WITH INTERCHANGEABLE BLADES

- Insulated handle with interchangeable blades in set
- For working on live equipment up to 1000 volts
- Complete with roll up pouch with clear 1000V indication
- IEC 60900 compliant

DESCRIPTION	CONTENTS
808061 6 blades set in a nylon pouch	PH1, PH2, 0.4x2.5, 0.5x3.0, 0.8x4.0, 1.0x5.5, handle
808062 6 blades set in a nylon pouch	PZ1, PZ2, 0.4x2.5, 0.5x3.0, 0.8x4.0, 1.0x5.5, handle