

Changeover Switch with Centre Off - 2, 3 & 4 Pole 16A - 160A



Insulated



- IP66/67 protection.
- auxiliary contacts provided with 3 & 4 pole switches.
- black handle, padlockable in Off position.
- earth terminal.
- insulated enclosed, grey, RAL7035.
- switch interlocked with lid to prevent opening in 'ON' position.

le AC-21A	2 Pole		Encl. Ref	Price (£)
16A	KH16	T902/GBA002 *KS52	KSA	35.79
20A	KH20	T902/GBA002 *KS52	KSA	37.97
25A	KH25	T902/GBA002 *KS52	KSA	42.61
32A	KH32	T902/GBA002 *KL12	KLC	59.64
40A	KH40	T902/GBA002 *KL12	KLC	64.31
63A	KH63	T902/GBA002 *KL72	KLE	95.47
80A	KH80	T902/GBA002 *KL72	KLE	109.11
100A	KH85	T902/GBA012 *KL72	KLE	165.58
125A				
125A ³⁾				
160A				

Mild Steel



- IP66 protection.
- auxiliary contacts provided with 3 & 4 pole switches.
- black handle, padlockable in Off position.
- earth terminal & lid bonding link included.
- grey powder paint finish, colour RAL7032 (also available in red powder paint finish, colour RAL3000).
- switch interlocked with lid to prevent opening in 'ON' position.

le AC-21A	2 Pole		Encl. Ref	Price (£)
16A	KH16	T902/GBA020 *MB2	MB2	89.93
20A	KH20	T902/GBA020 *MB2	MB2	93.11
25A	KH25	T902/GBA020 *MB2	MB2	97.70
32A	KH32	T902/GBA020 *MB2	MB2	107.92
40A	KH40	T902/GBA020 *MB2	MB2	113.21
63A	KH63	T902/GBA020 *MB3	MB3	148.09
80A	KH80	T902/GBA020 *MB3	MB3	189.54
100A	KH85	T902/GBA020 *MB3	MB3	214.73
125A				
125A ³⁾				
160A				

Stainless Steel



- IP66 protection.
- auxiliary contacts provided with 3 & 4 pole switches.
- black handle, padlockable in Off position.
- earth terminal & lid bonding link included.
- bright stainless steel enclosure, grade 316L.
- switch interlocked with lid to prevent opening in 'ON' position.

le AC-21A	2 Pole		Encl. Ref	Price (£)
16A	KH16	T902/GBA025 *SB2	SB2	158.27
20A	KH20	T902/GBA025 *SB2	SB2	161.44
25A	KH25	T902/GBA025 *SB2	SB2	166.03
32A	KH32	T902/GBA025 *SB2	SB2	176.15
40A	KH40	T902/GBA025 *SB2	SB2	207.48
63A	KH63	T902/GBA025 *SB3	SB3	232.73
80A	KH80	T902/GBA025 *SB3	SB3	274.19
100A	KH85	T902/GBA025 *SB3	SB3	318.58
125A				
125A ³⁾				
160A				


Notes

1) 2-off electrical isolated, early break, auxiliary contacts are provided with the 3 & 4 pole switches. One of these contacts closes in pos'n 1 and the other contact closes in pos'n 2. Both of the contacts are open in the Off pos'n.

2) Switched neutral pole is early make / late break.

3) KG125 suitable for applications requiring larger cable termination and increased enclosure size.

LOAD SWITCH - Changeover Switch with Centre Off - 4 Pole 32A - 315A

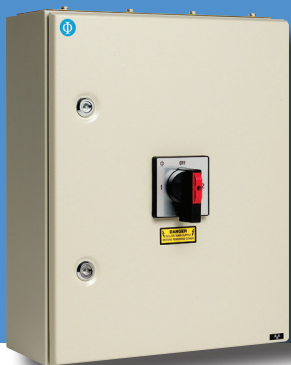

- IP66 protection.
- black handle, padlockable in Off position.
- earth terminal & lid bonding link included.
- grey powder paint finish, colour RAL7032 (also available in red powder finish, colour RAL3000).
- switch interlocked with lid to prevent opening in 'ON' position.

le AC-21A	Order Code No.		Encl. Ref	Price (£)
4 Pole				
32A	CA25	A213/GBA009 *MB20	MB20	159.90
40A	C32	A213/GBA009 *MB20	MB20	217.22
63A	C42	A213/GBA009 *MB20	MB20	238.69
100A	C80	A213/GBA009 *MB22	MB22	428.43
150A	C125	A213/GBA009 *MB22	MB22	575.81
200A	C200-4	A213/GBA002 *MB10	MB10	778.64
275A	C315	A213/GBA002 *MB10	MB10	942.37
315A	C315	A213/GBA010 *MB29	MB29	1248.76