

**SAK Series**  
**EK 2.5/35**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 16  
 D-32758 Detmold  
 Germany  
 Fon: +49 5231 1429-0  
 Fax: +49 5231 14292083  
 www.weidmueller.com


**Klippon® Connect with clamping yoke Technology**

The high reliability and variety of designs of the terminal blocks with clamping yoke connections make planning easier and optimises operational safety. Klippon® Connect provides a proven response to a range of different requirements.

**General ordering data**

Type	EK 2.5/35
Order No.	<a href="#">0661060000</a>
Version	SAK Series, PE terminal, Rated cross-section: 2.5 mm <sup>2</sup> , Screw connection, green / yellow, Direct mounting
GTIN (EAN)	4008190135287
Qty.	100 pc(s).

**SAK Series  
EK 2.5/35**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 16  
 D-32758 Detmold  
 Germany  
 Fon: +49 5231 1429-0  
 Fax: +49 5231 14292083  
 www.weidmueller.com

**Technical data**
**Dimensions and weights**

Depth	40 mm	Depth (inches)	1.575 inch
Net weight	18.96 g		

**Temperatures**

Continuous operating temp., min.	-50 °C	Continuous operating temp., max.	100 °C
----------------------------------	--------	----------------------------------	--------

**Material data**

Material	PA 66	Colour	Yellow, Green
UL 94 flammability rating	V-2		

**System specifications**

Version	Screw connection, With PE connection, closed	End cover plate required	No
Number of potentials	1	Number of levels	1
No. of clamping points per level	2	Number of potentials per tier	1
Levels cross-connected internally	No	PE connection	Yes
Mounting rail	TS 35	N-function	No
PE function	Yes	PEN function	No

**Additional technical data**

Explosion-tested version	Yes	Installation advice	Direct mounting
Number of similar terminals	1	Open sides	closed
Type of mounting	Screwed		

**CSA rating data**

Certificate No. (CSA)	12400-127	Current size C (CSA)	25 A
Voltage size C (CSA)	600 V	Wire cross section max. (CSA)	12 AWG
Wire cross section min. (CSA)	26 AWG		

**Conductors for clamping (additional connection)**

Conductor cross-section, flexible plus plastic collar DIN 46228/1, further connection, max.	2.5 mm <sup>2</sup>
---------------------------------------------------------------------------------------------	---------------------

**SAK Series  
EK 2.5/35**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 16  
 D-32758 Detmold  
 Germany  
 Fon: +49 5231 1429-0  
 Fax: +49 5231 14292083  
 www.weidmueller.com

**Technical data****Conductors for clamping (rated connection)**

Blade size	0.6 x 3.5 mm	Clamping range, rated connection, max.	6 mm <sup>2</sup>
Clamping range, rated connection, min.	0.33 mm <sup>2</sup>	Clamping screw	M 2.5
Connection direction	on side	Gauge to IEC 60947-1	A3
Number of connections	2	Stripping length	10 mm
Tightening torque, max.	0.6 Nm	Tightening torque, min.	0.4 Nm
Type of connection	Screw connection	Wire connection cross section AWG, max.	AWG 14
Wire connection cross section AWG, min.	AWG 22	Wire connection cross section, finely stranded with wire-end ferrules DIN 46228/1, rated connection, max.	2.5 mm <sup>2</sup>
Wire connection cross section, finely stranded with wire-end ferrules DIN 46228/1, rated connection, min.	0.5 mm <sup>2</sup>	Wire connection cross section, finely stranded, max.	4 mm <sup>2</sup>
Wire connection cross section, solid core max. rated connection	6 mm <sup>2</sup>	Wire connection cross section, solid core, min. rated connection	0.5 mm <sup>2</sup>
Wire connection cross section, stranded, rated connection, max.	4 mm <sup>2</sup>	Wire connection cross section, stranded, rated connection, min.	0.5 mm <sup>2</sup>
Wire connection cross-section, finely stranded, min.	0.5 mm <sup>2</sup>		

**PE rating data**

Rated short-time current	480 A (4 mm <sup>2</sup> )	Centre screw on PE terminals	M 2.5
Tightening torque range for fixing screw	0.4...0.6 Nm	PEN function	No

**Rating data**

Rated cross-section	2.5 mm <sup>2</sup>	Rated voltage to adjoining terminal	800 V
Standards	IEC 60947-7-2	Volume resistance according to IEC 60947-7-x	1.33 mΩ
Rated impulse withstand voltage to adjacent terminal	8 kV	Pollution severity	3

**UL rating data**

Certificate No. (UR)	E60693	Conductor size Factory wiring max. (UR)	12 AWG
Conductor size Factory wiring min. (UR)	26 AWG	Conductor size Field wiring max. (UR)	12 AWG
Conductor size Field wiring min. (UR)	22 AWG		

**Classifications**

ETIM 3.0	EC000901	ETIM 4.0	EC000491
ETIM 5.0	EC000491	ETIM 6.0	EC000901
UNSPSC	30-21-18-11	eClass 5.1	27-14-03-05
eClass 6.2	27-14-03-05	eClass 7.1	27-14-03-05
eClass 8.1	27-14-11-41	eClass 9.0	27-14-11-41
eClass 9.1	27-14-11-41		

**Approvals**

Approvals



ROHS

Conform

Creation date March 13, 2017 1:32:10 PM CET

Catalogue status 10.02.2017 / We reserve the right to make technical changes.

3

**Data sheet****SAK Series  
EK 2.5/35**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 16  
D-32758 Detmold  
Germany  
Fon: +49 5231 1429-0  
Fax: +49 5231 14292083  
www.weidmueller.com

**Technical data****Downloads**

---

Engineering data	<a href="#">EPLAN, WSCAD</a>
Declaration of Conformity	<a href="#">DE_PT1302_20160418_173_ISSUE01.pdf</a>
STEP	<a href="#">0661060000_07305_EK_2.5-35_STP.stp</a>

---

## SAK Series EK 2.5/35

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 16  
 D-32758 Detmold  
 Germany  
 Fon: +49 5231 1429-0  
 Fax: +49 5231 14292083  
 www.weidmueller.com

# Accessories

## QL / SAK 4



### Klippon® Connect with clamping yoke Technology

The high reliability and variety of designs of the terminal blocks with clamping yoke connections make planning easier and optimises operational safety. Klippon® Connect provides a proven response to a range of different requirements.

### General ordering data

Type	Order No.	Version	GTIN (EAN)	Qty.
QL 3 SAK4	<a href="#">0130700000</a>	SAK Series, Cross-connector, for cross-connection link, No. of poles: 3	4008190085117	100 pc(s).
QL 2 SAK4	<a href="#">0130600000</a>	SAK Series, Cross-connector, for cross-connection link, No. of poles: 2	4008190077372	100 pc(s).
QL 10 SAK4	<a href="#">0338200000</a>	SAK Series, Cross-connector, for cross-connection link, No. of poles: 10	4008190107413	20 pc(s).
QL 4 SAK4	<a href="#">0130800000</a>	SAK Series, Cross-connector, for cross-connection link, No. of poles: 4	4008190173715	50 pc(s).

## Blank



The Dekafix (DEK) marker is the universal marker for all conductor and plug-in connectors as well as for electronic sub-assemblies. The system is ideal for short number sequences and covers a wide range of ready-printed markers.

Strips for fast installation in only one work step. The printing is easy to read, rich in contrast and available in various widths.

- Large range of ready-to-use markers
- Strips for fast installation
- Terminal markers, suitable for all Weidmüller cable connectors
- Available as blank MultiCard or with standard printing

### General ordering data

Type	Order No.	Version	GTIN (EAN)	Qty.
DEK 5/6 MC NE BR	<a href="#">1454900000</a>	Dekafix, Terminal marker, 5 x 6 mm, Pitch in mm (P): 6.00 Weidmueller, Brown	4050118323313	1,000 pc(s).


## SAK Series EK 2.5/35

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 16  
 D-32758 Detmold  
 Germany  
 Fon: +49 5231 1429-0  
 Fax: +49 5231 14292083  
 www.weidmueller.com

## Accessories

DEK 5/6 MC <a href="#">1238310000</a> NE GN	Dekafix, Terminal marker, 4050118271812 1,000 pc(s). 5 x 6 mm, Pitch in mm (P): 6.00 Weidmueller, Green
DEK 5/6 MC <a href="#">1238290000</a> NE BL	Dekafix, Terminal marker, 4050118267327 1,000 pc(s). 5 x 6 mm, Pitch in mm (P): 6.00 Weidmueller, Blue
2014-12-31T00:00:00+01:00 OR	<a href="#">1912090000</a> Dekafix, Terminal marker, 4032248540525 1,000 pc(s). 5 x 6 mm, Pitch in mm (P): 6.00 Weidmueller, Orange
DEK 5/6 MC <a href="#">1238280000</a> NE GE	Dekafix, Terminal marker, 4050118038750 1,000 pc(s). 5 x 6 mm, Pitch in mm (P): 6.00 Weidmueller, Yellow
Discontinued 2013-04-01T00:00:00+02:00	DEK 5/6 MC V0 MC NE <a href="#">1789590000</a> Dekafix, Terminal marker, 4032248210923 1,000 pc(s). 5 x 6 mm, Pitch in mm (P): 6.00 Weidmueller, White
DEK 5/6 MC <a href="#">1609820000</a> NE WS	Dekafix, Terminal marker, 4008190203436 1,000 pc(s). 5 x 6 mm, Pitch in mm (P): 6.00 Weidmueller, White
DEK 5/6 MC <a href="#">1238330000</a> NE GR	Dekafix, Terminal marker, 4050118323306 1,000 pc(s). 5 x 6 mm, Pitch in mm (P): 6.00 Weidmueller, Grey

## Custom printing

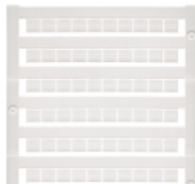

The Dekafix (DEK) marker is the universal marker for all conductor and plug-in connectors as well as for electronic sub-assemblies. The system is ideal for short number sequences and covers a wide range of ready-printed markers.

Strips for fast installation in only one work step. The printing is easy to read, rich in contrast and available in various widths.

- Large range of ready-to-use markers
- Strips for fast installation
- Terminal markers, suitable for all Weidmüller cable connectors
- Available as blank MultiCard or with standard printing

## General ordering data


Type	Order No.	Version	GTIN (EAN)	Qty.
DEK 5/6 MC SDR	<a href="#">1609830000</a>	Dekafix, Terminal marker, 5 x 6 mm, Pitch in mm (P): 6.00 Weidmueller, To customer specification	4008190456603	200 pc(s).
DEK 5/6 PLUS MC SDR	<a href="#">1038650000</a>	Dekafix, Terminal marker, 5 x 6 mm, Pitch in mm (P): 6.00 Weidmueller, To customer specification	4032248767908	200 pc(s).

## SAK Series EK 2.5/35

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 16  
 D-32758 Detmold  
 Germany  
 Fon: +49 5231 1429-0  
 Fax: +49 5231 14292083  
 www.weidmueller.com

# Accessories

## Bus bars

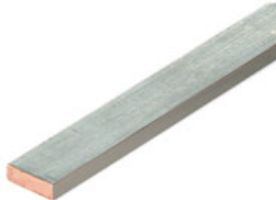

### Building installation wiring

For building installations, we offer a complete system that revolves around the 10×3 copper rail and comprises perfectly coordinated components: from installation terminal blocks, neutral conductor terminal blocks and distribution terminal blocks to comprehensive accessories such as busbars and busbar holders.

### General ordering data

Type	Order No.	Version	GTIN (EAN)	Qty.
SSCH 10X3X1000 MS/BK	<a href="#">0259800000</a>	Accessories, Busbar, Brass, 1000 mm	4008190049300	1 m
SSCH 7.3X1.2X1000	<a href="#">1071200000</a>	Accessories, Busbar, Copper, 1000 mm	4008190279172	1 m
SSCH 6X6X1000 CU/SN	<a href="#">0571300000</a>	Accessories, Busbar, Copper, 1000 mm	4008190015039	1 m
NSCH 1M	<a href="#">0280200000</a>	Accessories, Busbar, Copper, 1000 mm	4008190012953	1 m
ESCH 1 M	<a href="#">0280300000</a>	Accessories, Busbar, Steel, 1000 mm	4008190143053	1 m
SSCH 10X3X1000 CU/SN	<a href="#">0348900000</a>	Accessories, Busbar, Copper, 1000 mm	4008190024802	1 m
SSCH 15X6X1000 CU/SN	<a href="#">0357400000</a>	Accessories, Busbar, Copper, 1000 mm	4008190169572	1 m

**SAK Series  
EK 2.5/35**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 16  
D-32758 Detmold  
Germany  
Fon: +49 5231 1429-0  
Fax: +49 5231 14292083  
www.weidmueller.com

**Accessories**

**Blank**



The Dekafix (DEK) marker is the universal marker for all conductor and plug-in connectors as well as for electronic sub-assemblies. The system is ideal for short number sequences and covers a wide range of ready-printed markers.

Strips for fast installation in only one work step. The printing is easy to read, rich in contrast and available in various widths.

- Large range of ready-to-use markers
- Strips for fast installation
- Terminal markers, suitable for all Weidmüller cable connectors
- Available as blank MultiCard or with standard printing

**General ordering data**

Type	Order No.	Version	GTIN (EAN)	Qty.
DEK 5/6.5 MC	<a href="#">1609840000</a>	Dekafix, Terminal marker, 5	4008190203429	900 pc(s).
NE WS		x 6.5 mm, Pitch in mm (P): 6.50 Weidmueller, White		

**Custom printing**



The Dekafix (DEK) marker is the universal marker for all conductor and plug-in connectors as well as for electronic sub-assemblies. The system is ideal for short number sequences and covers a wide range of ready-printed markers.

Strips for fast installation in only one work step. The printing is easy to read, rich in contrast and available in various widths.

- Large range of ready-to-use markers
- Strips for fast installation
- Terminal markers, suitable for all Weidmüller cable connectors
- Available as blank MultiCard or with standard printing


**General ordering data**

Type	Order No.	Version	GTIN (EAN)	Qty.
DEK 5/6.5 MC	<a href="#">1609850000</a>	Dekafix, Terminal marker, 5	4008190456610	180 pc(s).
SDR		5 x 6.5 mm, Pitch in mm (P): 6.50 Weidmueller, To customer specification		



**SAK Series  
EK 2.5/35**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 16  
 D-32758 Detmold  
 Germany  
 Fon: +49 5231 1429-0  
 Fax: +49 5231 14292083  
 www.weidmueller.com

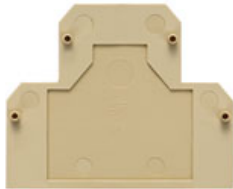**Accessories****End plates****Klippon® Connect with clamping yoke Technology**

The high reliability and variety of designs of the terminal blocks with clamping yoke connections make planning easier and optimises operational safety. Klippon® Connect provides a proven response to a range of different requirements.

**General ordering data**

Type	Order No.	Version	GTIN (EAN)	Qty.
AP SAK2.5	<a href="#">0279560000</a>	SAK Series, End plate, 1.5 mm, Beige, Direct mounting	4008190075736 20	pc(s).
AP SAK2.5+AST3+4/35	<a href="#">0460560000</a>	SAK Series, End plate, 1.5 mm, Beige, Direct mounting	4008190048334 20	pc(s).
AP SAK4-10 RT	<a href="#">0117900000</a>	SAK Series, End plate, 1.5 mm, Red, Direct mounting	4008190125059 20	pc(s).
AP SAK2.5+AST3+4/35 BL	<a href="#">0460580000</a>	SAK Series, End plate, 1.5 mm, Blue, Direct mounting	4008190081164 20	pc(s).
AP SAK4-10 DB	<a href="#">0105100000</a>	SAK Series, End plate, 1.5 mm, Dark Beige, Direct mounting	4008190394875 20	pc(s).
AP SAK4-10 I	<a href="#">0117910000</a>	SAK Series, End plate, 1.5 mm, Light Grey, Direct mounting	4008190183707 20	pc(s).
AP SAK2.5 BL	<a href="#">0279580000</a>	SAK Series, End plate, 1.5 mm, Blue, Direct mounting	4008190050702 20	pc(s).
AP SAK4-10 BL	<a href="#">0117980000</a>	SAK Series, End plate, 1.5 mm, Blue, Direct mounting	4008190171087 20	pc(s).
AP SAK35/ TW SAK16	<a href="#">0303660000</a>	SAK Series, End plate, 1.5 mm, Beige	4008190110765 10	pc(s).
AP AST1+5 DB	<a href="#">0266400000</a>	SAK Series, End plate, 1.5 mm, Dark Beige, Direct mounting	4008190176488 20	pc(s).
AP SAK35/ TW SAK16 BL	<a href="#">0303680000</a>	SAK Series, End plate, 1.5 mm, Blue	4008190025199 10	pc(s).
AP DK4S	<a href="#">0631360000</a>	SAK Series, End plate, 1.5 mm, Beige, Direct mounting	4008190101329 20	pc(s).
AP SAK4-10	<a href="#">0117960000</a>	SAK Series, End plate, 1.5 mm, Beige, Direct mounting	4008190081485 20	pc(s).

**SAK Series  
EK 2.5/35**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 16  
 D-32758 Detmold  
 Germany  
 Fon: +49 5231 1429-0  
 Fax: +49 5231 14292083  
 www.weidmueller.com

**Accessories**
**Insulated sockets**


STB 25 IH/6N 027120

**Klippon® Connect with clamping yoke Technology**

The high reliability and variety of designs of the terminal blocks with clamping yoke connections make planning easier and optimises operational safety. Klippon® Connect provides a proven response to a range of different requirements.

**General ordering data**

Type	Order No.	Version	GTIN (EAN)	Qty.
STB 28.5 IH/ SW SAK2.5	<a href="#">0133400000</a>	SAK Series, Socket	4008190136567	50 pc(s).

**Non-insulated sockets**

**Klippon® Connect with clamping yoke Technology**

The high reliability and variety of designs of the terminal blocks with clamping yoke connections make planning easier and optimises operational safety. Klippon® Connect provides a proven response to a range of different requirements.

**General ordering data**

Type	Order No.	Version	GTIN (EAN)	Qty.
STB 14/ D5/2.3/M3 SAK2.5	<a href="#">0168600000</a>	SAK Series, Socket	4008190135225	50 pc(s).
STB 14/ D6/4/M3 SAK10	<a href="#">0169900000</a>	Accessories, Socket	4008190076665	50 pc(s).
STB 8.5/5/2.3/ M3 SAK2.5	<a href="#">0280600000</a>	Accessories, Socket	4008190023188	50 pc(s).
STB 16/ D7/4/M4 SAK35	<a href="#">0140200000</a>	SAK Series, Socket	4008190134884	50 pc(s).
STB 8.5/ D4/2.3/M2.5 AKZ	<a href="#">0215700000</a>	Accessories, Socket	4008190184872	50 pc(s).
STB 8.5/ D4.5/2/M3 SAKT4	<a href="#">0244600000</a>	SAK Series, Socket	4008190103828	50 pc(s).
STB 6/ D3.7/2.3/M3 SAKR	<a href="#">0379400000</a>	SAK Series, Socket	4008190023478	100 pc(s).

## SAK Series EK 2.5/35

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 16  
 D-32758 Detmold  
 Germany  
 Fon: +49 5231 1429-0  
 Fax: +49 5231 14292083  
 www.weidmueller.com

## Accessories

STB 13.5/ D6/4/M4 SAKA10	<a href="#">0135200000</a>	SAK Series, Socket	4008190172862 50 pc(s).
STB 17/ D6/4/M4 SAKC10	<a href="#">0147100000</a>	SAK Series, Socket	4008190183042 50 pc(s).

## Railholder



### Shielding and earthing

Our protective earth conductor and shielding terminals featuring different connection technologies allow you to effectively protect both people and equipment from interference, such as electrical or magnetic fields. A comprehensive range of accessories rounds off our range.

### General ordering data

Type	Order No.	Version	GTIN (EAN)	Qty.
SH 2	<a href="#">0494920000</a>	Accessories, Rail support, KrG	4008190007584	10 pc(s).

## Q / AKZ



### Klippon® Connect with clamping yoke Technology

The high reliability and variety of designs of the terminal blocks with clamping yoke connections make planning easier and optimises operational safety. Klippon® Connect provides a proven response to a range of different requirements.

### General ordering data

Type	Order No.	Version	GTIN (EAN)	Qty.
Q 3 AKZ4	<a href="#">0336500000</a>	SAK Series, Cross- connector, for cross- connection link, No. of poles: 3	4008190121730	50 pc(s).
Q 4 AKZ4	<a href="#">0336600000</a>	SAK Series, Cross- connector, for cross- connection link, No. of poles: 4	4008190096656	50 pc(s).
Q 10 AKZ4	<a href="#">0368600000</a>	SAK Series, Cross- connector, for cross- connection link, No. of poles: 10	4008190056766	20 pc(s).
Q 2 AKZ4	<a href="#">0336400000</a>	SAK Series, Cross- connector, for cross-	4008190037680	50 pc(s).

## SAK Series EK 2.5/35

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 16  
 D-32758 Detmold  
 Germany  
 Fon: +49 5231 1429-0  
 Fax: +49 5231 14292083  
 www.weidmueller.com

## Accessories

connection link, No. of  
poles: 2

### Covers




#### Klippon® Connect with clamping yoke Technology

The high reliability and variety of designs of the terminal blocks with clamping yoke connections make planning easier and optimises operational safety. Klippon® Connect provides a proven response to a range of different requirements.

#### General ordering data

Type	Order No.	Version	GTIN (EAN)	Qty.
AD 4 AKZ4	<a href="#">0303400000</a>	SAK Series, cover plate, Yellow, 20 mm	400819006815850	pc(s).
AD 3 SAK2.5	<a href="#">0297900000</a>	SAK Series, cover plate, Yellow, 18 mm	400819003822950	pc(s).

### SchT group marker carrier

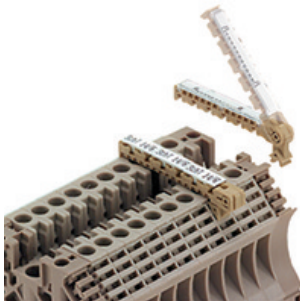

The SchT 5 S group tag carriers are clipped directly onto the TS 32 mounting rail (G-rail) or the TS 35 mounting rail (top-hat rail). It is therefore possible to label the terminal strip irrespective of the terminal and the type of terminal. SchT 5 and SchT 5 S are fitted with ESO 5, STR 5 protective strips.

The SchT 7 is a hinged group tag carrier for inlay tags which enables easy access to the clamping screw. The SchT 7 is fitted with ESO 7, STR 7 protective strips or DEK 5.

SchT 9/4 and SchT 14/6 are hinged group tag carriers for single dekafix and WS tags that enable easy access to the clamping screw.

SchT 9/4 and SchT 14/6 are fitted with WS or DEK.

Inlay tags and protective strips can be found under "Accessories".

#### General ordering data

Type	Order No.	Version	GTIN (EAN)	Qty.
SCHT 7	<a href="#">0517960000</a>	SCHT, Terminal marker, 39.3 x 8 mm, Pitch in mm (P): 7.00 White	400819000174220	pc(s).

## SAK Series EK 2.5/35

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 16  
 D-32758 Detmold  
 Germany  
 Fon: +49 5231 1429-0  
 Fax: +49 5231 14292083  
 www.weidmueller.com

# Accessories

## Plus



The Dekafix (DEK) marker is the universal marker for all conductor and plug-in connectors as well as for electronic sub-assemblies. The system is ideal for short number sequences and covers a wide range of ready-printed markers.

Strips for fast installation in only one work step. The printing is easy to read, rich in contrast and available in various widths.

- Large range of ready-to-use markers
- Strips for fast installation
- Terminal markers, suitable for all Weidmüller cable connectors
- Available as blank MultiCard or with standard printing

### General ordering data

Type	Order No.	Version	GTIN (EAN)	Qty.
DEK 5/6 PLUS	<a href="#">1011320000</a>	Dekafix, Terminal marker,	4032248717644	1,000 pc(s).
MC NE WS		5 x 6 mm, Pitch in mm (P): 6.00 Weidmueller, White		

## Q / SAK



### Klippon® Connect with clamping yoke Technology

The high reliability and variety of designs of the terminal blocks with clamping yoke connections make planning easier and optimises operational safety. Klippon® Connect provides a proven response to a range of different requirements.

### General ordering data

Type	Order No.	Version	GTIN (EAN)	Qty.
Q 2 SAK6N	<a href="#">0456700000</a>	SAK Series, Cross-connector, for cross-connection link, No. of poles: 2	4008190150044	50 pc(s).
Q 4 SAKD2.5N	<a href="#">0368000000</a>	SAK Series, Cross-connector, for cross-connection link, No. of poles: 4	4008190044909	50 pc(s).
Q 10 SAK4	<a href="#">0368800000</a>	SAK Series, Cross-connector, for cross-connection link, No. of poles: 10	4008190049478	20 pc(s).
Q 10 SAK2.5	<a href="#">0368700000</a>	SAK Series, Cross-connector, for cross-connection link, No. of poles: 10	4008190107796	20 pc(s).
Q 3 SAK2.5	<a href="#">0337100000</a>	SAK Series, Cross-connector, for cross-	4008190015411	50 pc(s).

## SAK Series EK 2.5/35

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 16  
D-32758 Detmold  
Germany  
Fon: +49 5231 1429-0  
Fax: +49 5231 14292083  
www.weidmueller.com

## Accessories

		connection link, No. of poles:	
Q 2 SAK2.5	<a href="#">0337000000</a>	3	400819000580 1 50 pc(s).
Q 2 SAK10	<a href="#">0457100000</a>	2	4008190103545 50 pc(s).
Q 3 SAK4	<a href="#">0336800000</a>	3	4008190089795 50 pc(s).
Q 4 SAK6N	<a href="#">0456900000</a>	4	4008190032579 50 pc(s).
Q 10 SAKD2.5N	<a href="#">0368100000</a>	10	4008190116293 20 pc(s).
Q 10 SAK16	<a href="#">0457800000</a>	10	4008190082512 20 pc(s).
Q 2 SAK16	<a href="#">0457500000</a>	2	4008190055349 50 pc(s).
Q 2 SAKD2.5N	<a href="#">0367800000</a>	2	4008190133436 50 pc(s).
Q 3 SAK16	<a href="#">0457600000</a>	3	4008190022280 50 pc(s).
Q 4 SAK16	<a href="#">0457700000</a>	4	4008190070823 50 pc(s).
Q 2 SAK4	<a href="#">0336700000</a>	2	4008190033842 50 pc(s).
Q 3 SAK6N	<a href="#">0456800000</a>	3	4008190110277 50 pc(s).
Q 4 SAK10	<a href="#">0457300000</a>	4	4008190129750 50 pc(s).

**SAK Series  
EK 2.5/35**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 16  
D-32758 Detmold  
Germany  
Fon: +49 5231 1429-0  
Fax: +49 5231 14292083  
www.weidmueller.com

**Accessories**

Q 4 SAK4	<a href="#">0336900000</a>	SAK Series, Cross-connector, for cross-connection link, No. of poles: 4	4008190036201 50 pc(s).
Q 10 SAK10	<a href="#">0457400000</a>	SAK Series, Cross-connector, for cross-connection link, No. of poles: 10	4008190016166 20 pc(s).
Q 3 SAKD2.5N	<a href="#">0367900000</a>	SAK Series, Cross-connector, for cross-connection link, No. of poles: 3	4008190176778 50 pc(s).
Q 10 SAK6N	<a href="#">0457000000</a>	SAK Series, Cross-connector, for cross-connection link, No. of poles: 10	4008190153762 20 pc(s).
Q 3 SAK10	<a href="#">0457200000</a>	SAK Series, Cross-connector, for cross-connection link, No. of poles: 3	4008190135379 50 pc(s).
Q 4 SAK2.5	<a href="#">0337200000</a>	SAK Series, Cross-connector, for cross-connection link, No. of poles: 4	4008190142902 50 pc(s).

**Test adapter**



**Klippon® Connect with clamping yoke Technology**

The high reliability and variety of designs of the terminal blocks with clamping yoke connections make planning easier and optimises operational safety. Klippon® Connect provides a proven response to a range of different requirements.

**General ordering data**

Type	Order No.	Version	GTIN (EAN)	Qty.
STA 2.5/2	<a href="#">0165860000</a>	SAK Series, Test adapter	4008190129491	100 pc(s).

**SAK Series  
EK 2.5/35**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 16  
D-32758 Detmold  
Germany  
Fon: +49 5231 1429-0  
Fax: +49 5231 14292083  
www.weidmueller.com

**Accessories**

**Covers**




**Building installation wiring**

For building installations, we offer a complete system that revolves around the 10×3 copper rail and comprises perfectly coordinated components: from installation terminal blocks, neutral conductor terminal blocks and distribution terminal blocks to comprehensive accessories such as busbars and busbar holders.

**General ordering data**

Available until	Type	Order No.	Version	GTIN (EAN)	Qty.
2016-11-02	TOADP40000000	<a href="#">1430760000</a>	SAK Series, Cover profile, Transparent	4008190132897	1 m

**Test plug**

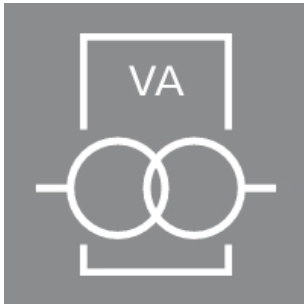

**Current and voltage transformer wiring**

Our test disconnect terminal blocks featuring spring and screw connection technology allow you to create all the important converter circuits for measuring current, voltage and power in a safe and sophisticated way.

**General ordering data**

Type	Order No.	Version	GTIN (EAN)	Qty.
PS 2.3 RT	<a href="#">0180400000</a>	Accessories, Test plug	4008190060121	20 pc(s).
PS 2.0 OR	<a href="#">0293800000</a>	Accessories, Test plug	4008190042356	20 pc(s).
PS 4 F.STB 4	<a href="#">0299600000</a>	Accessories, Test plug	4008190074043	20 pc(s).
ZS 2.3/4	<a href="#">0249600000</a>	Accessories, Adapter plug	4008190022785	20 pc(s).
FZS 2/4	<a href="#">1276300000</a>	Accessories, Adapter plug	4008190026080	20 pc(s).

RT/80 SAKT4



**SAK Series  
EK 2.5/35**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 16  
 D-32758 Detmold  
 Germany  
 Fon: +49 5231 1429-0  
 Fax: +49 5231 14292083  
 www.weidmueller.com

**Accessories**
**DEK 5/6**

**WS/ DEK**

MultiMark DEK/WS connector markers use an innovative composite material made from two components. The hard base contour of the marker snaps securely into the connector. The elastic surface finish makes the marker easy to mount. This specially punched material enables the strips to be stretched to accommodate the slight variations in spacing that tend to add up, especially with long terminal blocks. Another advantage: the excellent printability of the surface material guarantees durable and wear-resistant labelling. A print resolution of 300 dpi also produces a very legible script.

**Your benefits with MultiMark**

- Compatible with W, Z, P and SAK series terminal blocks
- Firm hold and durable printing
- Continuous strips save installation time
- Easy mounting thanks to an innovative composite material
- Space for multi-line printing

**General ordering data**

Type	Order No.	Version	GTIN (EAN)	Qty.
DEK 5/6 MM WS	<a href="#">2007120000</a>	Dekafix, Terminal marker, 5 x 6 mm, Weidmueller, White	4050118392104	600 pc(s).

**Busbar connections**

**Building installation wiring**

For building installations, we offer a complete system that revolves around the 10×3 copper rail and comprises perfectly coordinated components: from installation terminal blocks, neutral conductor terminal blocks and distribution terminal blocks to comprehensive accessories such as busbars and busbar holders.

**General ordering data**

Type	Order No.	Version	GTIN (EAN)	Qty.
ZB 4G BL	<a href="#">0322180000</a>	Accessories, Clamping yoke for busbar, Rated cross- section: Clamping yoke, PA, Blue, Feed-through (bushing)	4008190050504	50 pc(s).
ZB 4	<a href="#">0316500000</a>	Accessories, Clamping yoke for busbar, Rated cross- section: Clamping yoke, Feed-through (bushing)	4008190061999	50 pc(s).
ZB 16 ZKSC	<a href="#">0316600000</a>	Accessories, Clamping yoke for busbar, Rated cross-	4008190145989	50 pc(s).

**SAK Series**  
**EK 2.5/35**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 16  
 D-32758 Detmold  
 Germany  
 Fon: +49 5231 1429-0  
 Fax: +49 5231 14292083  
 www.weidmueller.com

**Accessories**

		section: Clamping yoke, Feed-through (bushing)	
IK 4 GG ZB4	<a href="#">0475460000</a>	Accessories, Special terminal, Rated cross-section: PA, green / yellow, Busbar	4008190065348 50 pc(s).
IK 4 BL ZB4	<a href="#">0475480000</a>	Accessories, Special terminal, Rated cross-section: PA, Blue, Busbar	4008190145668 50 pc(s).
ZB 4/6K BL	<a href="#">0565480000</a>	Accessories, Clamping yoke for busbar, Rated cross-section: Clamping yoke, PA, Blue, Feed-through (bushing)	400819008683 1 50 pc(s).
ZB 4/6K GE/ GN	<a href="#">0565460000</a>	Accessories, Clamping yoke for busbar, Rated cross-section: Clamping yoke, PA, green / yellow, Feed-through (bushing)	4008190032609 50 pc(s).
ZB 16K BL	<a href="#">0502880000</a>	Accessories, Clamping yoke for busbar, Rated cross-section: Clamping yoke, PA, Blue, Feed-through (bushing)	4008190014186 50 pc(s).
ZBE 6	<a href="#">0459500000</a>	Accessories, Clamping yoke for busbar, Rated cross-section: Clamping yoke, Busbar, Direct mounting	4008190032692 50 pc(s).
IK 6 GG ZBE6K	<a href="#">0526060000</a>	Accessories, Special terminal, Rated cross-section: PA, green / yellow, Busbar	4008190128647 50 pc(s).
ZB 35K BL M6X16	<a href="#">0502680000</a>	Accessories, Clamping yoke for busbar, Rated cross-section: Clamping yoke, PA, Blue, Feed-through (bushing)	4008190004385 20 pc(s).
ZB 16K GE/ GN	<a href="#">0502860000</a>	Accessories, Clamping yoke for busbar, Rated cross-section: Clamping yoke, PA, green / yellow, Feed-through (bushing)	4008190188795 50 pc(s).
ZB 4K GE/GN	<a href="#">0475360000</a>	Accessories, Clamping yoke for busbar, Rated cross-section: Clamping yoke, PA, green / yellow, Feed-through (bushing)	4008190188047 50 pc(s).
IK 16/ZB16 BL	<a href="#">0502980000</a>	Accessories, Special terminal, Rated cross-section: PA, Blue, Busbar	4008190159696 50 pc(s).
ZB 35K SW M6X16	<a href="#">0502610000</a>	Accessories, Clamping yoke for busbar, Rated cross-section: Clamping yoke,	4008190332587 20 pc(s).

**SAK Series**  
**EK 2.5/35**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 16  
 D-32758 Detmold  
 Germany  
 Fon: +49 5231 1429-0  
 Fax: +49 5231 14292083  
 www.weidmueller.com

**Accessories**

		PA, Black, Feed-through (bushing)
IK 16/ZB16 GG	<a href="#">0502960000</a>	Accessories, Special terminal, Rated cross-section: PA, green / yellow 4008190113438 50 pc(s).
ZB 35/M6X16	<a href="#">0266500000</a>	Accessories, Clamping yoke for busbar, Rated cross-section: Clamping yoke, Feed-through (bushing) 4008190102814 20 pc(s).
ZBE 6K BL	<a href="#">0525980000</a>	Accessories, Clamping yoke for busbar, Rated cross-section: Clamping yoke, PA, Blue, Busbar, Direct mounting 4008190060886 50 pc(s).
ZB 4G SW	<a href="#">0322110000</a>	Accessories, Clamping yoke for busbar, Rated cross-section: Clamping yoke, PA, Black, Feed-through (bushing) 4008190189310 50 pc(s).
ZBE 6K SW	<a href="#">0525910000</a>	Accessories, Clamping yoke for busbar, Rated cross-section: Clamping yoke, PA, Black, Busbar, Direct mounting 4008190977054 50 pc(s).
ZB 35K GE/ GN M6X16	<a href="#">0502660000</a>	Accessories, Clamping yoke for busbar, Rated cross-section: Clamping yoke, PA, green / yellow, Feed-through (bushing) 4008190052294 20 pc(s).
ZB 4K SW	<a href="#">0475310000</a>	Accessories, Clamping yoke for busbar, Rated cross-section: Clamping yoke, PA, Feed-through (bushing) 4008190008406 50 pc(s).
ZB 4G GN/GE	<a href="#">0322160000</a>	Accessories, Clamping yoke for busbar, Rated cross-section: Clamping yoke, PA, green / yellow, Feed-through (bushing) 4008190014278 50 pc(s).
ZB 4K GG HENSEL	<a href="#">1824560000</a>	Accessories, Clamping yoke for busbar, Rated cross-section: Clamping yoke, PA, green / yellow, Feed-through (bushing) 4032248330973 50 pc(s).
ZB 16K SW	<a href="#">0502810000</a>	Accessories, Clamping yoke for busbar, Rated cross-section: Clamping yoke, PA, Black, Feed-through (bushing) 4008190332563 50 pc(s).
ZBE 6K GE/ GN	<a href="#">0525960000</a>	Accessories, Clamping yoke for busbar, Rated cross-section: Clamping yoke, PA, green / yellow, Busbar, Direct mounting 4008190145026 50 pc(s).

**SAK Series  
EK 2.5/35**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 16  
D-32758 Detmold  
Germany  
Fon: +49 5231 1429-0  
Fax: +49 5231 14292083  
www.weidmueller.com

**Accessories**

IK 35/ZB35 BL <a href="#">0502780000</a>	Accessories, Special terminal, Rated cross-section: PA, Blue, Busbar	4008190141455 50 pc(s).
ZB 4/6 <a href="#">0556700000</a>	Accessories, Clamping yoke for busbar, Rated cross-section: Clamping yoke, Feed-through (bushing)	4008190188412 50 pc(s).
ZB 4K BL <a href="#">0475380000</a>	Accessories, Clamping yoke for busbar, Rated cross-section: Clamping yoke, PA, Blue, Feed-through (bushing)	4008190010942 50 pc(s).

**Small partition**



**Klippon® Connect with clamping yoke Technology**  
The high reliability and variety of designs of the terminal blocks with clamping yoke connections make planning easier and optimises operational safety. Klippon® Connect provides a proven response to a range of different requirements.

**General ordering data**

Delivery status Available until	Type	Order No.	Version	GTIN (EAN)	Qty.
This article will no longer be available in the future.	TSCH 6 DKI S4	<a href="#">0190260000</a>	SAK Series, Small partition, Beige, 5 mm	4008190051075	100 pc(s).
TSCH 4 AKZ4	SAK Series, Small partition, Beige, 6 mm	<a href="#">0363360000</a>	4008190136680 100 pc(s).		
TSCH 2	SAK Series, Small partition, Beige, 0.6 mm	<a href="#">0353660000</a>	4008190128432 100 pc(s).		
TSCH 1	SAK Series, Small partition, Beige, 2 mm	<a href="#">0319160000</a>	4008190097219 100 pc(s).		
TSCH 3 SAKD2.5 N	SAK Series, Small partition, Beige, 5 mm	<a href="#">0366860000</a>	4008190010928 100 pc(s).		

**SAK Series  
EK 2.5/35**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 16  
D-32758 Detmold  
Germany  
Fon: +49 5231 1429-0  
Fax: +49 5231 14292083  
www.weidmueller.com

**Accessories**

**End bracket**



**Klippon® Connect with clamping yoke Technology**  
The high reliability and variety of designs of the terminal blocks with clamping yoke connections make planning easier and optimises operational safety. Klippon® Connect provides a proven response to a range of different requirements.

**General ordering data**

Type	Order No.	Version	GTIN (EAN)	Qty.
EWK 1	<a href="#">0206160000</a>	Accessories, End bracket	4008190080020	50 pc(s).

**Partition plates**




**Klippon® Connect with clamping yoke Technology**  
The high reliability and variety of designs of the terminal blocks with clamping yoke connections make planning easier and optimises operational safety. Klippon® Connect provides a proven response to a range of different requirements.

**General ordering data**

Type	Order No.	Version	GTIN (EAN)	Qty.
WTW EN	<a href="#">1058800000</a>	W-Series, Separation plate	4008190140175	20 pc(s).

**Partition plates**

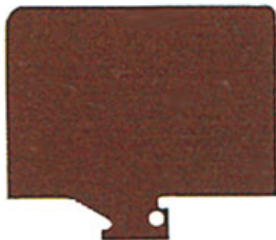

**Klippon® Connect with clamping yoke Technology**  
The high reliability and variety of designs of the terminal blocks with clamping yoke connections make planning easier and optimises operational safety. Klippon® Connect provides a proven response to a range of different requirements.

**General ordering data**

Type	Order No.	Version	GTIN (EAN)	Qty.
TW SAK2.5	<a href="#">0302860000</a>	SAK Series, Separation plate, 1.5 mm, Beige, Direct mounting	4008190032968	20 pc(s).
TW SAK2.5 BL	<a href="#">0302880000</a>	SAK Series, Separation plate, 1.5 mm, Blue, Direct mounting	4008190047948	20 pc(s).

## Data sheet

### SAK Series EK 2.5/35

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 16  
 D-32758 Detmold  
 Germany  
 Fon: +49 5231 1429-0  
 Fax: +49 5231 14292083  
 www.weidmueller.com

## Accessories

TW SAKS2 HP/DBR/2	<a href="#">060700000</a>	SAK Series, Separation plate, 2 mm, Dark brown, Used between terminals	4008190002732 20 pc(s).
TW SAK4-10 HP/DBR/0.5	<a href="#">0197100000</a>	SAK Series, Separation plate, 0.5 mm, Brown, Dark Beige, Direct mounting	4008190146627 20 pc(s).
TW 4 SAK4-10 BL	<a href="#">0130180000</a>	SAK Series, Separation plate, 1.5 mm, Blue	4008190114138 20 pc(s).
TW 4 SAK4-10	<a href="#">0130160000</a>	SAK Series, Separation plate, 1.5 mm, Beige	4008190096335 20 pc(s).
TW SAK2.5 HP/TF/GE/1	<a href="#">0297100000</a>	SAK Series, Separation plate, 1 mm, Yellow, Direct mounting	4008190161545 20 pc(s).
TW AST1/PA HP/DBR/0.5	<a href="#">0474700000</a>	SAK Series, Separation plate, 0.5 mm, Dark brown	4008190078508 20 pc(s).

## Insulation sleeve



### **Klippon® Connect with clamping yoke Technology**

The high reliability and variety of designs of the terminal blocks with clamping yoke connections make planning easier and optimises operational safety. Klippon® Connect provides a proven response to a range of different requirements.

## General ordering data

Type	Order No.	Version	GTIN (EAN)	Qty.
IH 2.8 DB	<a href="#">0386060000</a>	W-Series, Insulating sleeve	4008190043414	100 pc(s).
IH 4.8 DB	<a href="#">0386160000</a>	W-Series, Insulating sleeve	4008190141004	100 pc(s).
IH 6.3 WEM GE	<a href="#">0386260000</a>	W-Series, Insulating sleeve	4008190164256	100 pc(s).

**SAK Series  
EK 2.5/35**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 16  
 D-32758 Detmold  
 Germany  
 Fon: +49 5231 1429-0  
 Fax: +49 5231 14292083  
 www.weidmueller.com

**Accessories**

**Blank**



The Dekafix (DEK) marker is the universal marker for all conductor and plug-in connectors as well as for electronic sub-assemblies. The system is ideal for short number sequences and covers a wide range of ready-printed markers.

Strips for fast installation in only one work step. The printing is easy to read, rich in contrast and available in various widths.

- Large range of ready-to-use markers
- Strips for fast installation
- Terminal markers, suitable for all Weidmüller cable connectors
- Available as blank MultiCard or with standard printing

**General ordering data**

Type	Order No.	Version	GTIN (EAN)	Qty.
DEK 5/5 MC	<a href="#">1609801044</a>	Dekafix, Terminal marker,	4008190397111	1,000 pc(s).
NE WS		5 x 5 mm, Pitch in mm (P): 5,00 Weidmueller, White		

# Addresses worldwide

Let's connect.


- AE United Arab Emirates**  
Weidmüller Middle East FZE  
Warehouse Q3-79  
SAIF-Zone  
P.O. BOX 8591  
Sharjah  
Telephone number +971 65572723  
Fax number +971 65572724  
wme.info@weidmueller.com
- AF Afghanistan**  
Representative Office  
  
AF 11050 Beograd  
Telephone number +381 11 2885 274  
Fax number +381 11 2885 274  
zoran.rabrenovic@weidmueller.com
- AO Angola**  
Please contact  
Phambili Interface  
South Africa
- AR Argentina**  
CPI SA  
Bauness 2660  
C1431DOF Buenos Aires  
Telephone number +54 11 4523 8008  
Fax number +54 11 4522 0546  
info@cpi.com.ar  
www.cpi.com.ar
- AT Austria**  
Weidmüller GmbH  
IZ NOE Süd, Str. 2b, Obj M59,  
2355 Wiener Neudorf  
Telephone number +43 2236 67080  
Fax number +43 2236 6708-899  
office.at@weidmueller.com  
www.weidmueller.com
- AU Australia**  
Weidmüller Pty. Ltd.  
PO BOX 6944  
Huntingwood 2148  
Huntingwood Drive 43  
Huntingwood NSW 2148  
Telephone number +61 2 9671 9999  
Fax number +61 2 9671 9911  
info@weidmuller.com.au  
www.weidmuller.com.au
- AZ Azerbaijan**  
Representative Office  
Weidmüller Interface  
Demirchi Tower, 4th floor  
37, Khojali ave.  
AZ 1025 Baku  
Telephone number +994 12 488 80 36  
Fax number +994 12 488 80 37  
aliyar.hashimli@weidmueller.com
- BA Bosnia and Herzegovina**  
Please contact  
our Representative Office  
Weidmüller Interface GmbH  
& Co. KG  
Serbia  
  
or  
BH ES Elektrosistem d.o.o.  
Palih boraca 104  
78000 Banja Luka  
Telephone number +387 51 420 340  
Fax number  
elsist@inecco.net  
www.elektrosistem.ba  
BIG electric d.o.o  
Mladena Stojanovića 117A  
78000 Banja Luka  
Telephone number +387 51926277  
Fax number +387 51926277  
bigelectric@blic.net  
www.bigelectric.ba
- BE Belgium**  
Weidmüller Benelux B. V.  
Mechelsesteenweg 519 bus  
6 en 7  
1930 Nossegem  
Telephone number +32 2 752 40 70  
Fax number +32 2 751 36 06  
info@weidmueller.be  
www.weidmueller.be
- BG Bulgaria**  
Weid-Bul EOOD  
Bul. „Kliment Ohridski“ 13  
1756 Sofia  
Telephone number +359 2 963 2560  
Fax number +359 2 963 1098  
sofia@weidbul.com  
www.weidbul.com
- BH Bahrain**  
Khayber Trading Company  
P.O.Box 1976  
Manama  
Telephone number +973 720747  
Fax number +973 720331  
khayber@batelco.com.bh
- BR Brazil**  
Weidmüller Conexel do Brasil  
Conexões Elétricas Ltda.  
Av. Presidente Juscelino, 642  
- Piraporinha  
Diadema, São Paulo  
09950-370  
Telephone number +55 (11) 4366-9600  
Fax number +55 (11) 4362-1677  
vendas@weidmueller.com.br  
www.weidmueller.com.br
- BW Botswana**  
Please contact  
Phambili Interface  
South Africa
- BY Belarus**  
TECHNIKON Ltd.  
Nezavisimosti pr. 177-9  
220125 Minsk  
Telephone number +375 17 393-11-77  
Fax number +375 17 3930080  
wm@technikon.by
- CA Canada**  
W Interconnections Canada  
Inc.  
10 Spy Court  
Markham Ontario L3R 5H6  
Telephone number +1 (905) 475-1507 Ext. 9836  
Fax number +1 (905) 475-2798  
support@weidmuller.ca  
www.weidmuller.ca
- CG Congo**  
Please contact  
Phambili Interface  
South Africa
- CH Switzerland**  
Weidmüller Schweiz AG  
Rundbuckstraße 2  
8212 Neuhausen am  
Rheinfall SH  
Telephone number +41 52 674 07 07  
Fax number +41 52 674 07 08  
info@weidmueller.ch  
www.weidmueller.ch
- CL Chile**  
CPI CHILE LTDA  
Av. Presidente Frei Montalva  
6001, 47 complejo el cortijo  
Santiago - Conchalí  
Telephone number +562 963 8440  
Fax number +562 963 8440  
cpi@cpichile.cl  
www.cpichile.cl
- CN China**  
Weidmüller Interface  
(Shanghai) Co. Ltd.  
100 Yutong Road  
25 F. BM Intercontinental  
Business Center  
200070 Shanghai  
Telephone number +86 21-22195008  
Fax number +86 21-22195009  
customer.hotline@weidmueller.com.cn  
www.weidmueller.com.cn
- CO Colombia**  
Automatización Avanzada  
S. A.  
Carrera 97 No., 24 c.-23  
Bodega 4  
110911 Bogotá-D.C.  
Telephone number +57 (1) 547-8510  
Fax number +57 (1) 422-3044  
comercial@automatizacionavanzada.com  
www.automatizacionavanzada.com
- CR Costa Rica**  
ELVATRON S. A.  
la Uruca 400 Norte Banco  
Costa Rica  
San Jose Costa Rica  
Telephone number +506 2961-060  
Fax number +506 5200-609  
dirk.haase@elvatron.com  
www.elvatron.com
- CZ Czech Republic**  
Weidmüller s.r.o.  
Lomnického 5/1705  
140 00 Praha 4  
Telephone number +420 244 001 400  
Fax number +420 244 001 499  
office@weidmueller.cz  
www.weidmueller.cz
- DE Germany**  
Weidmüller GmbH & Co. KG  
Ohmstraße 9  
32758 Detmold  
Postfach 30 54  
32720 Detmold  
Telephone number +49 5231 1428-0  
Fax number +49 5231 14-292083  
weidmueller@weidmueller.de  
www.weidmueller.de
- DK Denmark**  
Weidmüller Danmark  
Vallensbækvej 18A  
2605 Brøndby  
Telephone number +45 27747800  
kundeservice@weidmuller.dk  
www.weidmuller.dk
- DZ Algeria**  
SARL INTER ELECTRIC  
1a Angles des Rues Okba Ibn  
Nafaa et Hassi Beida  
2300 Annaba  
Telephone number  
Fax number  
contact@inter-electric.com
- EC Ecuador**  
Elsystec S. A., Electricidad  
Sistemas y Tecnología  
Vasco de Contreras N35-251  
y Mañosa  
Quito - Pichincha  
Telephone number +593 22456510  
Fax number +593 22456755  
Elsystec@uio.satnet.net
- EE Estonia**  
Please contact  
our Representative Office  
Weidmüller Interface GmbH  
& Co. KG  
Latvia  
  
or  
SLO Eesti AS  
  
11415 Tallinn  
Telephone number +372 6 272 200  
Fax number  
info@slo.ee  
  
SLO Eesti AS  
  
12618 Tallinn  
Telephone number +372 622 9119  
Fax number  
elit@elit.ee  
  
Soots Interface OÜ  
Pärnu mnt 142  
11317 Tallinn  
Telephone number +372 609 6933  
Fax number  
info@sootsinterface.ee  
www.sootsinterface.ee
- EG Egypt**  
Standard Electric (OMEGA)  
1, Abdelhamid Badawy Street  
Heliopolis  
Cairo  
Telephone number +202 21805 111  
Fax number +202 21805600  
stdelec@rite.com
- ES Spain**  
Weidmüller, S. A.  
Narcis Monturiol 11-13, Pol.  
Ind. Sudoeste  
8960 Sant Just  
Desvern - Barcelona  
Telephone number +34 934 803 386  
Fax number +34 933 718 055  
weidmuller@weidmuller.es  
www.weidmuller.es
- FI Finland**  
Weidmüller Suomi,  
Weidmüller Aktiebolagetin  
sivuliike  
Koy Plaza Vivace  
Äyritie 8C  
FI 15100 Vantaa  
Telephone number +358 20 7351300  
Fax number +358 800 114 667  
asiakaspalvelu@weidmuller.fi  
www.weidmuller.fi
- FR France**  
Weidmüller E. U. R. L.  
2 Boulevard de l'Oise  
CS 31100 CERGY  
95095 CERGY PONTOISE  
Cedex  
Telephone number +33 1 34 24 55 00  
Fax number +33 1 34 24 55 01  
mail@weidmuller.fr
- GB Great Britain**  
Weidmüller Ltd.  
Klippon House  
Centurion Court Office Park,  
Meridian East, Meridian  
Business Park  
Leicester  
LE19 1TP  
Telephone number +44 116 282 3470  
Fax number +44 116 289 3582  
marketing@weidmuller.co.uk  
www.weidmuller.co.uk
- GE Georgia**  
Please contact  
our Representative Office  
Weidmüller Interface  
Azerbaijan.
- GH Ghana**  
Please contact  
our Representative Office  
Weidmüller Interface GmbH  
& Co. KG  
South Africa.
- GR Greece**  
G.A. Solutions  
Ippokratous 11 Metamorfsi  
144 52 Athens  
Telephone number +30 210 2823233  
Fax number +30 210 2823233  
info@weidmuller.gr  
www.weidmuller.gr
- GT Guatemala**  
Prestelectro, Prestegard  
Electro, S.A.  
Avenida Petapa 44-22,  
Zona 12  
Guatemala City  
Telephone number +502 2442-3346  
Fax number +502 2476-8945  
ventas@prestelectro.com
- HK Hong Kong**  
Weidmüller (Hong Kong)  
Limited Co. Ltd.  
Unit 1617, Metropolis Tower  
No. 10 Metropolis Drive,  
Hung Hom, Kowloon  
Telephone number +852 3154 8088  
Fax number +852 31548099  
Info-hk@weidmueller.com.hk
- HR Croatia**  
ElektroPARTNER d.o.o.  
Slavonska avenija 24/6  
HR-10000 Zagreb  
Telephone number +385 (1) 6184 793  
Fax number +385 (1) 6184 795  
elektropartner@zg.t-com.hr  
www.elektropartner.hr
- HU Hungary**  
Weidmüller Kereskedelmi Kft.  
Budapest  
Gubacsi út 6.  
1097  
Telephone number +36 1 382 7700  
Fax number +36 1 382 7701  
info@weidmueller.hu  
www.weidmueller.hu
- ID Indonesia**  
PT. Nego Electrindo  
Ruko Mega Grosir Cempaka  
Mas Blok I No. 20 - 22  
Jakarta 10640  
Telephone number +62 21 42882266  
Fax number +62 21 42882266  
sales@negoelectrindo.co.id
- IE Ireland**  
Please contact  
Weidmüller Ltd.  
Great Britain
- IL Israel**  
A. U. Shay Ltd.  
23/25, Embar Street  
49222 Petach-Tikva  
P.O. Box 1 00 49  
49222 Petach-Tikva  
Telephone number +972 3-923-3601  
Fax number +972 3-923-4601  
shay@uriel-shay.com  
www.uriel-shay.com  
ATEKA Ltd.  
4, Ha Tavor lane Industrial  
area Segula  
49691 Petach-Tikva  
P.O. Box 4710  
Petach-Tikva  
Telephone number +972 73-200-1311  
Fax number +972 3-924 4245  
marketing@ateka.co.il  
www.ateka.co.il





You can find all Weidmüller addresses and your local contact on the internet at: [www.weidmuller.com/countries](http://www.weidmuller.com/countries)

Sales company 

Representation abroad 

without representation abroad 

Let's connect.

- IN India**  
Representative Office  
Weidmüller Electronics India  
Pvt. Ltd.  
No. 9, Union Street, Off.  
Infantry Road  
BANGALORE  
560 001  
Telephone number +91-80-  
22860028  
wmi@weidmuller.in  
www.weidmuller.com
- IR Iran**  
Representative Office  
Tamin Ehtajat Fanni Tehran  
(TAF Co.)  
No. 36, West 4th St., Ettehad  
Ave. Damavand Rd.  
Tehran - 1658674583, Iran  
Telephone number +9821  
77120809  
info@taf-co.com  
http://www.taf-co.com
- IS Iceland**  
Samey Automation Center  
Lyngas 13  
210 Garoabaer  
Telephone number +354  
510 5200  
Fax number +354 5 10 5201  
Samey@samey.is  
www.samey.is
- IT Italy**  
Weidmüller S. r.l.  
Via Albert Einstein 4  
20092 Cinisello  
Balsamo Milano  
Telephone number +39 02  
680681  
Fax number +39 02  
6124945  
weidmuller@weidmuller.it  
www.weidmuller.it
- JM Jamaica**  
Please contact  
W Interconnections Inc.  
United States
- JO Jordan**  
Billeh Electricals Mat. Co.  
PO Box 4343  
Amman  
Telephone number +962 6  
4656 987  
Fax number +962 6 4649  
216
- JP Japan**  
Nihon Weidmüller Co. Ltd.  
Sphere Tower Tennoz 2-2-8  
Higashi-Shinagawa,  
Shinagawa-ku  
Tokyo  
140-0002  
Telephone number +81 3  
6711 5300  
Fax number +81 3 6711  
5333  
info@weidmuller.co.jp  
www.weidmuller.co.jp
- KE Kenya**  
Please contact  
our Representative Office  
Weidmüller Interface GmbH  
& Co. KG  
South Africa.
- KG Kyrgyzstan**  
Please contact  
our Representative Office  
Weidmüller Interface  
Azerbaijan.
- KR Korea**  
Weidmüller Korea Co. Ltd.  
9th floor  
429, Teheran-ro, Gangnam-Gu  
Seoul 135-721  
Telephone number +82  
2-516-0003  
Fax number +82 2-516-0090  
info@weidmuller.co.kr  
www.weidmuller.co.kr
- KW Kuwait**  
Kana Controls General Trading  
& Contracting Co. W. L. L.  
Al Rai Industrial Area, Plot  
28-30, St. 31  
13016 Safat  
B.P. 25593  
Telephone number +965  
4741373  
Fax number +965 4741537  
info@kanacontrols.com  
  
Petroleum Services Co. W.L.L.  
Kuwait Trade Free Zone Area  
P.O. Box 4098 Safat 13041  
  
Telephone  
number +96524610801/2/3  
ext. 208 II  
Fax number +96524613754  
psc-systems@petserv.net
- KZ Kazakhstan**  
Please contact  
Weidmüller Group  
Russia
- LB Lebanon**  
Progress Engineering &  
Trading Enterprises  
Al Nahr Street  
Beirut 11-1111  
Telephone number +961 1  
444 664  
Fax number +961 1 561 880  
progress@inco.com.lb
- LT Lithuania**  
Please contact  
our Representative Office  
Weidmüller Interface GmbH  
& Co. KG  
Latvia  
  
or  
ELEKTROS IRANGA  
Tinklu g. 29 a  
LT-5319 Panevezys  
Telephone number +370 (45)  
582 828  
Fax number +370 (45)  
582 727  
info@eliranga.lt  
  
UAB „SLO Lithuania“  
Vilkpėdės g. 4  
LT-LT-03151 Vilnius  
Telephone number +370 5  
215 00 70  
Fax number +370 5 215  
00 71  
biuras@slo.lt
- LU Luxembourg**  
Please contact  
Weidmüller Benelux B. V.  
Netherlands
- LV Latvia**  
SIA Abi4  
Daugavgrivas 49 k3  
Riga, LV-1007  
Telephone number +371 674  
70999  
Fax number  
abi\_4@tvnet.lv  
  
Representative Office  
Weidmüller Interface GmbH  
& Co. KG  
Udens str. 12-118  
Riga, LV-1007  
Telephone number +371  
29254766  
Fax number  
lgonis.rudaks@weidmuller.  
com  
www.weidmuller.com
- MA Morocco**  
Sofimed  
137, Bd Moulay Ismail Roches  
Noires  
20290 Casablanca  
Telephone number  
Fax number  
contact@sofimedmaroc.com
- MD Moldova**  
Inoxpa Solutions SRL  
20, Igor Vieru street  
MD-2075 Chisinau  
Moldova  
Telephone number +373 (22)  
866665  
Fax number +373 ( 22)  
866663  
atiuleanu@gmp-moldova.com  
www.gmp-moldova.com
- ME Montenegro**  
Please contact  
our Representative Office  
Weidmüller Interface GmbH  
& Co. KG  
Serbia.
- MG Madagascar**  
Please contact  
Phambili Interface  
South Africa
- MK Macedonia**  
Please contact  
our Representative Office  
Weidmüller Interface GmbH  
& Co. KG  
Serbia  
  
or  
ELEKTRO - SMK dooel  
UL. III Makedonska brigada  
b.b.  
1000 Skopje  
Telephone number +389  
22460295  
Fax number  
Elektro-smk@telekabel.net.mk
- MN Mongolia**  
Please contact  
our Representative Office  
Weidmüller Interface  
Azerbaijan.
- MT Malta**  
E. S. S., Electrical Supplies &  
Services Ltd.  
San Gwakkim Road  
Mriehal  
  
Telephone number +356  
21255777  
Fax number +356 21255999  
robert.agius@ess.com.mt
- MU Mauritius**  
Mubelo Electrical Ltd.  
Office 26, Gateway building,  
St Jean Road  
Quatre Bornes  
Mauritius  
Telephone number +230  
4670989  
Fax number +230 4654051  
richard.mubelo@orange.mu
- MW Malawi**  
Please contact  
our Representative Office  
Weidmüller Interface GmbH  
& Co. KG  
South Africa.
- MX Mexico**  
W Interconnections S. A.  
DE C. V.  
Blvd. Hermanos Serdán 698,  
Col. San Rafael Oriente  
72029 Puebla  
Telephone number +52 (222)  
268 6227  
Fax number +52 (222) 286  
6242  
clientes@weidmuller.com.mx
- MY Malaysia**  
Connect Plus Technology  
Sdn Bhd  
No. 43, Jalan PJS 11/22,  
Bandar Sunway  
46150 Petaling Jaya  
Selangor Darul Ehsan  
Telephone number +60 3  
5633 7363  
Fax number +60 3 5633  
6562  
paul@cptech.com.my  
www.cptech.com.my
- MZ Mozambique**  
Please contact  
Phambili Interface  
South Africa
- NA Namibia**  
Please contact  
Phambili Interface  
South Africa
- NG Nigeria**  
Please contact  
Weidmüller Interface GmbH  
& Co. KG  
South Africa
- NL Netherlands**  
Weidmüller Benelux B. V.  
Franciscusweg 221  
1216 SE Hilversum  
P.O. Box 1505  
1200 BM Hilversum  
Telephone number +31 35  
626 12 61  
Fax number +31 35 623  
20 44  
info@weidmuller.nl  
www.weidmuller.nl
- NO Norway**  
Sivilingeniør J.F. Knudtzen AS  
Billingstadsetta 97  
1396 Billingstad  
PO Box 160  
1378 Nesbru  
Telephone number +47 66  
98 33 50  
Fax number +47 66 98 09 55  
firmapost@jfknudtzen.no  
www.jfknudtzen.no
- NZ New Zealand**  
Cuthbert S. Steward Ltd.  
27 Te Puni Street  
Petone  
PO Box 38496  
Wellington Mail Centre 5054  
Telephone number (04) 568  
6156  
Fax number (09) 489 1752  
csi@cuthbertstewart.co.nz  
  
Cuthbert S. Steward Ltd  
4 Fred Thomas Drive  
Aon Building, Ground Floor,  
South Entry  
Takapuna  
PO Box 100 338  
North Shore City 745  
Telephone number (09) 489  
1751  
Fax number (04) 568 6056  
csiak@cuthbertstewart.co.nz
- OM Oman**  
DAN INTERNATIONAL LLC.  
Ghala St. 111  
BP 2901  
Seeb  
Telephone number +968  
5036 77  
Fax number +968 5037 55  
yedu@danintl.com
- PE Peru**  
IMPEXINCA S.A.C.  
Calle Ortiz de Zevallos No.  
105, Urb. San Antonio  
18  
Lima, Miraflores  
Telephone number +51 1  
447 5608  
info@impexinca.pe  
www.impexinca.pe  
  
J & W CIA. S. A.  
Calle 6 Mz. D Lte. 23, Urb.  
Ind. Grimanesa  
01  
Callao  
Telephone number +51 1  
572 2539  
Fax number +51 1 572 0152  
contacto@jwcia.com  
www.jwcia.com
- PH Philippines**  
Enclosure Systems Specialists  
Inc.  
2276 Don Chino Roces  
Avenue Extension  
Room 103/105 Narra Building  
1231 Makati City  
Telephone number +63 2  
813 8580  
Fax number +63 2 813 8596  
sales\_encsys@pltdsl.net  
www.enclosuresystemsph.  
com
- PK Pakistan**  
Automation Controls (Pak)  
Apartment No. 33 C III,  
Chensab Block, Allama Iqbal  
Town  
Lahore  
Telephone number +92 42  
37809948  
Fax number +92 42  
37809950  
nadeem@acpak.com.pk  
www.acpak.com.pk
- PL Poland**  
Weidmüller Sp. z o. o.  
ul. Ogrodowa 58  
00-876 Warszawa  
Telephone number +48 22  
510 09 40  
Fax number +48 22 510  
09 41  
biuro@weidmuller.com.pl  
www.weidmuller.pl
- PR Puerto Rico**  
Please contact  
W Interconnections Inc.  
United States
- PT Portugal**  
Weidmüller Sistemas de  
Interface S. A.  
Estrada Outeiro Polima, R.  
Augusto Dias da Silva, Lote  
B - Esc. 2  
São Domingos de Rana  
2785-515 Abóboda  
Telephone number +351 214  
459 191  
Fax number +351 214  
455 871  
weidmuller@weidmuller.pt  
www.weidmuller.pt
- PY Paraguay**  
Please contact  
CPI SA  
Argentina
- QA Qatar**  
Doha Motors  
PO Box 145  
  
Telephone number +974  
4651441  
Fax number +974 4654579  
dmtctech@qatar.net.qa  
http://www.dohamotorsgroup.  
com/td.html
- RO Romania**  
Representative Office  
Weidmüller Interface GmbH  
& Co. KG  
Inescu Crum Street, No.  
1, 1st Tower, 1st Floor,  
Office 4  
500446 Brasov - Brasov  
Business Park  
Telephone number +40 (268)  
446 222  
Fax number +40 (268)  
446 224  
claudiu.totea@weidmuller.  
com  
www.weidmuller.ro
- RS Serbia**  
Representative Office  
Weidmüller Interface GmbH  
& Co. KG  
Ustanička 189, III sprat  
lokal 7a  
11050 Beograd  
Telephone number +381  
112885274  
Fax number +381  
112885274  
zoran.rabrenovic@  
weidmuller.com  
  
TeLa Elektrik d.o.o.  
Ul. Dr. Drage Ljocić 6  
Beograd  
Telephone number +381 11  
2772 415  
Fax number +381 11 2772  
850  
office@tela.rs  
www.tela.rs

# Addresses worldwide

Let's connect.

- RU Russia**  
Weidmüller Group  
7/10 Khlebozavodskiy  
Passage,  
Moskau  
115230  
Telephone number +7 495  
280 72 71  
Fax number +7 495 280  
72 71  
Info@weidmueller.ru  
www.weidmueller.ru
- SA Saudi Arabia**  
Al Abdulkarim Holding Co.  
P.O. Box 4  
Dammam 31411  
Telephone number +966 3  
8337 110  
Fax number +966 3  
8829547  
E-mail salehsk@akh.com.sa  
www.weidmueller.ae
- Saudi Electric Supply  
Company (SESCO)  
P.O. Box 32 98  
Al Khobar 31952  
Telephone number +966 3  
8829546 Ext. 3030  
Fax number  
E-mail Safdar.Malik@sescogex.com  
www.sescogex.com
- SE Sweden**  
Weidmüller AB  
Axel Danielssons väg 271  
BOX 31025  
SE-200 49 Malmö  
Telephone number +46 77-  
143 00 44  
Fax number +46 40-37 48 60  
info@weidmuller.se  
www.weidmuller.se
- SG Singapore**  
Weidmüller Pte. Ltd.  
70 Bendemeer Road  
# 04-03 Luzerne Building  
Singapore 339940  
Telephone number +65 6841  
53 11  
Fax number +65 6841 5377  
info@weidmuller.com.sg  
www.weidmuller.com.sg
- SI Slovenia**  
Elektrospoji d. o. o.  
Stegne 27  
SI- 1000 Ljubljana  
Osrednjeslovenska  
Telephone number +386 1  
511 3810  
Fax number +386 1 511  
1604  
info@elektrospoji.si  
www.elektrospoji.si
- SK Slovakia**  
ELEKTRIS s.r.o.  
Elektrárenská 1  
831 04 Bratislava  
Telephone number +421  
2/4920 0113  
Fax number +421 2/4920  
0119  
bratislava@elektris.sk
- SV El Salvador**  
Prestegard Electro  
11 Avenida Norte No. 240  
Edificio Salazar No. 2  
San Salvador  
Telephone number +503  
2271 1690  
Fax number +503 2221  
3851  
prestegard@navegante.com.sv
- SY Syria**  
Please contact  
Weidmuller Middle East FZE  
United Arab Emirates
- SZ Swaziland**  
Please contact  
Phambili Interface  
South Africa
- TH Thailand**  
Pisanu Engineering Co. Ltd.  
Kwang Dingaeng, Khet  
Dingaeng  
800/2 Soi Trakulsuk, Asoke-  
dindaeng Road  
Dindaeng, Bangkok  
10400  
Telephone number +66 2  
248 2896  
Fax number +662 105 6301  
ecsales@pisanu.co.th  
www.pisanu.co.th
- Representative Office  
Weidmüller Pte. Ltd.  
37/F, Sathorn Square Building  
98 North Sathorn Road  
Bangkok, Silom Bangrak  
10500  
Telephone number +66 2  
105 6300  
Fax number +66 2 642 9220  
info@weidmuller.com.sg
- TJ Tajikistan**  
Please contact  
our Representative Office  
Weidmüller Interface  
Azerbaijan.
- TM Turkmenistan**  
Please contact  
our Representative Office  
Weidmüller Interface  
Azerbaijan.
- TN Tunisia**  
Please contact  
Weidmüller E. U. R. L.  
France
- TR Turkey**  
Weidmüller Elektronik Ticaret  
Ltd. Sirketi  
Kavacik Mah. Orhan Veli Kanik  
Caddesi 9/1  
34810 Beykoz / Istanbul  
Telephone number +90 (216)  
537 10 70  
Fax number +90 (216) 537  
10 77  
info@weidmuller.com.tr  
www.weidmuller.com.tr
- TW Taiwan**  
Please contact  
Weidmuller (Hong Kong)  
Limited Co. Ltd.  
Hong Kong
- TZ Tanzania**  
Please contact  
our Representative Office  
Weidmüller Interface GmbH  
& Co. KG  
South Africa.
- UA Ukraine**  
LLC WM UKRAINE  
Levanevskogo str. 6  
Kiev  
3058  
Telephone number +38 044  
490 32 48  
Fax number  
info@wm-ua.com.ua  
wm-ua.com.ua/
- Representative Office  
Weidmüller Interface GmbH  
& Co. KG  
Z. office 303  
7-D, Zdolbunivska str.  
Kiev, 2081  
Telephone number  
(mobile) +38 050 440 25 24  
info.ua@weidmueller.com
- US United States**  
W Interconnections Inc.  
821 Southlake Boulevard  
Richmond Virginia 23236  
Telephone number +1 (804)  
794-2877  
Fax number +1 (804) 379-  
2593  
info@weidmuller.com  
www.weidmuller.com
- UY Uruguay**  
REWO Uruguay S. A.  
AV. Bolivia 2001Esq  
Rocafuerte  
11300 Carrasco Montevideo  
Telephone number +598  
2604 8439  
Fax number +598 2604  
8439  
rewo@rewooruguy.com.uy
- UZ Republic of Uzbekistan**  
Please contact  
our Representative Office  
Weidmüller Interface  
Azerbaijan.
- VE Venezuela**  
Somerinca C. A.  
Corazon de Jesus - 3ra  
Transversal con calle el  
Carmen- Los Dos Caminos  
Caracas 1070-A  
Telephone number +58  
2122352748  
Fax number +58  
2122399341  
klocmoeller@cantv.net  
www.somerinca.com
- VN Vietnam**  
AUMI Industrial Equipment &  
Automation Company Limited  
E1, La Thanh Hotel  
218 Doi Can Street  
Lieu Giai Ward, Ba Dinh  
District  
Hanoi City  
Telephone number +84 4  
37 628601  
Fax number +84 4  
62661391  
aumi@aumi.com.vn  
www.aumi.com.vn
- Representative Office  
Weidmüller Pte. Ltd.  
Level 16 Saigon Tower  
Building  
29 Le Duan Street  
District 1  
Ho Chi Minh  
Telephone number +848  
3520 7717  
Fax number +848 3520  
7604  
info@weidmuller.com.sg
- ZA South Africa**  
Phambili Interface  
PO Box 193  
1609 Johannesburg, Edenvale  
5 Bundo Road, Sebenza  
1610 Johannesburg  
Telephone number +27 (11)  
4521930  
Fax number  
info@weidmuller.co.za  
www.weidmuller.co.za
- Representative Office  
Weidmüller Interface GmbH  
& Co. KG  
210 Amarand  
Avenue, Pegasus Building  
181 Pretoria, waterkloof Glen  
ext 2 -  
Telephone number +27 12  
003 2906  
Fax number +27 (11)  
4526455  
Jacques.Vosloo@weidmueller.  
com  
www.weidmueller.com
- ZM Zambia**  
Please contact  
Phambili Interface  
South Africa
- ZW Zimbabwe**  
Please contact  
Phambili Interface  
South Africa