


113A.8C 113A.C - Chromed adjustable wrenches

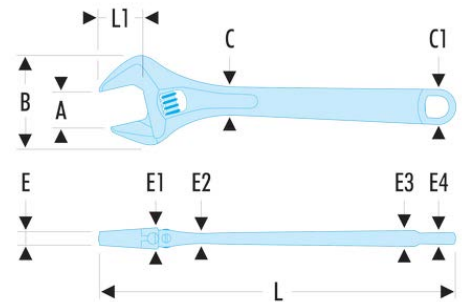

- Good access to the button = easy setting.
- Non-protruding moving jaw at maximum capacity.
- Pre-adjustment of jaw opening thanks to millimetric gradation.
- Right-hand button rotation.
- Range from 4" to 24".
- Presentation: chromed body and polished head faces.

A [mm]: 27

B [mm]: 61,5

C x C1 [mm]: 18,5 x 24,0

C1 [mm]: 24

E [mm]: 6,5

E maxi [mm]: 6,5

E1 [mm]: 13,5

E2 [mm]: 9,0

E3 [mm]: 11,0

E4 [mm]: 8,5

L [mm]: 206

L1 [mm]: 24

[g]: 275