


26 16 200

Snipe Nose Side Cutting Pliers (Stork Beak Pliers)



- high loadable, elastic precision points
- half-round, long jaws
- knurled gripping surfaces
- with cutting edges for medium hard wire max. dia. 3.2 mm and hard wire max. dia. 2.2 mm
- cutting edges additionally induction hardened, cutting edge hardness approx. 61 HRC
- Vanadium electric steel; forged, oil-hardened

Article No.	26 16 200
EAN	4003773022831
Pliers	chrome plated
Handles	insulated with multi-component grips, VDE-tested
Head	
Style	1
Insulation standard	IEC 60900 DIN EN 60900
medium hard wire Ø mm	3,2
hard wire Ø mm	2,2
T1 mm	9,5
W3 mm	17,5
W4 mm	3,0
T2 mm	2,5
L3 mm	73,0
Nominal size	200 mm
Length mm	200
Net weight g	206

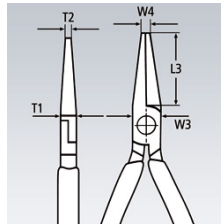

technical change and errors excepted

