


Datasheet

Steel Zinc Plated Toggle Latch, 30kgf Op. Tension

RS Stock number [206-4624](#)

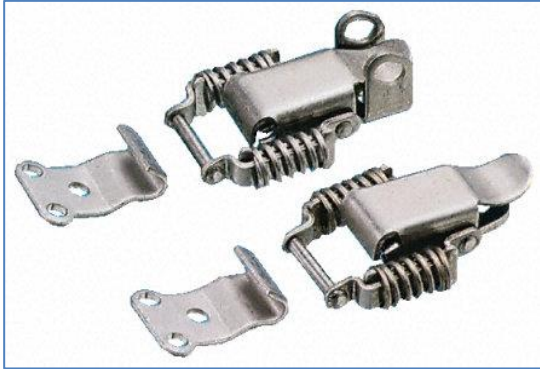

Description:

Similar in design to the variable tolerance versions but smaller.

Wide positioning tolerance created by the spring mechanism

Failsafe design prevents over extension of links

Operating tension is 20 kgf when distance between Catch fixing hole centres and the furthest Latch fixing hole centre is 63.2 mm

Maximum operating tension is 30Kgf.

Use 4 ' M4 screws for fixing

Features:

- Dimensions 53 x 35 x 17mm
- Finish Zinc Plated
- Length 53mm
- Material Steel
- Operating Tension 30kgf
- Spring Loaded Yes

