

---

## 2000 K

### LEDiving W5W – Premium | LED – Interior lighting



---

#### Areas of application

- Interior lighting

---

#### Product benefits

- 5 year guarantee
- Perfect light distribution thanks to modern diffusor material
- Non selective illumination thanks to homogenous light
- Wide range of different light colors for a variety of customization options
- Maintenance-free thanks to long lifetime of up to 5,000 h
- Up to 80 % less energy consumption (compared to standard lamps)
- Easy plug & play replacement

---

#### Product features

- LED retrofit lamps for various applications in vehicle interiors
- LEDW5W available with color temperature: 4,000 K, 6,000 K, 6,800 K, 2,000 K
- LEDW5W available with light color: Warm White, Cool White, Ice Blue, Amber
- Shockproof and vibration-proof

---

Technical data

**Electrical data**


|                 |        |
|-----------------|--------|
| Nominal wattage | 1.00 W |
| Nominal voltage | 12 V   |

**Photometrical data**

|                   |        |
|-------------------|--------|
| Color temperature | 2000 K |
| Luminous flux     | 30 lm  |

**Dimensions & weight**

---

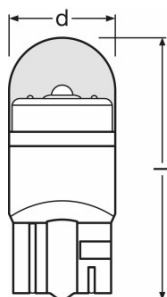

---

|          |         |
|----------|---------|
| Length   | 26.8 mm |
| Diameter | 10.0 mm |

**Lifespan**

|             |        |
|-------------|--------|
| Lifespan B3 | 2500 h |
| Lifespan Tc | 5000 h |

**Additional product data**

|                             |           |
|-----------------------------|-----------|
| Base (standard designation) | W2.1x9.5d |
|-----------------------------|-----------|

**Certificates & standards**

|              |   |
|--------------|---|
| ECE category | - |
|--------------|---|

## Product datasheet

---

### Logistical Data

| Product code  | Product description | Packaging unit (Pieces/Unit) | Dimensions (length x width x height) | Volume               | Gross weight |
|---------------|---------------------|------------------------------|--------------------------------------|----------------------|--------------|
| 4008321875600 | 2000 K              | Blister<br>2                 | 135 mm x 95 mm x<br>13 mm            | 0.17 dm <sup>3</sup> | 15.80 g      |
| 4008321875617 | 2000 K              | Shipping carton box<br>10    | 71 mm x 104 mm x<br>146 mm           | 1.08 dm <sup>3</sup> | 109.00 g     |

The mentioned product code describes the smallest quantity unit which can be ordered. One shipping unit can contain one or more single products. When placing an order, for the quantity please enter single or multiples of a shipping unit.

---

### References / Links

Guarantee terms are available at

▶ [www.osram.com/am-guarantee](http://www.osram.com/am-guarantee)

---

### Legal advice

Not ECE conform

Only approved for off-road use when used in an exterior application. Illegal use on public roads leads to cancellation of vehicle operating licence and loss of insurance cover.

---

### Disclaimer

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.