


# Datasheet

## 6 Lock, 10mm Shackle Steel Ball Value Lockout, 25mm Attachment Point

RS Stock number [712-618](#)

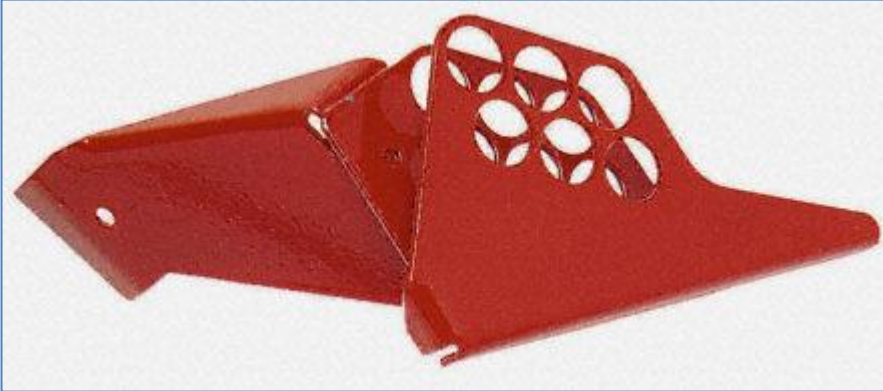

### Description:

- Easy to use, single piece design locks quarter-turn ball valves in the OFF position
- Two sizes fit most valves up to 3" in diameter
- Made from either powder-coated steel or super-tough nylon

### Material:

- Polyamide: Nylon 6/6
- Colour: Pantone 1807
- Steel
- Powder Coat: Red

Chemical	°C	Chemical	°C
Acetone	25	Petroleum	25
Acetone	60	Turpentine oil	25
Chlorine, chlorine water	25	Turpentine substitute (white spirit)	25
Fuel, engine: Gasoline (normal & premium grade)	85	Trichloroethane 1,1,1	45
Lubrication oil: gear oil	< 120	Lubricating oil: HD engine oils, hydraulic oils, transformer oils	< 120
Fuel, engine: M15 mixture (15% methanol)	70	Water (including seawater)	25
Methanol	25	Water (including seawater), chlorinated (<0,5 mg/l)	80


### Chemical Resistance

All approved chemicals listed are based on the manufactures specified chemical resistance chart for plastic material only.

### Temperature Range

- Plastic: -20°F to 250°F (-30°C to 120°C)
- Steel: -30°F to 350°F (-35°C to 175°C)
- Powder Coat: -20°F to 200°F (-30°C to 93°C)

Dimensions					
<b>Plastic</b>					
A	-	3.7" [95mm]			
B	-	3.1" [77mm]			
C	-	1.1" [27mm]			
D	-	2.25" (57mm)			
E	-	0.31" (8mm)			
F	-	0.29" (3.3mm)			
			<b>Small</b>	<b>Large</b>	
A	-	3.7"[95mm]	6.12"[156mm]	6.12"[156mm]	
B	-	3.1"[77mm]	4.96"[126mm]	4.96"[126mm]	
C	-	N/A	N/A	N/A	
D	-	2.25"[57mm]	3.86"[98mm]	3.86"[98mm]	
E	-	0.31"[8mm]	0.65"[16.5mm]	0.65"[16.5mm]	
F	-	0.38"[3.3mm]	0.29"[7.4mm]	0.38"[3.3mm]	

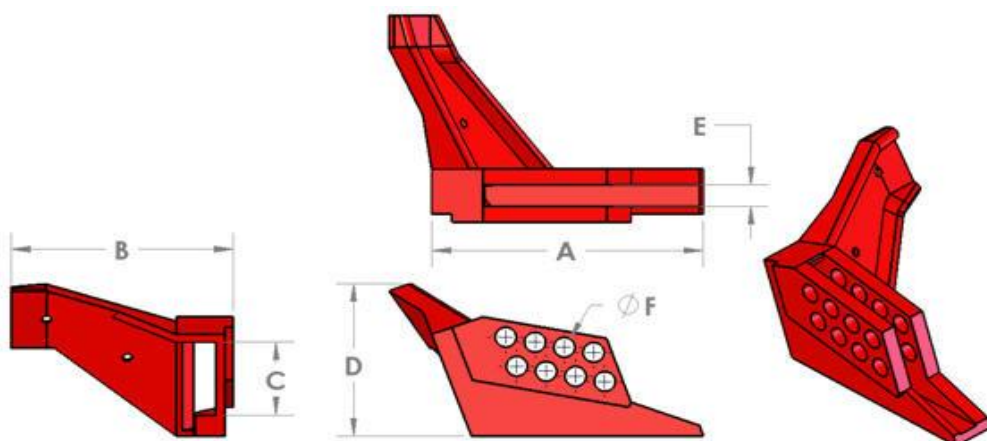

Plastic Version