



DMK - DMUK

TORQUE WRENCH DREMASTER® K / UK 20-850 N-m / 15 - 630 lbf-ft

Use:

- Controlled screw tightening in the most common range of 20 - 850 N-m / 15 - 630 lbf-ft (guide for screws M7-10.9 to M24-8.8, M30-5.6)
- Adjustable, releasing and sturdy tubular torque wrench with integrated ratchet and with square drive for industry and the trades

Features:

 
- Classified to DIN EN ISO 6789:2003 Type II Class A, with a factory certificate allowing for operations to be traced back. Calibrated to a permitted +/- 3% deviation and better. The specifications of the standard (+/- 4%) are exceeded.
- For controlled bi-directional tightening. DMUK only for controlled clockwise-tightening
- Models DMK: 1/2" mushroom head interchangeable square with push-button releasing and a ball-locking mechanism. From Model No. DMK 400 with 3/4" push-through square and a pin-locking mechanism
- Models DMUK: With 1/2" reversible ratchet
- Sturdy, satin chrome-plated tubular steel construction, with chrome-plated ratchet head and top-grade plastic parts
- Ergonomically shaped, 2-component plastic grip with calibration aid
- Change-over between N-m main scale and lbf-ft ancillary scale to avoid reading errors when setting the torque wanted
- With micrometre scale for main N-m scale for setting interim values
- Release system triggers a tactile and audible signal
- Ergonomic system for torque adjustment with reference symbol
- Provision for rapid setting with hexagon allen key, not included
- Secured adjusting/setting system
- Patent applied

12.5


1/2"

20

3/4"



"	■	N-m	lbf-ft	سلسله	scale ring	L	lw	c	h	b	🔊	Code	No.
1/2	12.5	20-100	15-75	5 N-m	0,5 N-m	423.5	329.2	35	38.4	44	1.100	2641232	DMK 100
1/2	12.5	40-200	30-150	10 N-m	1 N-m	514.5	420.2	35	38.4	44	1.300	2641240	DMK 200
1/2	12.5	60-300	45-220	10 N-m	1 N-m	606.5	511.2	35	38.4	46	1.500	2641259	DMK 300
3/4	20.0	80-400	60-300	10 N-m	1 N-m	715.5	609.2	46	31.0	67	2.400	2641267	DMK 400
3/4	20.0	110-550	80-405	10 N-m	1 N-m	953.5	846.7	52	31.0	69	3.800	2641275	DMK 550
3/4	20.0	150-750	110-550	10 N-m	1 N-m	1,228.5	1,121.7	327	31.0	69	4.900	2641283	DMK 750
3/4	20.0	250-850	185-630	10 N-m	1 N-m	1,375.5	1,268.7	474	31.0	69	5.200	2641291	DMK 850

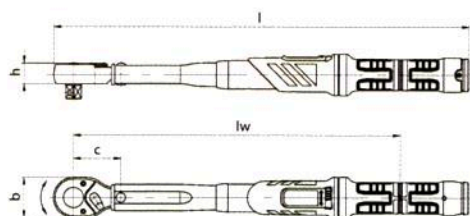

DMUK 200

12.5

1/2"



"	■	N-m	lbf-ft	سلسله	scale ring	L	lw	c	h	b	🔊	Code	No.
1/2	12.5	20-100	15-75	5 N-m	0,5 N-m	438.0	344.2	50	22.0	43	1.200	2641305	DMUK 100
1/2	12.5	40-200	30-150	10 N-m	1 N-m	529.0	435.2	50	22.0	43	1.400	2641313	DMUK 200