

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **39-01-4040**
Status: **Active**
Overview: Mini-Fit Jr.™ Power Connectors
Description: Mini-Fit Jr.™ Receptacle Housing, Single Row, PA Polyamide Nylon 6/6, UL 94V-2, 4 Circuits

Documents:

3D Model	Product Specification PS-5556-001 (PDF)
Drawing (PDF)	Test Summary TS-5556-002 (PDF)
Product Specification PS-45750-001 (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification

CSA	LR19980
UL	E29179

General

Product Family	Crimp Housings
Series	5557
Application	Power, Wire-to-Board, Wire-to-Wire
Comments	Current = 13A max. per circuit when header is mated to a receptacle loaded with 45750 series terminals crimped to 16 AWG wire. . See Molex product specification PS-45750-001 for additional current derating information.. See Molex product specification. Mini-Fit Jr.™ Power Connectors
Overview	
Product Name	Mini-Fit Jr.™
UPC	800754314961

Physical

Breakaway	No
Circuits (maximum)	4
Color - Resin	Natural
Flammability	94V-2
Gender	Receptacle
Glow-Wire Compliant	No
Keying to Mating Part	None
Lock to Mating Part	Yes
Material - Resin	Nylon
Net Weight	1.200/g
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	4.20mm
Pitch - Termination Interface	4.20mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40°C to +105°C

Electrical


Current - Maximum per Contact	13A
-------------------------------	-----

Material Info

Old Part Number	5557-04R2
-----------------	-----------

Reference - Drawing Numbers

Product Specification	PS-45750-001, PS-5556-001
Sales Drawing	SD-5557-NR2*

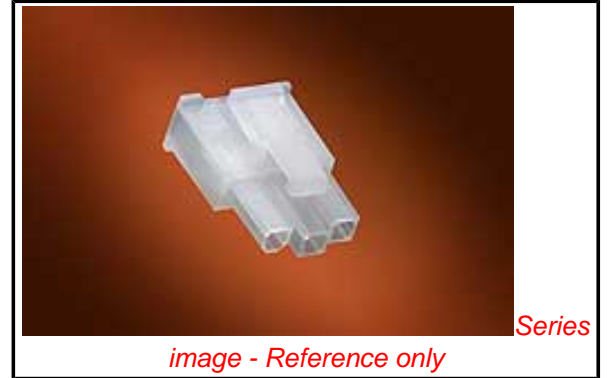

EU RoHS

ELV and RoHS Compliant

REACH SVHC

Contains SVHC: No Low-Halogen Status Low-Halogen

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

[5557Series](#)

Mates With

[39-01-4046](#) Free Hanging Plug, [39-30-2045](#) Vertical Header, [39-30-2047](#) Vertical Header, [39-30-3045](#) Right Angle Header, [39-30-3047](#) Right Angle Header

Use With

[5556](#) Mini-Fit® Female Crimp Terminals, [45750](#) Mini-Fit® Plus HCS Crimp Terminal

This document was generated on 02/13/2015

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION