


Magnetic Ballasts for HID Lamps

Magnetic Ballast Electrical Data

Lamp Watts (W)	70
Lamp Current (A)	1
Input Voltage at 50Hz	230/240
Circuit Watts (W)	86
Running Current (A)	0.39
Delta T (°C)	70
tw (°C)	140
Thermal cut out °C (± 5°C)	160
Capacitor Value (µf)	10
Capacitor Voltage (V)	250
Energy Efficiency Index (EEI)	A3

Physical Data

Dimensions (LxWxH mm)	120x69x56
Fixings (mm)	86-97
Weight (kg)	1.4

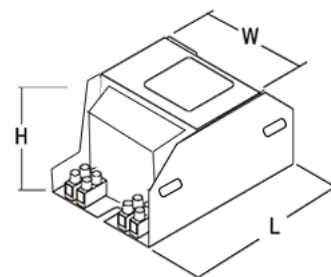

Ballast Diagram

Revision: 15-07-2013

See page 2 for product notes



Product Code: HSA07223221

Magnetic Ballasts for HID Lamps

Notes:

Additional fixings 53x95-109mm and side fixings 95-109mm