


QLINE® I

Cover Screw Kit

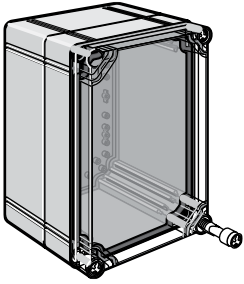


Screws are polyamide. Wing-head-style screws provide rapid access to enclosure interior without requiring special tools to open. Kit includes four polyamide cover screws and four self-tapping, plated panel screws. Tamper-resistant screws have molded 3-mm double-bit drive; kit includes four cover screws, one key and four self-tapping, plated panel screws. Use on all QLINE® I enclosures.

Bulletin: Q41Y

Catalog Number	Description
QIWHSK	wing-head screw
QITSK	3-mm tamper-resistant double-bit

Brass Insert Kit

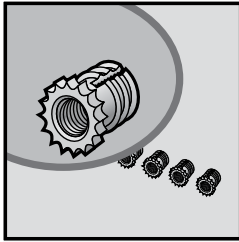


Four M5 self-tapping brass inserts screw into molded pads in bottom of enclosure. Inserts have M3 internal thread.

Bulletin: Q41Y

Catalog Number
QBIK

Panel Depth Fitting

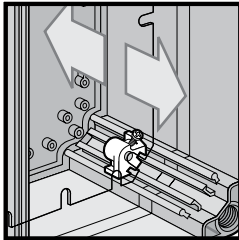

Panel Depth Fitting attaches to corner molded rails of enclosure to facilitate full-range front-to-back panel adjustment. Package includes four polyamide fittings and plated screws. Use on all QLINE I enclosures.

Bulletin: Q41Y

Catalog Number
QIPDF

Swing Panel



Adjustable-depth aluminum swing panels, for use in QLINE® I polycarbonate enclosures, provide a convenient way to install controls and instruments near enclosure body opening while providing access and security. Suitable applications include water, pulp and paper, petroleum and chemical processing, food, packaging and pharmaceutical applications.

Bulletin: Q41Y

Catalog Number	Panel Size D x E mm/in.	Fits Enclosure Size A x B mm/in.	Hinged Side of Enclosure
QIHFP22A	186 x 180	200 x 200	200
	7.32 x 7.09	7.87 x 7.87	
QIHFP23A	186 x 280	300 x 200	200
	7.32 x 11.02	11.81 x 7.87	
QIHFP32A	286 x 180	300 x 200	300
	11.26 x 7.09	11.81 x 7.87	
QIHFP42A	386 x 180	400 x 200	400
	15.20 x 7.09	15.75 x 7.87	
QIHFP33A	286 x 280	300 x 300	300
	11.26 x 11.02	11.81 x 11.81	
QIHFP43A	386 x 280	400 x 300	400
	15.20 x 11.02	15.75 x 11.81	
QIHFP63A	586 x 280	600 x 300	600
	23.07 x 11.02	23.62 x 11.81	
QIHFP64A	586 x 380	600 x 400	600
	23.07 x 14.96	23.62 x 15.75	