


7BB-20-3

In Production RoHS REACH

Appearance & Shape

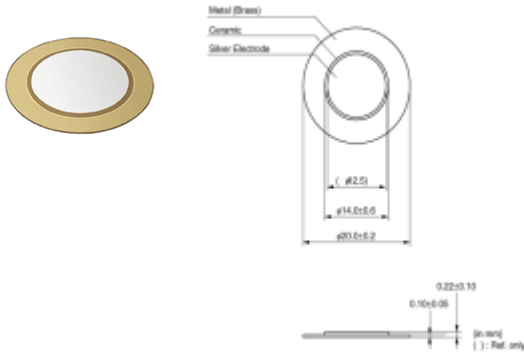

Features

1. Clear sound
2. Ultra thin and lightweight
3. No contacts: therefore, no noise and highly reliable
4. Low power consumption for voltage type

Applications

Other Usage	Consumer/Industrial
-------------	---------------------

Packaging Information

Packaging	Specifications	Minimum Order Quantity
-	Bulk	3000

Attention

1. This datasheet is downloaded from the website of Murata Manufacturing Co., Ltd. Therefore, its specifications are subject to change or our products may be discontinued without advance notice. Please check with our sales representatives or product engineers before ordering.
 2. This datasheet has only typical specifications because there is no space for detailed specifications.
 Therefore, please review our product specifications or consult the approval sheet for product specifications before ordering.

7BB-20-3

Specifications

Resonance Frequency	3.6kHz
Resonant Frequency Tolerance	±0.6kHz
Resonant Impedance	500Ω
Capacitance	20nF
Tolerance	±30%
Measurement Condition of Capacitance	[1kHz]
Plate Size	20mm
Element Size	14mm
Plate Material	Brass
Drive Type	External Drive
EIAJ Part Number	PD-SU2-C20-36

Attention

1.This datasheet is downloaded from the website of Murata Manufacturing Co., Ltd. Therefore, it's specifications are subject to change or our products may be discontinued without advance notice. Please check with our sales representatives or product engineers before ordering.
 2.This datasheet has only typical specifications because there is no space for detailed specifications.
 Therefore, please review our product specifications or consult the approval sheet for product specifications before ordering.