




# Datasheet


ENGLISH

Stock No: 136-976

# RS Pro Right Angle 50Ω PCB Mount TNC Connector, jack, Solder Termination

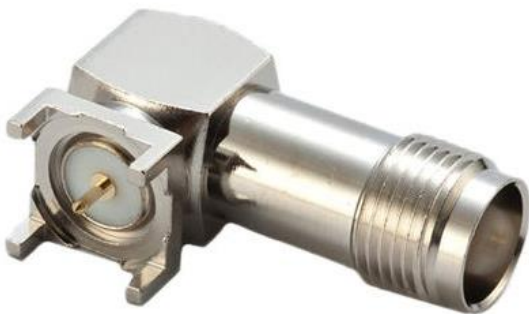

90° PCB socket

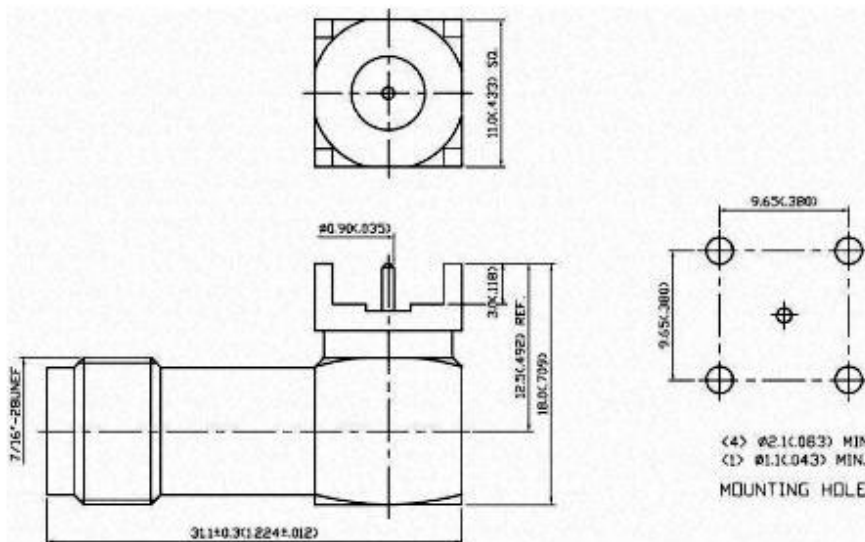



## Product Details

Brass bodied TNC connectors with PTFE insulators and gold plated contacts.

Bulk kit containing 100 RG58 straight plugs 546-5200 is available, making production and servicing much easier.

Component parts are neatly stored in a sturdy dispensing case

Crimp Tooling		
Cable Type	Cable Group	Use Crimp Tool(s)
RG58	A	456-431, 848-391, 848-436
RG174	B	492-9595 (frame) 492-9703 (die)
RG179	E	492-9595 (frame) 492-9703 (die)
RG59	F	456-447, 453-870, 848-391, 848-436
RG178	N	848-391, 282-3502

Body Material	Nickel plated brass
Contact Material	Gold plated copper alloy
Insulator Material	PTFE
Working Voltage	500V peak
Proof Voltage	1500V peak
Temperature Range	-40°C to +155°C
Nominal Impedance	50Ω and 75Ω
Operating Voltage	500V rms at sea level
Contact Resistance	Outer : 0.2mΩ
	Centre : 1.5mΩ
Insulation Resistance	5000mΩ
Dielectric	PTFE
Centre Contact	Gold plated



ENGLISH

## Specifications:

Gender	Female
Body Orientation	Right Angle
Termination Method	Solder
Mounting Type	PCB Mount
Body Plating	Nickel
Polarity	Normal
Impedance	50Ω
Contact Plating	Gold
Contact Material	Copper Alloy