


Ferrules INSULATED (INDUSTRIAL STANDARD)

French Code <Polypropylene insulated and tin-plated electrolytic copper>

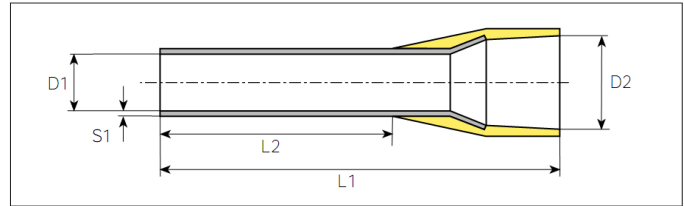

DIN 46228, part 4, except #


Model No.	Applicable wire		Style	Colour Code	Dimensions (mm)				
	mm2	AWG			L1	L2	D1	S1	D2
FWE0.25-6	0.25	24	II	Violet	11	6	0.8	0.15	1.9
FTR0.5-8	0.50	20	II	White	14	8	1	0.15	2.6
FTR0.75-8 #	0.75	18	I	Light Blue	14	8	1.2	0.15	3.2
FTR1.0-8 #	1.00	18	I	Red	14	8	1.4	0.15	3.4
FTR1.5-8 #	1.50	16	I	Black	14	8	1.7	0.15	3.8
FWE2.5-8	2.50	14	I	Grey	14	8	2.2	0.15	4.2
FWE4-10	4.00	12	I	Orange	17	10	2.8	0.2	4.8
FWE6-12	6.00	10	I	Green	20	12	3.5	0.2	6.3
FWE10-12	10.0	8	I	Brown	22	12	4.5	0.2	7.6
FWE16-12	16.0	6	II	White	24	12	5.8	0.2	8.8
FWE25-16	25.0	4	I	Black	30	16	7.3	0.2	11.2
FWE35-16	35.0	2	I	Red	30	16	8.3	0.2	12.7
FWE50-20	50.0	1	I	Blue	36	20	10.3	0.3	15

Note: 1) Style I - Suitable for Tri-rated cable, Style II - Standard

2) Maximum operating temperature: + 105°C

3) Delivery lead times may vary depending on the product. These products are **ONLY** available from the following JST affiliates; J.S.T. (U.K.) Ltd, J.S.T. Belgium N.V., J.S.T. India Liaison Office, and JST-SouthAfrica.com.

German Code <Polypropylene insulated and tin-plated electrolytic copper>

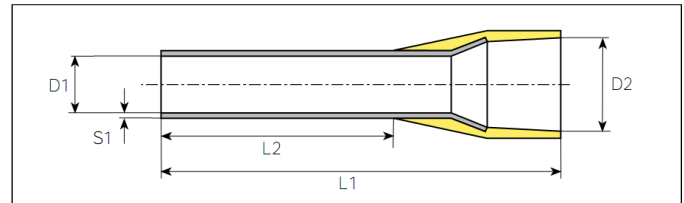

DIN 46228, part 4, except #

Model No.	Applicable Wire		Style	Colour Code	Dimensions				
	mm2	AWG			L1	L2	D1	S1	D2
GWE0.25-6	0.25	24	II	Light Blue	11	6	0.8	0.15	1.9
GTR0.5-8	0.50	20	II	Orange	14	8	1	0.15	2.6
GTR0.75-8 #	0.75	18	I	White	14	8	1.2	0.15	3.2
GTR1.0-8 #	1.00	18	I	Yellow	14	8	1.4	0.15	3.4
GTR1.5-8 #	1.50	16	I	Red	14	8	1.7	0.15	3.8
GWE2.5-8	2.50	14	I	Blue	14	8	2.2	0.15	4.2
GWE4-10	4.00	12	I	Grey	17	10	2.8	0.2	4.8
GWE6-12	6.00	10	I	Black	20	12	3.5	0.2	6.3
GWE10-12	10.0	8	I	Ivory	22	12	4.5	0.2	7.6
GWE16-12	16.0	6	II	Green	24	12	5.8	0.2	8.8
GWE25-16	25.0	4	I	Brown	30	16	7.3	0.2	11.2
GWE35-16	35.0	2	I	Beige	30	16	8.3	0.2	12.7
GWE50-20	50.0	1	I	Olive	36	20	10.3	0.3	15

Note: 1) Style I - Suitable for Tri-rated cable, Style II - Standard

2) Maximum operating temperature: + 105°C

3) Delivery lead times may vary depending on the product. These products are **ONLY** available from the following JST affiliates; J.S.T. (U.K.) Ltd, J.S.T. Belgium N.V., J.S.T. India Liaison Office, and JST-SouthAfrica.com.