


Steel wedge nail – PBZ-PRO

Steel wedge nail, white zinc plated - PBZ-PRO


Steel wedge nail, white zinc plated - PBZ



PBZ-PRO

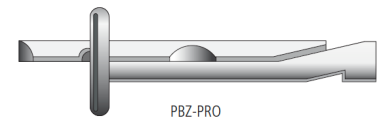

PBZ

 

Approvals and test reports



PBZ-PRO



PBZ-PRO

Product description

1. General Applications

PBZ-PRO

- ETA approved for (redundant) multiple fixing of non load bearing systems in cracked concrete C20/25 to C50/60
- Suitable for safety relevant applications

PBZ-PRO and PBZ

- For medium loads
- For use in cracked and uncracked concrete, sand-lime stone, solid brick, hollow core concrete slabs, light weight concrete and comprehensiveresistant stone
- Hammer set anchor for push through installation for ceiling suspensions
- For fixing battens, metal profiles, wire hangers ventilation pipes, ceilings, etc.

2. Benefits

- Quick and simple hammer set installation reduces installation time
- No special setting tool required
- Safe and controlled expansion
- Small drill diameter required, shallow embedment
- Can be installed close to an edge
- Big head provides perfect fixing through big slots
- High(est) load compared to competitors

3. Properties

 
PBZ-PRO

- ETA part 6 approval for drill diameter 6mm in cracked and uncracked concrete
- F30 to F120 fire resistance approval


PBZ-PRO and PBZ

- Available in two sizes
6 x 35 for small fixtures
6 x 65 for big fixtures





PBZ-PRO

 

PBZ



PBZ-PRO



PBZ-PRO steel wedge nail						
Type	Art. Nr.					
Type	Art. Nr.			L [mm]	d _o [mm]	
PBZ-PRO 6x5/35	02836	100	1000	35	6	
PBZ-PRO 6x35/65	02838	100	1000	65	6	
PBZ-6x5/35	02830	200	1600	35	6	
PBZ-6x35/65	02832	200	800	65	6	







Allowable loads						
Type	h _{ef} [mm]	h ₁ [mm]	d _f [mm]	t _{fix} [mm]	N _{all} & V _{all} [kN]	
PBZ-PRO 6x5/35	30	40	7	5	1,4	
PBZ-PRO 6x35/65	30	40	7	35	1,4	

Recommended loads						
Type	h _{ef} [mm]	h ₁ [mm]	d _f [mm]	t _{fix} [mm]	N _{rec} & V _{rec} [kN]	
PBZ-6x5/35	30	40	7	5	0,8	
PBZ-6x35/65	30	40	7	35	0,8	



Allowable loads						
Type	h _{ef} [mm]	h ₁ [mm]	d _f [mm]	t _{fix} [mm]	N _{all} & V _{all} [kN]	
PBZ-PRO 6x5/35	30	40	7	5	1,4	
PBZ-PRO 6x35/65	30	40	7	35	1,4	

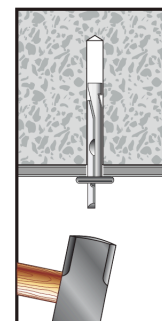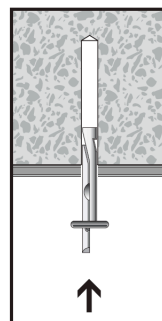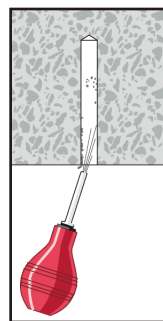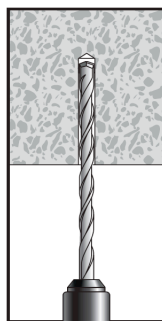

+31 (0)888-POWERS (769 377)

Powers cannot be responsible for any errors and reserves the right to make technical and range modifications without notice. No liability is accepted for printing errors and omissions. Powers terms and conditions apply. Copyright © 2011 Powers Fasteners Europe. All rights reserved.

Powers