


BESGR Conduit Joiner Ex e Non Metallic System

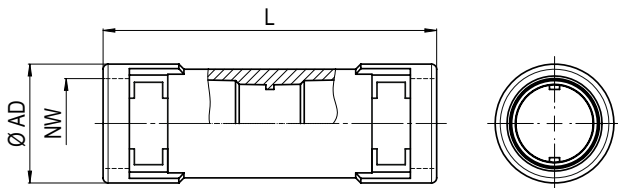

Features

- Prevents electrostatic charging
- For indoor and outdoor applications
- High thread and system connection strengths
- Easy installation
- Very good chemical properties

Approvals



Certification & Standards

Approved to:	IEC EN 60079-0, 60079-7, 60079-31
EC TYPE Examination Certificate:	ATEX: SEV 15 ATEX 0107X IECEX: IECEX SEV15.0001X Ex e IIC Gb Ex tb IIIC Db
Temperature:	-5°C to +85°C Sizes 02-03 -20°C to +85°C Sizes 04-08
IP protection:	IP68

Compatible with: XESX Conduit / Materials: Anti-Static Nylon 12 / Colour: ● Black

Part No.	Conduit Size (mm)		Dimensions (mm)		Weight kg/100	GID Codes
	Metric	NW	L	ØAD		
BESGR0303	16	12	66	23.5	1.3	7TCA297120R0394
BESGR0404	20	17	87	29.5	2.1	7TCA297120R0395
BESGR0505	25	23	103	37	3.7	7TCA297120R0396
BESGR0606	32	29	100	44	4.4	7TCA297120R0397
BESGR0707	40	36	130	53.5	8.1	7TCA297120R0398
BESGR0808	50	48	133	66	12.6	7TCA297120R0399