



Datasheet
Stock No:123-7928

ENGLISH

RS Pro LED G9 Capsule Warm White (2,700k) 100lm 2W

Specifications:


Lamp & Base Type: G9
Material: Polycarbonate
Length Dimension: 48mm
Width Dimension: 16mm
Voltage Rating: 220-240 V
Power Consumption: 2W
Electric current: AC
Ampage: 160mA
Frequency Range: 50/60Hz



Features:

For indoor and general lighting
Non-Dimmable

2700 K

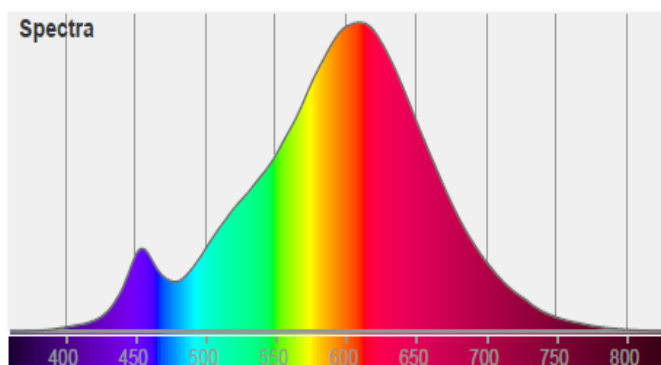

Beam angle

285°

