

Molex's range of pre-crimped leads offers a simple and cost-effective solution for any pre-production and prototype requirements. Available for the most popular Molex connector families, the leads are offered in female-to-female and male-to-male configurations and lengths of 150mm and 300mm

Features and Benefits

Pre-crimped and fully tested cables	Decrease time to market
Available in 150mm and 300mm lengths	Ideal for all prototype and pre-production requirements
Leads crimped on both ends	Suitable for wire-to-wire applications and when cut in half wire-to-board applications
UL listed cables	Assures high-quality approved materials
Available for most popular Molex families	Helps customers choose the right connector before investing in application tooling




C-Grid III™



CLIK-Mate™



DuraClik™

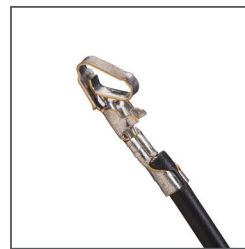

KK®



Mega-Fit®



MicroClasp™



Micro-Fit 3.0™




Mini-Fit®



MLX™



PicoBlade™

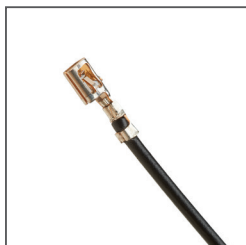

Pico-Clasp™



Pico-EZmate™



Pico-Lock™



Pico-SPOX™



Sabre™



Sherlock™



SL™



Standard .062"



Standard .093"

Ordering Information

Product Family	Order Number	Length	Connector A	Connector B	Wire Size	Wire/Cable Type
C-Grid®	797582022	150mm	Female	Female	22 AWG	UL 1061
	797582023	300mm	Female	Female	22 AWG	UL 1061
CLIK-Mate™	797581011	300mm	Female	Female	24 AWG	UL 1061
	797581012	150mm	Female	Female	28 AWG	UL 1061
	797581013	300mm	Male	Male	28 AWG	UL 1061
	797581014	150mm	Male	Male	24 AWG	UL 1061
	797581015	300mm	Male	Male	24 AWG	UL 1061
DuraClik™	797581008	150mm	Female	Female	26 AWG	UL 1061
	797581009	300mm	Female	Female	26 AWG	UL 1061
KK®	797580007	150mm	Female	Female	22 AWG	UL 1061
	797580011	300mm	Female	Female	22 AWG	UL 1061
	797580015	300mm	Male	Male	22 AWG	UL 1061
	797582024	300mm	Female	Female	24 AWG	UL 1007
Mega-Fit®	797582037	150mm	Female	Female	16 AWG	UL 1015
	797582038	300mm	Female	Female	16 AWG	UL 1015
	797582039	150mm	Female	Female	12 AWG	UL 1015
	797582040	300mm	Female	Female	12 AWG	UL 1015
Micro-Clasp™	797581001	150mm	Female	Female	24 AWG	UL 1007
	797581002	300mm	Female	Female	24 AWG	UL 1007
Micro-Fit™	797580002	150mm	Female	Female	20 AWG	UL 1061
	797580004	150mm	Female	Female	20 AWG	UL 1061
	797580010	300mm	Female	Female	20 AWG	UL 1061
	797580012	300mm	Female	Female	20 AWG	UL 1061
Mini-Fit®	797580001	150mm	Female	Female	18 AWG	UL 1061
	797580005	150mm	Male	Male	18 AWG	UL 1061
	797580009	300mm	Female	Female	18 AWG	UL 1061
	797580013	300mm	Male	Male	18 AWG	UL 1061
	797582029	150mm	Male	Male	18 AWG	UL 1015
MLX™	797582030	300mm	Male	Male	18 AWG	UL 1015
	797582031	150mm	Female	Female	18 AWG	UL 1015
	797582032	300mm	Female	Female	18 AWG	UL 1015
	6660012	152mm	Female	Female	28 AWG	Discrete Wire
PicoBlade™	6660013	300mm	Female	Female	28 AWG	Discrete Wire
	6660015	150mm	Female	Female	28 AWG	Discrete Wire
	6660016	150mm	Female	Male	28 AWG	Discrete Wire
	6660017	300mm	Female	Male	28 AWG	Discrete Wire
	797580006	150mm	Female	Female	26 AWG	UL 1061
	797580014	300mm	Female	Female	26 AWG	UL 1061
	797581016	150mm	Female	Female	28 AWG	UL 1571
Pico-Clasp™	797581017	300mm	Female	Female	28 AWG	UL 1571
	797581018	150mm	Female	Female	28 AWG	UL 1571
	797581019	300mm	Female	Female	28 AWG	UL 1571
	797581010	300mm	Female	Female	28 AWG	UL 1516
Pico-EZmate™	797581003	150mm	Female	Female	24 AWG	UL 1061
Pico-Lock™	797581004	300mm	Female	Female	24 AWG	UL 1061
	797581005	150mm	Female	Female	30 AWG	UL 1571
	797581006	300mm	Female	Female	30 AWG	UL 1571
	797580008	150mm	Female	Female	24 AWG	UL 1061
Pico-SPOX™	797580016	300mm	Female	Female	24 AWG	UL 1061
	797581007	300mm	Female	Female	24 AWG	UL 1061
	797582041	150mm	Male	Male	16 AWG	UL 1015
Sabre™	797582042	300mm	Male	Male	16 AWG	UL 1015
	797582043	150mm	Female	Female	16 AWG	UL 1015
	797582044	300mm	Female	Female	16 AWG	UL 1015
Sherlock™	797581020	150mm	Female	Female	26 AWG	UL 1061
	797581021	300mm	Female	Female	26 AWG	UL 1061
SL™	797580003	150mm	Female	Female	22 AWG	UL 1061
Standard .062"	797582025	150mm	Male	Male	22 AWG	UL 1015
	797582026	300mm	Male	Male	22 AWG	UL 1015
	797582027	150mm	Female	Female	22 AWG	UL 1015
	797582028	300mm	Female	Female	22 AWG	UL 1015
Standard .093"	797582033	150mm	Male	Male	18 AWG	UL 1015
	797582034	300mm	Male	Male	18 AWG	UL 1015
	797582035	150mm	Female	Female	18 AWG	UL 1015
	797582036	300mm	Female	Female	18 AWG	UL 1015