

Professionally approved products.


Datasheet

RS 9.5mm Yellow Heat Shrink Tubing 2:1, 1.2m Length

RS Stock 399-619



Dimensions: (mm)

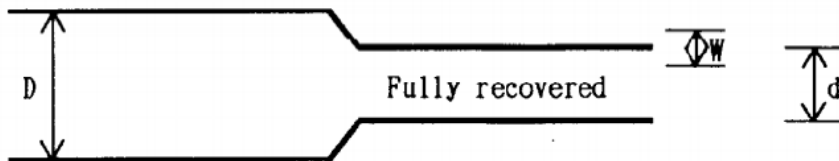

Specification

		Requirement
Physical	Tensile Strength	10.3MPa (min.)
	Ultimate Elongation	200% (min.)
	Longitudinal Change	0±5%
	2%Secant Modulus	172.4MPa (max.)
	Specific Gravity	1.00 (max.)
	Heat Resistance	Elongation 100% (min.) after 168hours at 175°C
	Heat Shock	No dripping, flowing or cracking after 4hours at 250°C
	Low Temperature Flexibility	No cracking, during mandrel bend after 4hours at -55°C
	Flammability	Not Flame Retarded
Electrical	Dielectric Strength	19.7KV/mm (min.)
Chemical	Copper Contact Corrosion	Non-corrosive
	Water Absorption	0.2% (max.)
	Fungus Resistance	Inert

