


# Data sheet

## PS

RS Stock No. 334-2616

ENGLISH

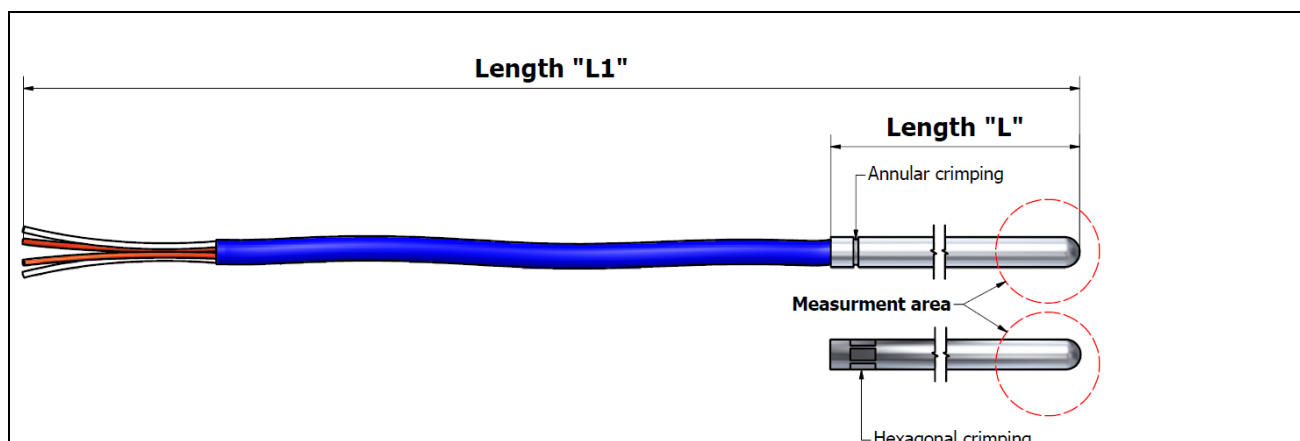

### PT1000 THERMIC ELEMENT WITH CABLE AND TIP

**RANGE :**

- 20°C / +100°C

**USE :**

- Universal

**KEY POINT :**

- Flexible

**SPECIFICATIONS:**

- PT1000Ω thermic element A Class – 1x2 wires
- Tip in SS3304L
- Cable 2 conductors, section 0.5mm<sup>2</sup>, isolated PVC/PVC
- Hexagonal crimping

**DIMENSIONS:**

- Tip length = 100mm
- Tip diameter = 6mm
- Total length (tip + cable) = 2100mm

**METROLOGICAL DATA :**

- As per IEC 751
- Standard tolerance PT100 A class :±0.15 + 0.002.[t°C]

**Other dimensions:**

TIP Length	35mm	100mm
Diameter	6mm	457-3653
		334-2616