

**Application:** A mild steel IP66 industrial wall box suitable for housing electronic and electrical equipment in demanding environments, where the area is prone to frequent hosing or generally wet conditions.

**Supply Includes:** Enclosure and door mounting plate, single locking system, gland plate, sealing gasket and fixing accessories.

**Standard Configuration:** Paint finish epoxy polyester powder coating textured finish


**Color:** RAL7032

**Protection degree:** IP66

**Against mechanical impacts:** IK10

**Thickness:** enclosure & door 1.2mm or 1.5mm sheet steel

**Mounting plate:** zinc-coated steel 1.5mm or 2.0mm

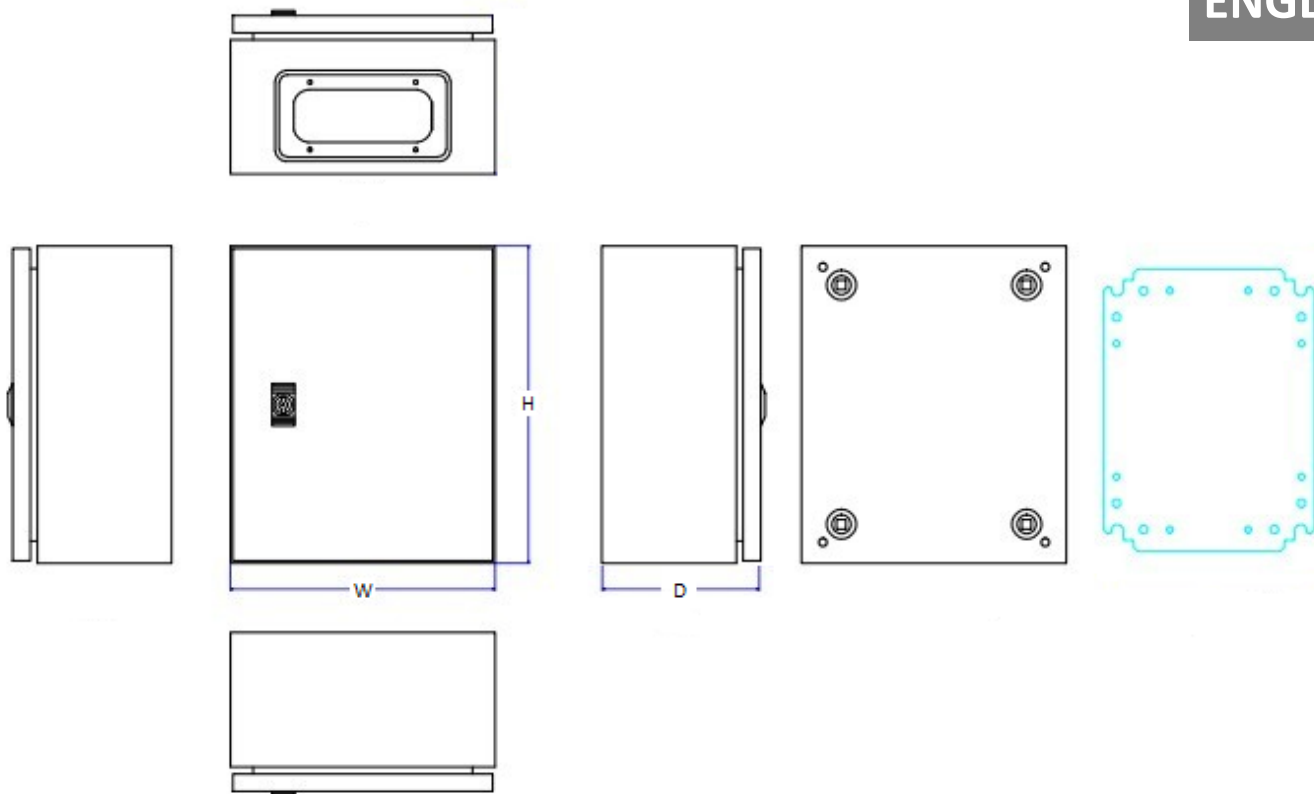

Stock no.	Description	Height (mm)	Width (mm)	Depth (mm)	Body & door thickness (mm)	Mounting plate thickness (mm)
775-5785	Single lock	200	200	150	1.2	1.5
775-5788	Single lock	300	200	150	1.2	1.5
775-5300	Single lock	300	250	150	1.2	1.5
775-5782	Single lock	300	250	150	1.2	1.5
775-5791	Single lock	300	300	150	1.2	1.5
775-5319	Single lock	300	300	210	1.2	1.5
775-5794	Single lock	300	400	200	1.2	1.5
775-5312	Single lock	300	400	210	1.2	1.5
775-5798	Single lock	400	300	150	1.2	1.5
775-5808	Single lock	400	300	200	1.2	1.5
775-5316	Single lock	400	300	210	1.2	1.5
775-5801	Single lock	400	400	200	1.2	1.5
775-5325	Single lock	400	400	210	1.2	1.5
775-5328	Single lock	400	600	210	1.2	1.5
775-5805	Single lock	500	400	150	1.2	1.5
775-5814	Single lock	500	400	200	1.2	1.5
775-5322	Single lock	500	400	210	1.2	1.5
775-5331	Single lock	500	500	210	1.2	1.5
775-5334	Single lock	500	500	300	1.2	1.5