

# Datasheet

## Round Fixed Height Feet, 50865 19mm, Synthetic Rubber

RS Stock number 543-232



GRADE: C599M/75


DESCRIPTION: PVC COMPOUND

PRODUCT FORM: PELLETS

REGULATORY: ROHS & WEEE COMPLIANT  
DINP Plasticiser

Temperatures  
50°C Maximum Continuous  
70°C Maximum Intermittent

Property	Test Method	Units	Value
Relative Density- S.G.	BS2782 620A	g/cc	1.32
Softness-BSS Number	BS2782 365A		82
Softness-Shore A Hardness			56
Tensile Strength MN/m <sup>2</sup>	BS2782 320A	MN/m <sup>2</sup>	10.53
Extension at Break - %	BS2782 320A		332
Modulus at 100% - MN/m <sup>2</sup>	BS2782 320A	MN/m <sup>2</sup>	4.16
Cold Flex Temperature	BS2782 150B	° C	-42.5°C

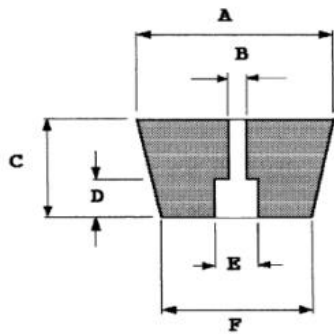

Stock No.	A	B	C	D	E	F
543-232	19	5	10.2	6.6	10	18
543-513	19	3.8	15.5	4.5	8	13.2

Dimensions in mm

All dimensions are approximate only.

Please note that the above figures are typical values and do not constitute any part of a product specification.