


## Datasheet

# Black Neoprene Rubber Sheets, 1000mm x 1200mm a 1.5mm

RS Stock number [506-3107](#)

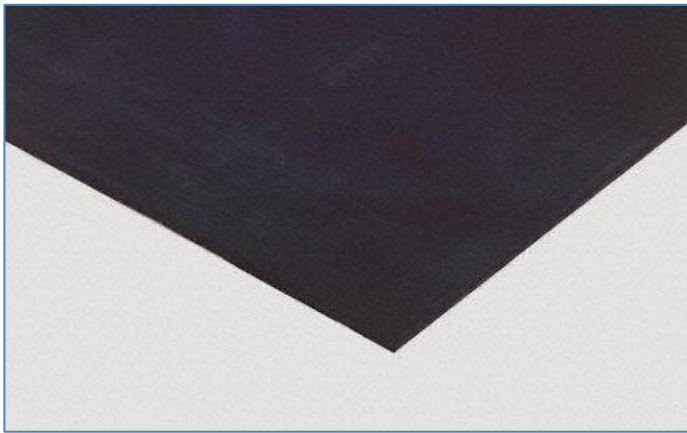

## Description:

Black Neoprene Rubber sheets which can be used in outdoor applications where resistance to atmospheric ageing sunlight and seawater are required. Not resistant to oil and benzene.

## Specifications:

Colour:	Black
Hardness:	60+/-7
Finish:	Smooth
Durometer:	Shore A
Density (Gram/Cm <sup>3</sup> ):	1.35
Tensile Strength:	5 N/mm <sup>2</sup>
Elongation at Break:	300%
Temperature (°C):	Minimum -10 Maximum +70 Intermittent +90