

Datasheet

## RS Pro P13.5s Filament Indicator Lamp, Clear, 2.2 V, 300 mA, 18h

RS Stock No: **106-442**



### Product Details

RS Pro P13.5s filament indicator lamp comes with clear lens and P13.5s prefocus base. It is filled with Krypton gas for high brightness. It has a voltage rating of 2.2 V and current rating of 300 mA. The lamp has 18 h life.

### Features and Benefits

- Olive shape B3 - 11 mm glass
- Alternative to vacuum types
- P13.5s prefocus base




**Specifications:**

Current Rating	300 mA
Diameter	11 mm
Lamp Base	P13.5s
Length	28 mm
Lens Colour	Clear
Life Hours	18 h
Luminosity	42 lm
Voltage Rating	2.2 V

RS Stock No.	106442
--------------	--------

*DRAWING - I*

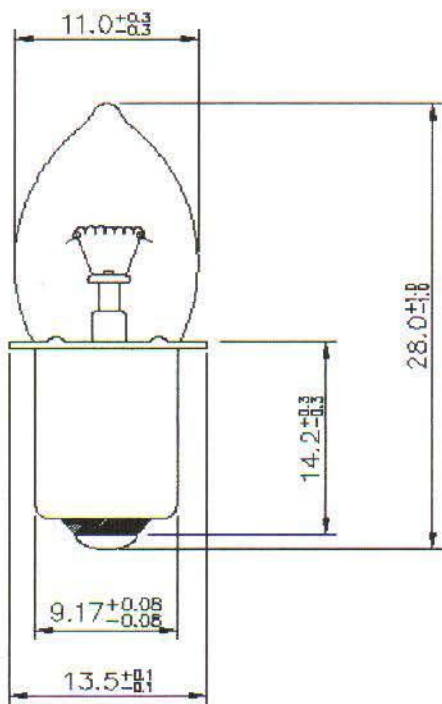

Unit : mm

1. Structure	Bulb Type	Near-Far Brilliant
	Bulb Diameter	Ø 11.0Max.
	Length	28.0Max
	Base Type	P13.5s
2. Design Characteristics	Voltage	2.2V
	Amperage	300mA±10%
	Filament Type	Vacuum Type
	Luminous Flux	42Lm±20%
	Life Hours	18Hrs