



Datasheet

RS Pro 1905 Piece Stainless Steel Screw/Bolt Kit, M3, M4, M5, M6

RS Stock No: **395-434**



Product Details

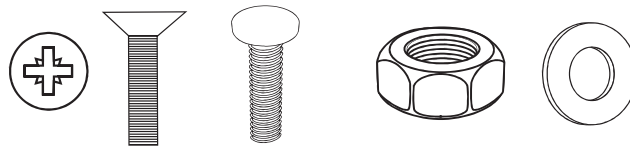
RS Pro screw/bolt kit contains 1905-pieces of M3, M4, M5 and M6 threaded screws. The screw/bolt with pozidriv drive, features A4 grade 316 stainless steel construction with plain finish. The screws meets DIN 7985 and 965 standards, nuts meets 934 standards and washers meets DIN 125 standards.

 
 
 
 
 
 
 
 
 
 
 

 
 




Features and Benefits

- Flat, pan head
- Stainless steel construction
- Sold as pack of 1905

Specifications:

Drive Type	Pozidriv
Finish	Plain
Head Shape	Flat, Pan
Material	Stainless Steel
Number of Pieces	1905
Screw/Bolt Length Longest	30 mm
Screw/Bolt Length Shortest	6 mm
Screw/Bolt Type	Machine Screw
Screw/Bolts Lengths	6 to 30 mm
Stainless Steel Type	316, A4
Thread Size	M3, M4, M5, M6
Specification	DIN 7985, DIN 965, DIN 934, DIN 125



 3 x 6 3 x 8	 3 x 10 3 x 12	 3 x 16 3 x 20	 4 x 8 4 x 10	 4 x 12 4 x 20	 5 x 10 5 x 12 5 x 20
 6 x 16 6 x 20	 3 x 6 3 x 12	 3 x 16 4 x 6	 4 x 12 4 x 16	 4 x 20 4 x 25	 5 x 30
 M6	 M5	 M4	 M4	 M3	 M3