



Datasheet

125 mm Chrome Molybdenum Steel Circlip Pliers with Bent Tip, External, Range 10 → 25 mm

RS Stock number [541-6848](#)

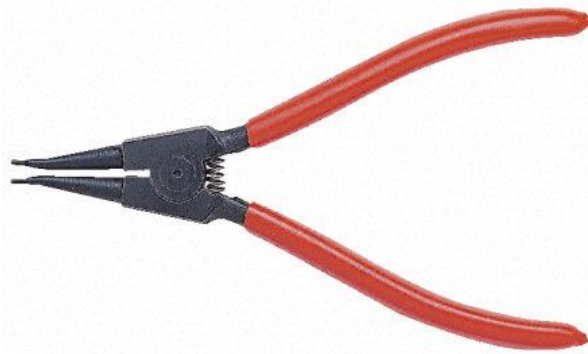

RS Stock No: 541-6848

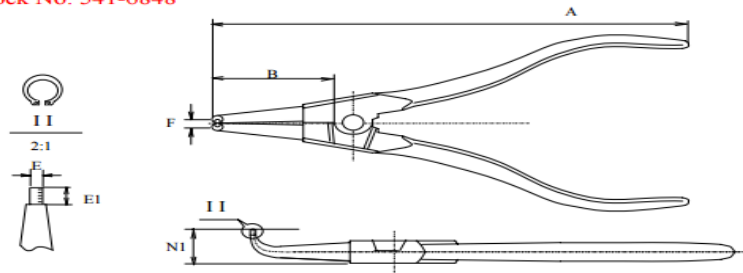

Inspection item	Specification	Inspection tools
A mm	126±2	Kaliper
B mm	25+2	Kaliper
E mm	1.3±0.3	Kaliper
E1 mm	1.5±0.3	Kaliper
D max	(17.1)	Kaliper
N1 mm	14±2	Kaliper

MATERIAL: CHROME MOLYBDENUM STEEL FOR PLIERS, SPRING STEEL FOR AUTOMATIC RETURN FUNCTION AND VINYL DIPPING HANDLES.

FINISH: CHEMICAL BLACK FINISH WITH POLISH MAIN SURFACE FOR PLIERS, RED COLOR HANDLE.

HARDNESS: HEAT TREATED TO HRC: 45~55 (CIRCLIP TIP), HRC: 44~48 (HANDLE) AND HRC: 30~48 (JOINT)

CONTENTS:

1 PC - 5" (125 MM) EXTERNAL 90 BENT TYPE, LARGE CYLINDRICAL TIP CIRCLIP PLIERS WITH AUTOMATIC RETURN SPRING AND RED COLOR VINYL DIPPING GRIP (DIAMETER OF TIP - 1.3MM, OVERALL LENGTH -125MM, JAW LENGTH - 38 MM, CIRCLIP SEAL RING CAPACITY - 8-25 MM)
PA0400 RS STOCK NO: 541-6848 (OLD STOCK NO: 185-2830)-A11

REMARKS:

1. DIMENSIONS, HANDLE SPIN, RETAINING TESTS, PERMANENT AND HUMIDITY MEET DIN- STANDARD. (FORM A TYPE)