

Datasheet

## RS Pro Straight PCB Mount SMC Connector, jack, Clamp Termination

RS Stock No: **546-3456**



### Product Details

RS Pro PCB mount SMC connector jack offers clamp termination. This straight connector includes a soldered centre contact. It is compatible with RG174 A/U cable type.


### Features and Benefits

- Gold-plated
- Suitable for use with RG174 cable
- Centre contact is soldered

**Specifications:**

Body Orientation	Straight
Body Plating	Gold
Contact Material	Brass
Contact Plating	Gold
Gender	Female
Impedance	50 Ω
Mounting Type	PCB Mount
Operating Frequency	10 GHz
Size	Subminiature
Termination Method	Clamp
Operating Temperature Range	-65 to +165°C

All Dimensions in mm (inch in brackets)

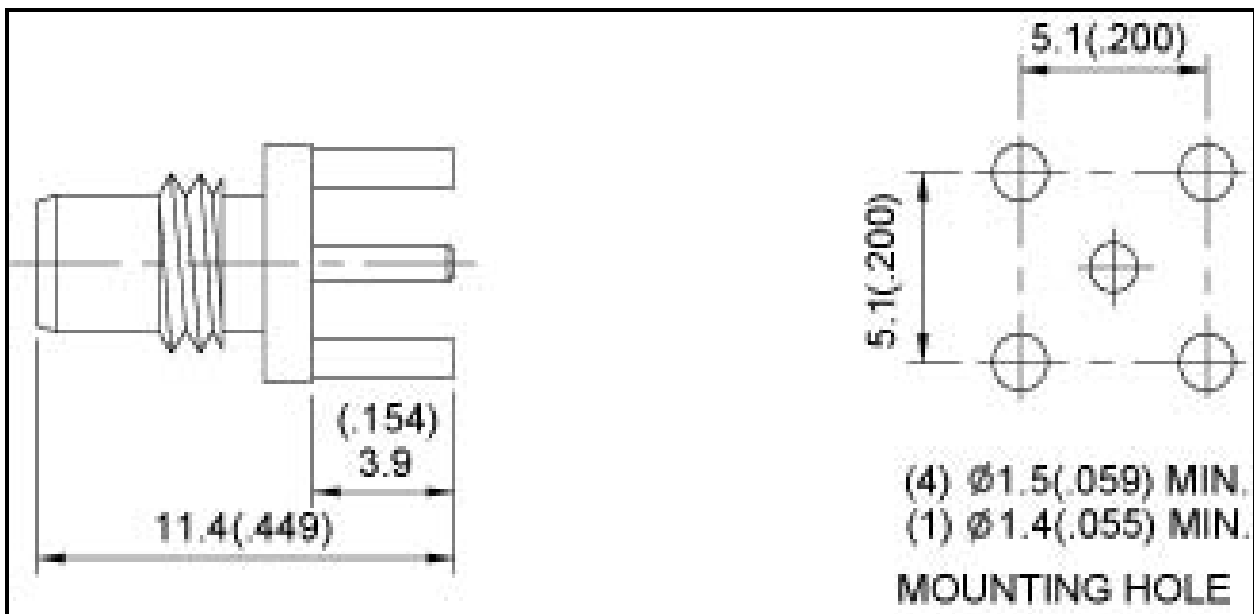

**Straight PCB Mount Jack Receptacle**