



ENGLISH

Datasheet

RS Gooseneck Microphone, Unidirectional 500 Ω

RS Stock number: 699-7304



Electronical Specifications:

Directional Characteristics: Uni-Directional

Frequency: 100 Hz ~ 16,000 Hz

Impedance: 500 Ω \pm 30% (at 1,000 Hz)

Sensitivity: -77 dB \pm 3dB (0 dB = 1 V/microbar 1,000 Hz indicated by open circuit)

Mechanical Specifications:

Dimension: ϕ 31.7 x 464.5 mm

Weight: 215g

Connector: 3-Pin XLR Type Jack


Finish: Black

Method of Measurement:

According to JIS C-5502

Test Instrument:

Bruel & Kjaer – Type 2012 Digital turntable system

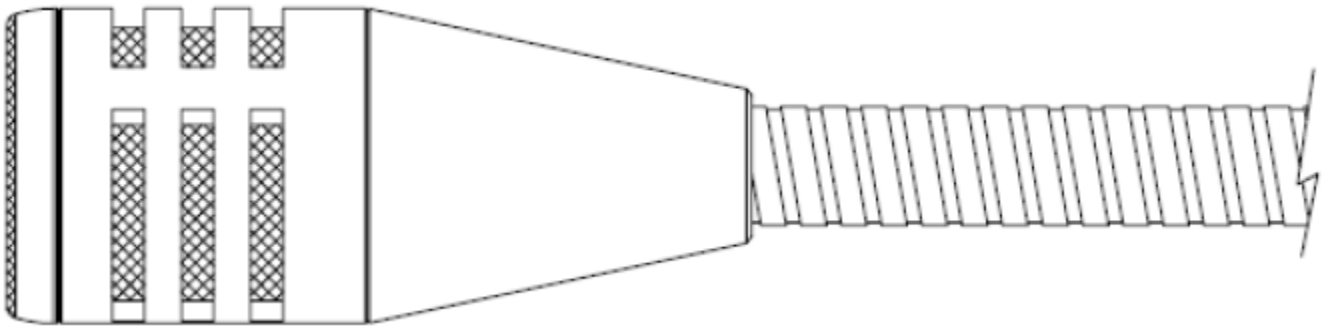

Frequency Response Curve:

